




# Hook Type Toggle Clamps

stainless steel

# Stainless Steel Toggle Clamps

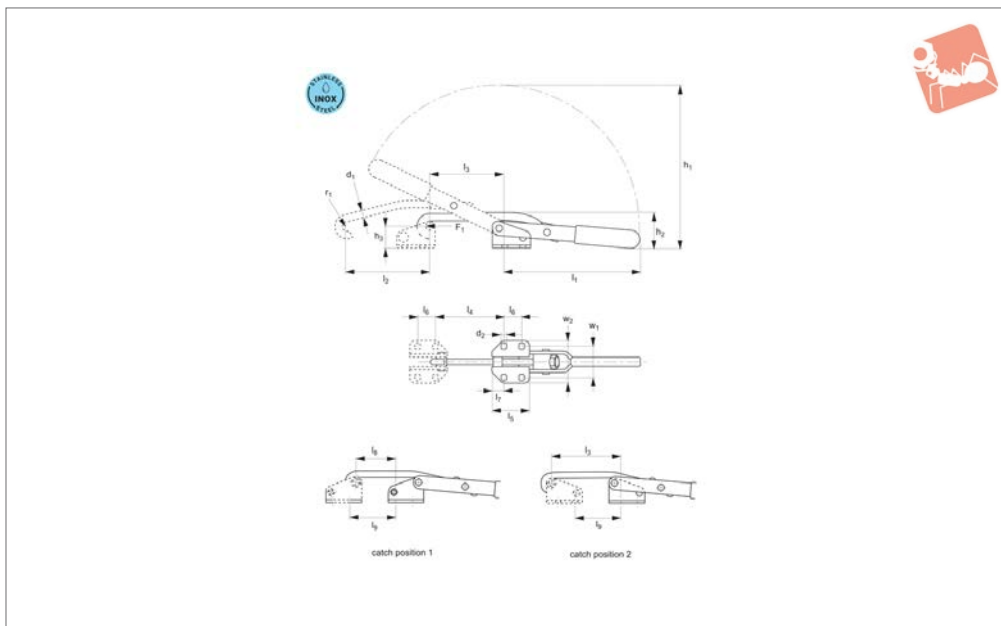

**41700.4**

STAINLESS STEEL TOGGLE CLAMPS

### Material

Body: stainless steel (AISI 304, 1.4301).  
 Rivets: stainless steel running in hardened bushes. Pre-lubricated bearings.  
 Handle: oil-resistant plastic with large grip

area.

### Technical Notes

For counter strike see part no. 41740.  
 W0011- .W0015.

**The length of the hook is adjustable by rotating the threaded hook to extend or contract its reach.**

Temperature range -10°C to +80°C.  
 Suitable for food industry.

Order No.	Size	F <sub>1</sub> kN	h <sub>1</sub>	h <sub>2</sub>	h <sub>3</sub>	l <sub>1</sub>	l <sub>2</sub>	l <sub>3</sub>	l <sub>4</sub>	Weight g
41700.W0301	1	1.0	111	35.0	22.7	88	45	35,0-42,0	35,0-42,5	100
41700.W0303	3	1.5	179	36.5	22.7	148	97	65,5-77,0	72,5-84,0	270
41700.W0305	5	2.5	280	70.5	49.1	228	146	57,0-71,0	58,0-72,0	850

Order No.	l <sub>5</sub>	l <sub>6</sub>	l <sub>7</sub>	l <sub>8</sub>	l <sub>9</sub>	w <sub>1</sub>	w <sub>2</sub>	d <sub>1</sub>	d <sub>2</sub>	r <sub>1</sub>	Adj. distance
41700.W0301	31	19	6	16,5-23,5	16,0-23,0	40	25,5-30,5	6	4.5	4.5	8
41700.W0303	40	19	13	39,5-50,5	32,5-44,0	45	31,0-36,0	8	5.6	5.5	12
41700.W0305	55	29	13	27,5-42,0	26,5-40,0	85	56,0-63,5	12	11.2	8.0	14