





# Star Grips

die-cast stainless steel - DIN 6336

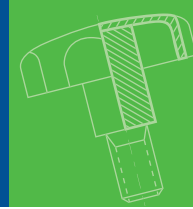

Grips

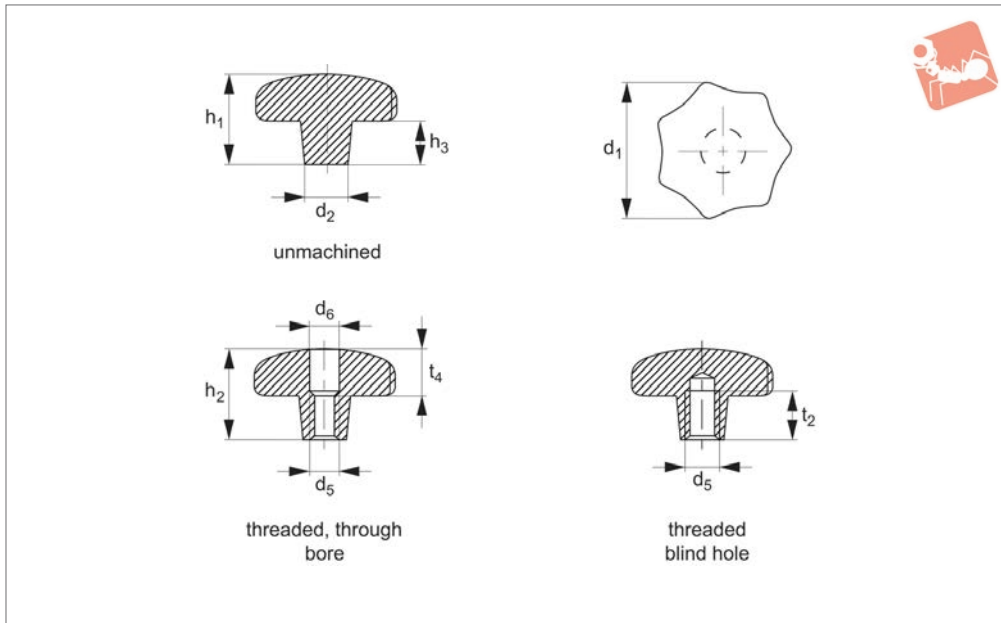

70122

GRIPS

## Material

Stainless steel A2 (AISI 304), dull blasted.

Order No.	Finish	d <sub>1</sub>	d <sub>2</sub>	d <sub>5</sub>	d <sub>6</sub>	h <sub>1</sub>	h <sub>2</sub>	h <sub>3</sub>	t <sub>2</sub>	t <sub>4</sub>	Weight g
70122.W0032	Unmachined	32	12	-	-	21	-	10	-	-	56
70122.W0040	Unmachined	40	14	-	-	26	-	13	-	-	85
70122.W0050	Unmachined	50	18	-	-	34	-	17	-	-	181
70122.W0063	Unmachined	63	20	-	-	42	-	21	-	-	319
70122.W0332	Threaded, Through	32	12	M 6	6.4	-	20	-	-	10	52
70122.W0340	Threaded, Through	40	14	M 8	8.4	-	25	-	-	12	75
70122.W0350	Threaded, Through	50	18	M10	10.5	-	32	-	-	16	158
70122.W0363	Threaded, Through	63	20	M12	13.0	-	40	-	-	20	279
70122.W0432	Threaded, Blind	32	12	M 6	-	-	20	-	12	-	53
70122.W0440	Threaded, Blind	40	14	M 8	-	-	25	-	15	-	77
70122.W0450	Threaded, Blind	50	18	M10	-	-	32	-	18	-	165
70122.W0463	Threaded, Blind	63	20	M12	-	-	40	-	22	-	296