




# Flush Mount - Drop Lid Hinges

overlay - zinc



## Hinges

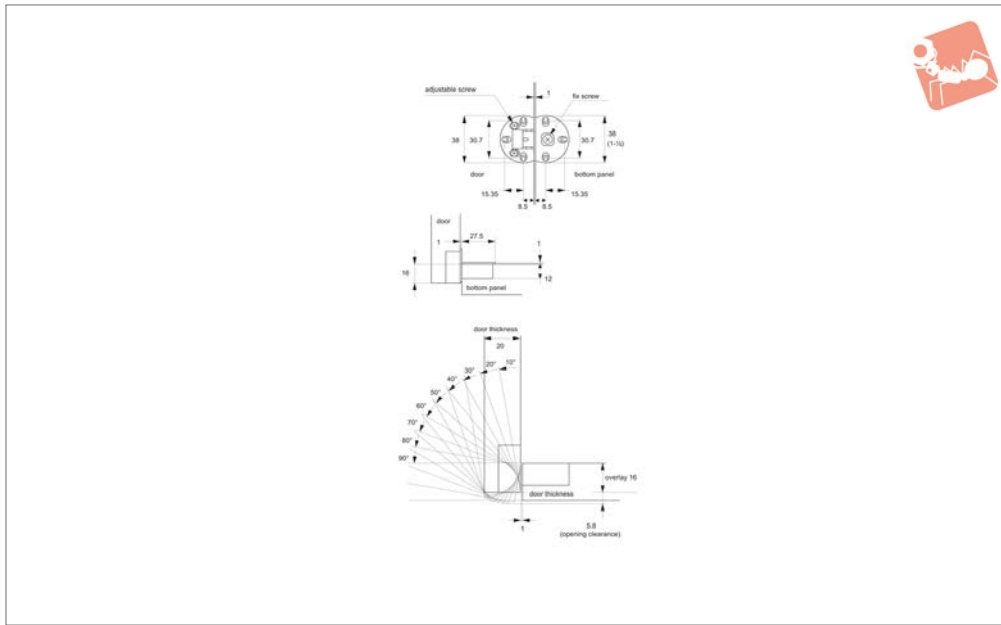

**S2050**

HINGES

**Material**

Die cast zinc, nickel plated.

**Technical Notes**

Hinge flush when opened.


Max door thickness: 16-20mm. Overlay coverage: 14-16mm.


Hinge alignment adjustable after installation. Max. opening angle 90°.

**Important Notes**

Ideal for use in hi-fi cabinets, writing desks etc.

Order No.	Door thickness max.	Hinge dia.	Weight g
S2050.AC0038	16-20mm	38	79

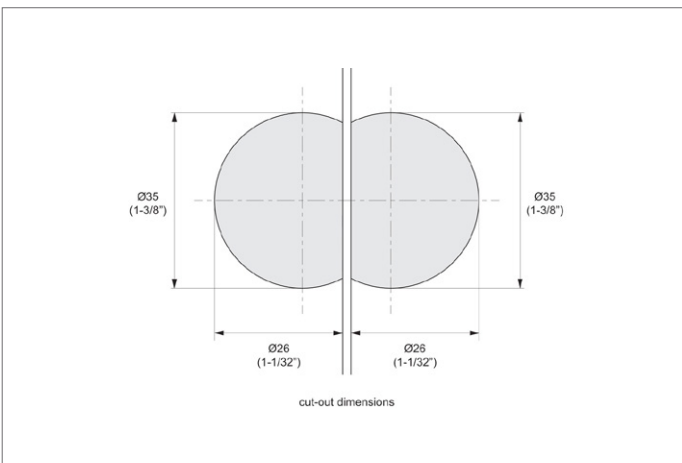


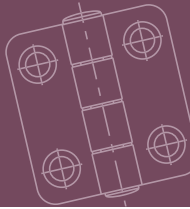

### A variety of mounting methods are available!

#### Mounting combinations

Wixroyd concealed hinges can be mounted in a variety of ways using additional nuts and bolts.

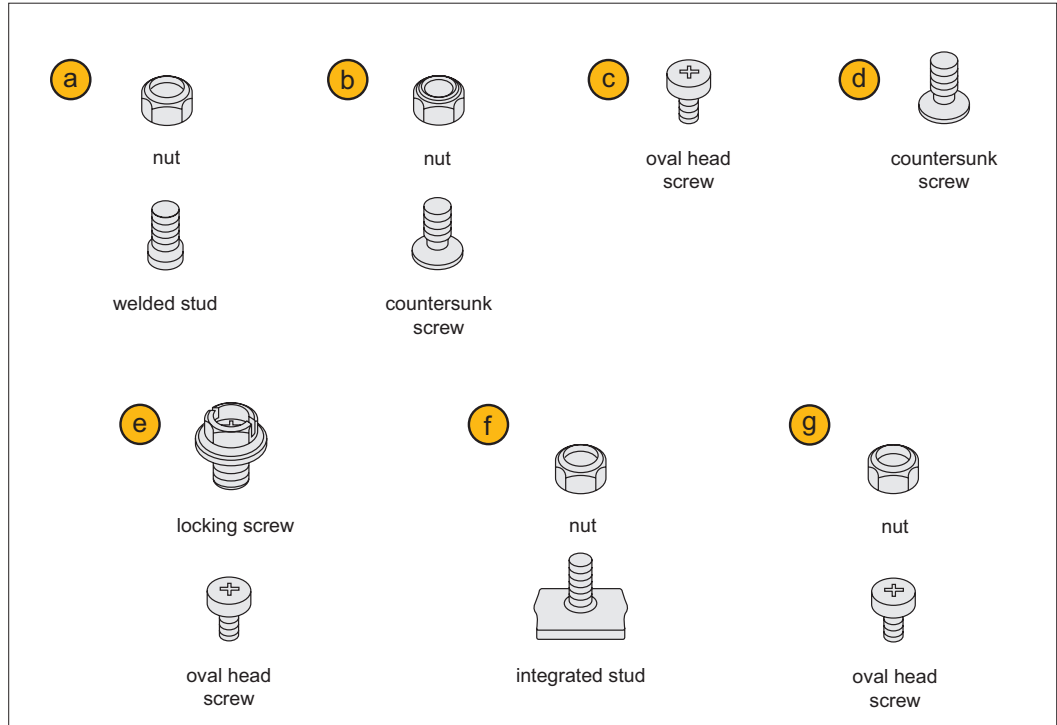

**Important Note:** Refer to individual product pages for suitable mounting options. If you have any problems please contact our Technical Sales Team.

#### Mounting example

In the example, mounting option ②, a nut with a countersunk screw, is used to mount the hinge onto the enclosure body.

