
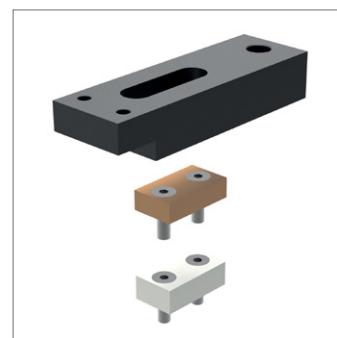


Adjustable Plain Clamps

Standard Manual Clamp-

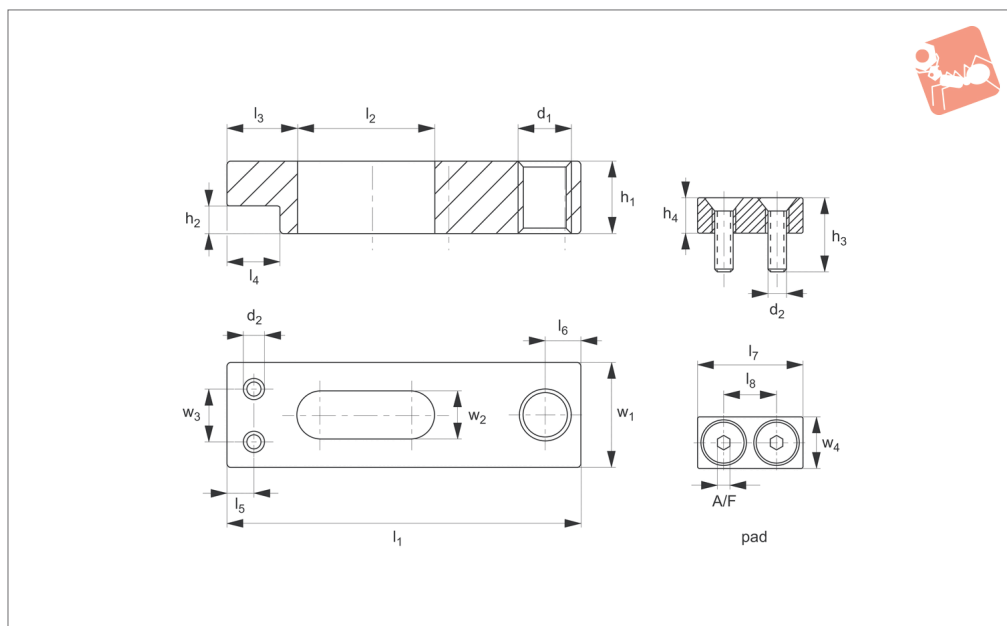

10425

STANDARD MANUAL CLAMPING

Material

Clamp: steel, heat-treated and blackened.
Pads: brass or plastic.

Technical Notes

Clamp provided without clamping pads.

Mounting screws included with clamping pads.

Temperature should not exceed 250°C when using brass pad, or 0-50°C when using plastic pad.

Tips

Particularly suitable for clamping sensitive components; soft pads protect the work-piece.

Order No.	Type	d ₁	d ₂	h ₁	h ₂	h ₃	h ₄	Weight g
10425.W0050	Clamp only	M 6	M 2	8	3	-	-	25
10425.W0051	Clamp only	M 6	M 2,5	10	4	-	-	45
10425.W0052	Clamp only	M 8	M 3	12	4	-	-	85
10425.W0053	Clamp only	M10	M 4	16	6	-	-	180
10425.W0054	Clamp only	M12	M 5	20	8	-	-	363
10425.W0055	Clamp only	M16	M 8	30	12	-	-	1445
10425.W0060	Brass pad	-	M 2	-	-	8	4	2.5
10425.W0061	Brass pad	-	M 2,5	-	-	10	6	7
10425.W0062	Brass pad	-	M 3	-	-	12	6	11
10425.W0063	Brass pad	-	M 4	-	-	16	9	25
10425.W0064	Brass pad	-	M 5	-	-	20	12	53
10425.W0065	Brass pad	-	M 8	-	-	30	16	193
10425.W0070	Plastic pad	-	M 2	-	-	8	4	0.7
10425.W0071	Plastic pad	-	M 2,5	-	-	10	6	1.6
10425.W0072	Plastic pad	-	M 3	-	-	12	6	2.7
10425.W0073	Plastic pad	-	M 4	-	-	16	9	6
10425.W0074	Plastic pad	-	M 5	-	-	20	12	13
10425.W0075	Plastic pad	-	M 8	-	-	30	16	48

Order No.	l ₁	l ₂	l ₃	l ₄	l ₅	l ₆	l ₇	l ₈	w ₁	w ₂	w ₃ +0.5	w ₄	A/F
10425.W0050	40	15.5	8	6	4	3.0	-	-	12	6	5.5	-	-
10425.W0051	50	22.0	10	8	5	4.0	-	-	16	9	7.0	-	-
10425.W0052	63	29.0	12	10	6	5.0	-	-	20	11	9.0	-	-
10425.W0053	80	36.0	15	13	8	6.5	-	-	25	14	11.0	-	-
10425.W0054	100	44.0	18	16	10	8.0	-	-	32	16	14.0	-	-
10425.W0055	160	63.0	30	28	16	14.0	-	-	50	30	18.0	-	-
10425.W0060	-	-	-	-	-	-	12	6	-	-	5.5	6	1.3
10425.W0061	-	-	-	-	-	-	16	9	-	-	7.0	8	1.5
10425.W0062	-	-	-	-	-	-	20	11	-	-	9.0	10	2.0
10425.W0063	-	-	-	-	-	-	25	14	-	-	11.0	13	2.5
10425.W0064	-	-	-	-	-	-	32	16	-	-	14.0	16	3.0



Order No.	l_1	l_2	l_3	l_4	l_5	l_6	l_7	l_8	w_1	w_2	w_3 +0.5	w_4	A/F
10425.W0065	-	-	-	-	-	-	50	30	-	-	18.0	28	5.0
10425.W0070	-	-	-	-	-	-	12	6	-	-	5.5	6	1.3
10425.W0071	-	-	-	-	-	-	16	9	-	-	7.0	8	1.5
10425.W0072	-	-	-	-	-	-	20	11	-	-	9.0	10	2.0
10425.W0073	-	-	-	-	-	-	25	14	-	-	11.0	13	2.5
10425.W0074	-	-	-	-	-	-	32	16	-	-	14.0	16	3.0
10425.W0075	-	-	-	-	-	-	50	30	-	-	18.0	28	5.0

