



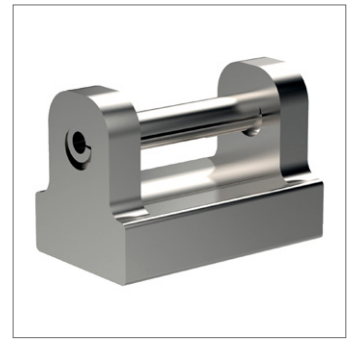

Pressure Pad

for power clamp 10588.W0022 - W0049

Standard Manual Clam-

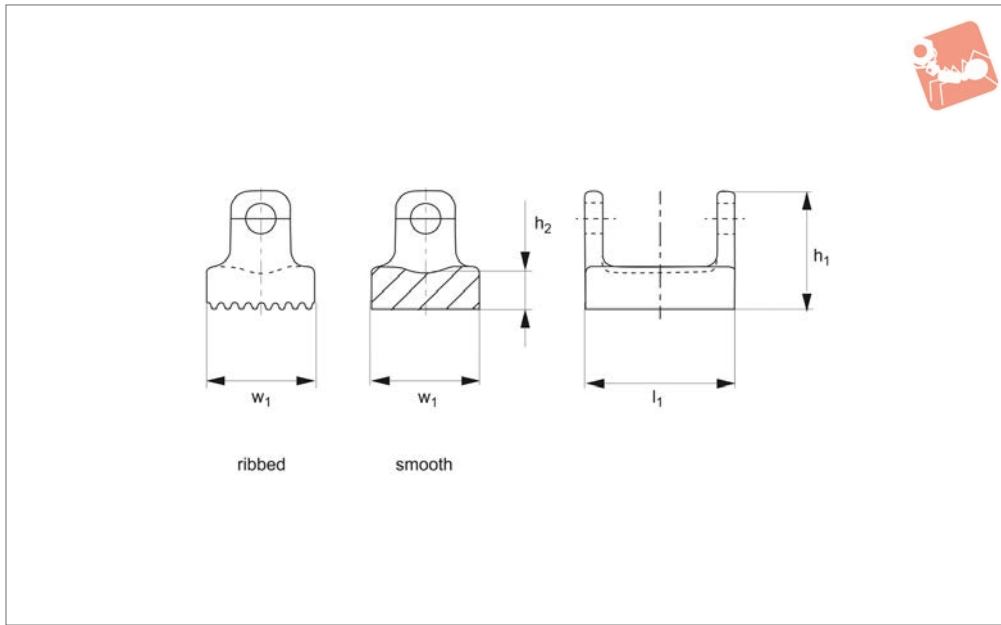

10588.6

STANDARD MANUAL CLAMPING

Material

Stainless steel.

Technical Notes

Complete with pin.

Order No.	Size	Form	h_1	h_2	l_1	w_1	Weight g
10588.W0701	22	Smooth	14.0	4.5	19	12	11
10588.W0702	30/32	Smooth	19.5	6.0	25	18	28
10588.W0703	40/43	Smooth	24.0	6.5	30	20	47
10588.W0704	49	Smooth	28.0	7.0	36	25	75
10588.W0711	22	Ribbed	14.0	4.5	19	12	10
10558.W0712	30/32	Ribbed	19.5	6.0	25	18	27
10588.W0713	40/43	Ribbed	24.0	6.5	30	20	48
10558.W0714	49	Ribbed	28.0	7.0	36	25	78