




Low Profile Toe Clamps

Low Profile Side Clamping

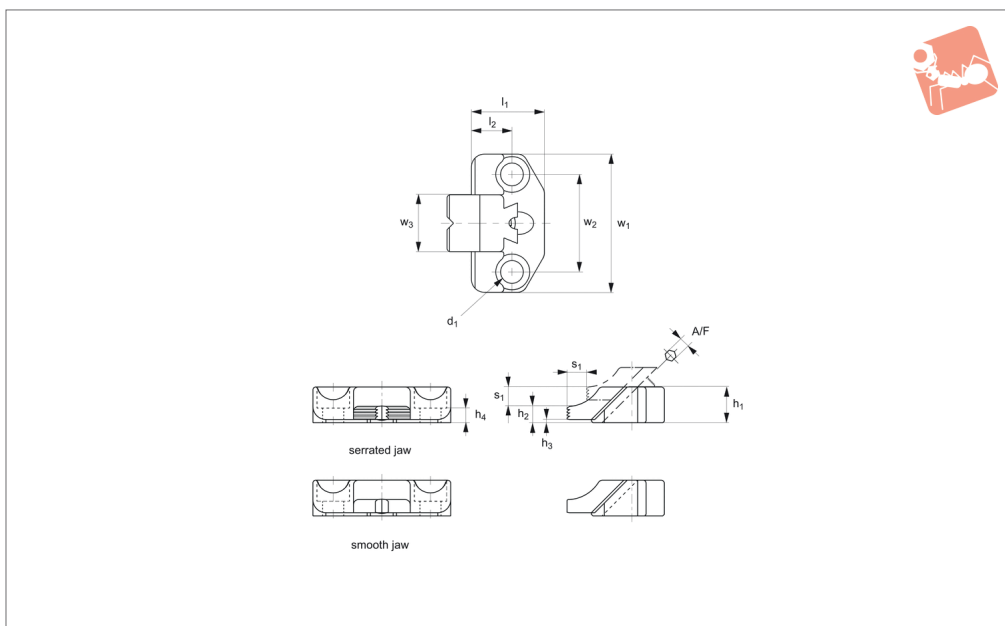

10988

LOW PROFILE SIDE CLAMPING

Material

Body: steel (42CrMo), tempered. Black oxide finish.

Jaw: steel (42CrMo), induction hardened (clamping face). Black oxide finish. Precision ground (smooth jaw).

Order No.	Type	d ₁	l ₁	l ₂	h ₁	h ₂	h ₃	h ₄	w ₁	w ₂	w ₃	Torque to Nm max.	Stroke s ₁	A/F	Clamping force kN max.	Weight g
10988.W0025	Serrated	M 8	39.5	25	16	7.5	1.5	7	65	45	25	8	7	4	4	160
10988.W0035	Serrated	M12	60.0	40	22	10.0	2.0	9	85	60	35	26	12	6	9	450
10988.W0040	Serrated	M16	77.0	50	30	14.0	2.0	13	100	70	40	60	14	8	17	900
10988.W0125	Smooth	M 8	39.5	25	16	7.5	1.5	7	65	45	25	8	7	4	4	160
10988.W0135	Smooth	M12	60.0	40	22	10.0	2.0	9	85	60	35	26	12	6	9	450
10988.W0140	Smooth	M16	77.0	50	30	14.0	2.0	13	100	70	40	60	14	8	17	900