
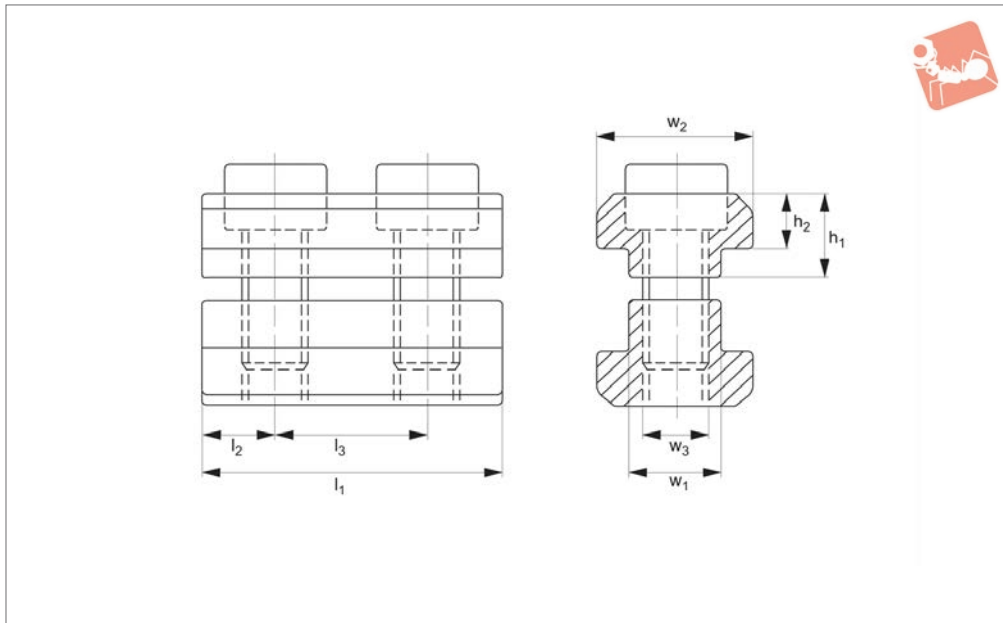


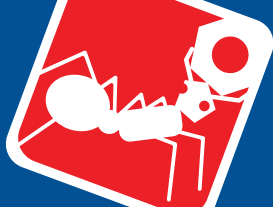

12000

LOW PROFILE SIDE CLAMPING

Material

Tempered steel, burnished.

transverse direction. Their low overall height allows use in applications with flat workpieces.

Technical Notes

The stops can be used in a longitudinal or

Order No.	Slot size	l_1	l_2	l_3	h_1	h_2	w_1	w_2	w_3	Weight g
12000.W0012	12	36	9.0	18	12	7	11.7	18	M 8	100
12000.W0014	14	44	11.0	22	12	8	13.7	22	M 8	140
12000.W0016	16	50	12.5	25	15	9	15.7	25	M12	240
12000.W0018	18	56	14.0	28	16	10	17.7	28	M12	340
12000.W0020	20	64	16.0	32	19	12	19.7	32	M16	520
12000.W0022	22	70	17.5	35	21	14	21.7	35	M16	720
12000.W0024	24	80	20.0	40	23	16	23.7	40	M20	880
12000.W0028	28	88	22.0	44	24	18	27.7	44	M20	1460