




Vice Jaw Set for Versagrip Clamps

Vice Clamping

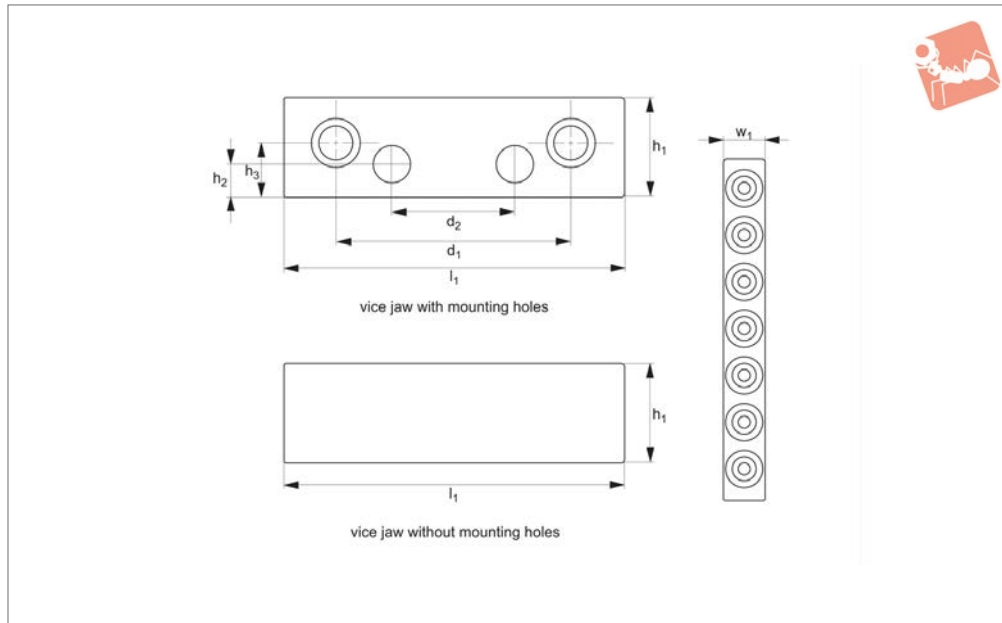

12037

VICE CLAMPING

Material

Steel, hardened (52-54 HRC).

Technical Notes

The Versagrip jaws increase the functionality of your 100 and 150mm vices. This is a simple bolt-on system that allows you to perform aggressive machining operations

whilst clamping on as little as 1,5mm for irregular shaped parts. Ideal for small batch sizes or when building a fixture is not economical.

Tips

Has penetrating teeth designed to bite into your workpiece to prevent lateral and horizontal movement. They will hold flame cut parts, castings and even parts with negative draft.

zontal movement. They will hold flame cut parts, castings and even parts with negative draft.

Important Notes

Set includes a pair of vice jaws, and four Versagrip clamps, part no. 12036.W0175.

Order No.	For vice size	Type	Jaw type	Vice jaw	Versagrip clamps	d ₁	d ₂	h ₁	h ₂	h ₃	l ₁	w ₁	Number of holes	Weight g
12037.W0015	4"/6"	Vice jaw set	With holes	2 off	4 pc 12036.W0175	98,55	63,5	47,75	23,87	17,47	150	25,4	7	2460
12037.W0020	6"	Vice jaw set	With holes	2 off	4 pc 12036.W0175	98,55		47,75	23,87		200	25,4	9	3470
12037.W0115		Vice jaw set	W/o holes	2 off	4 pc 12036.W0175			47,75			150	25,4	7	2780
12037.W0120		Vice jaw set	W/o holes	2 off	4 pc 12036.W0175			47,75			200	25,4	9	3640

