




# Locating Bush

for single clamping module 12045



## Bore Clamping

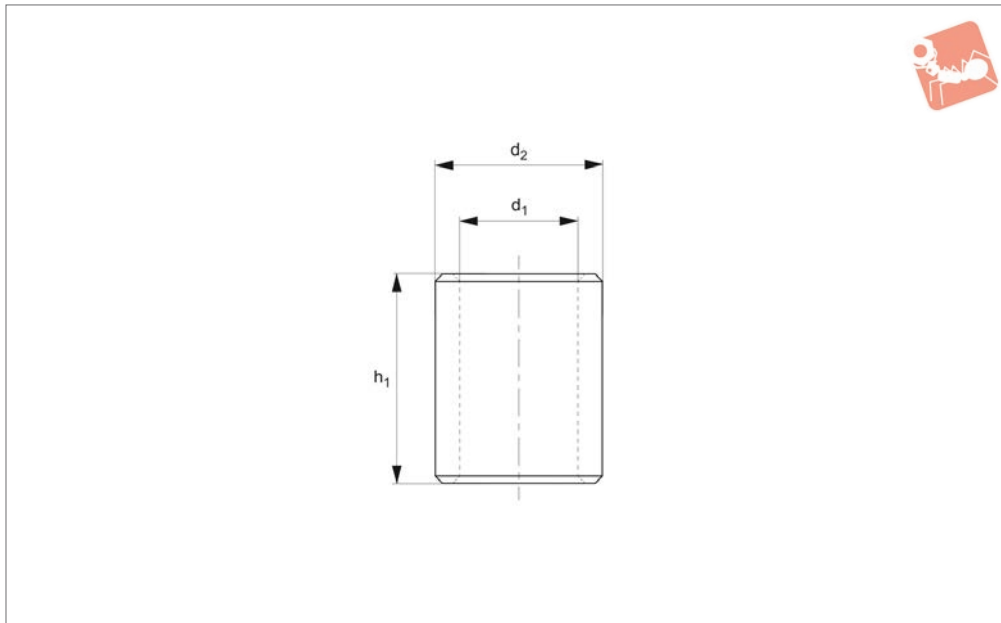

**12048.1**

BORE CLAMPING

### Material

Steel (SK95), tempered, black oxide finish, precision ground.

single clamping module (see part no. 12045) location on the fixture plate. Can achieve clamping module locating repeatability of up to 0,04mm.

### Technical Notes

Can be used to increase the accuracy of

| Order No.   | $h_1$ | Suitable clamping module 12045 | Size | $d_1$ | $d_2$<br>tol. h6 | Weight<br>g |
|-------------|-------|--------------------------------|------|-------|------------------|-------------|
| 12048.W0008 | 11    | 8                              | 8    | 6.0   | 8                | 2           |
| 12048.W0011 | 15    | 11                             | 11   | 8.5   | 12               | 7           |
| 12048.W0016 | 22    | 16                             | 16   | 12.5  | 18               | 22          |
| 12048.W0021 | 28    | 21                             | 21   | 16.5  | 22               | 35          |