




Clamping Screws - Plain standard

Bore Clamping

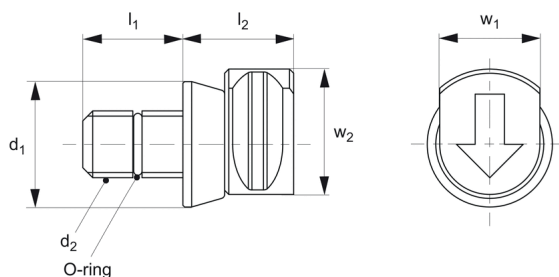

12049.4

BORE CLAMPING

Material

Bushing: steel (C45E), black oxide finish,
precision ground.

Screw: steel (SCM 435), tempered, black

oxide finish.

O-ring: nitrile rubber.

Technical Notes

For suitable clamping modules see part no.
12049.1.

Order No.	l_1	w_1	Suitable clamping module size	Type	Size	d_1	d_2	O-ring size	l_2	w_2	Weight g
12049.W0412	12	12	12	Standard	12	15	M 8x1,25	SS050 (CS1 I/D 5,0)	13,0	15,0	18
12049.W0419	18	19	19	Standard	19	24	M12x1,75	S8 (CS1,5 I/D 7,5)	21,5	23,5	69
12049.W0424	22	24	24	Standard	24	31	M16x2,00	S12 (CS 1,5 I/D 11,5)	27,0	30,0	147