



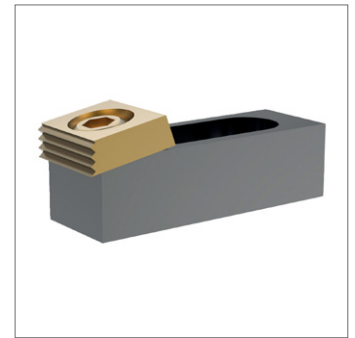

Multi-Fixture Clamps and Stops without locating step

Low Profile Side Clamping

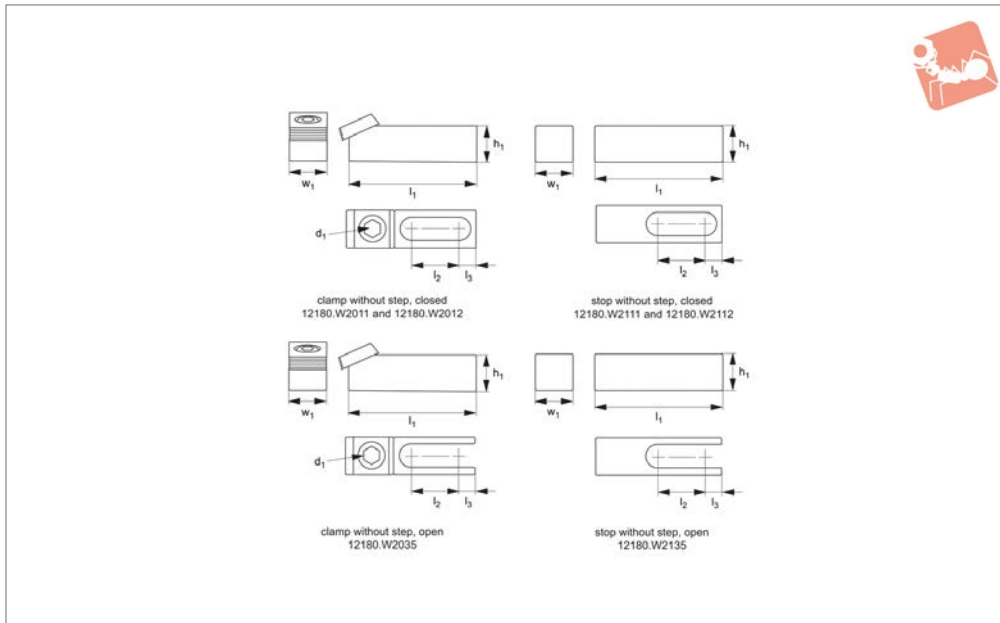

12180.2

LOW PROFILE SIDE CLAMPING

Material

Body: steel, hardened.
Clamp: brass.

threaded holes and in T-slots. Can be mounted vertically or horizontally.
Typically used as a clamp and stop pair - please order separately.

Technical Notes

Enables flexible setups. For use in both

Order No.	Type	Slot type	Mounting screw	Cam screw d_1	l_1	l_2	l_3	h_1	w_1	Torque to Stroke Nm max.	For use with	Holding force kN	
12180.W2011	Clamp - w/o Step	Closed	M 8	M 8	54,9	21,1	13,5	15,8	19,1	28	1,6	12180.W2111	8,9
12180.W2012	Clamp - w/o Step	Closed	M12	M12	58,6	42,7	12,7	15,8	28,5	88	2,0	12180.W2112	17,8
12180.W2035	Clamp - w/o Step	Open	M16	M16	96,5	46,2		41,2	38,1	135	2,5	12180.W2135	26,7
12180.W2111	Stop - w/o Step	Closed	M 8		55,9	28,2	13,5	19,1	19,1			12180.W2011	
12180.W2112	Stop - w/o Step	Closed	M12		83,5	42,7	12,7	22,1	28,5			12180.W2012	
12180.W2135	Stop - w/o Step	Open	M16		83,8	46,2		50,8	38,1			12180.W2035	

