




Standard Manual Clam-

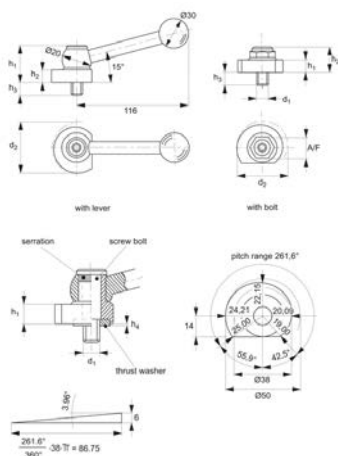

STANDARD MANUAL CLAMPING



Material

Steel Type:

Body: steel, blackened. Spiral eccentric and washer case hardened.

Screw: bolt nitrated.

Ball knob: DIN 319 black plastic, (PF31).

Stainless Steel Type:

Body: stainless steel 1.4305 (AISI 303),
nickel plated.

Screw: stainless steel 1.4021, heat-

treated, nickel plated.

Ball knob: DIN 319 black plastic, (PF31).

Technical Notes

The screw bolt and washer can be pre-set together so that the clamp can be easily rotated to any position - by means of the serrations. By removing the washer the clamp can also be used as an infinitely adjustable stop.

Tips

No. 12500 eccentric clamp, clamps from the SIDE.

Left hand acting version available on request.

No. 12520 clamping catch, clamps from ABOVE or BELOW.

Left hand acting version can be supplied on request.

Order No.	Material	d ₁	h ₁	d ₂	h ₂	h ₃	h ₄	Type	A/F	Clamping surface	Weight g
12500.W0050	Steel	M10	34.5	50	12	11	0.2	With Lever	-	Side	317
12500.W0150	Steel	M10	24.0	50	12	11	0.2	With Bolt	19	Side	159
12500.W0051	Stainless Steel	M10	34.5	50	12	11	0.2	With Lever	-	Side	317
12500.W0151	Stainless Steel	M10	25.0	50	12	11	0.2	With Bolt	19	Side	159