




Miniature Down Thrust Clamps swivelling

Adjustable Vertical Clamps

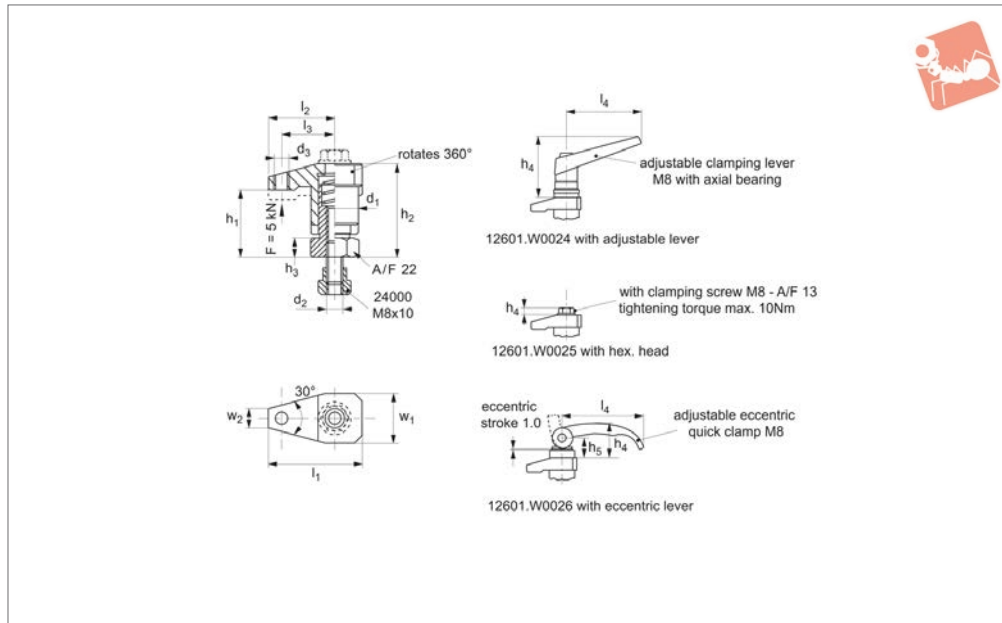

12601

ADJUSTABLE VERTICAL CLAMPS

Material

Steel case-hardened, blackened and ground.

Technical Notes

Ideally suited for clamping small

components. The 10mm wide nose allows a very small clamping footprint. For suitable self-aligning pads (if required) see no. 34100.

Tips

T-nuts can be supplied in any M8 sizes, see no. 24000.

Order No.	Type	Clamping height h_1 min.	Clamping height h_1 max.	Stroke	d_1	d_2	w_1	w_2	h_2 min.	h_2 max.	h_3	h_4	h_5	l_1	l_2	l_3	l_4	Weight g
12601.W0024	with adj. clamping lever	30	35	5	25	M8	26	10	44	49	10	60,0		49,5	35	28	74	363
12601.W0025	with hex. head	30	35	5	25	M8	26	10	44	49	10	6,9		49,5	35	28		215
12601.W0026	with ecc. clamping lever	30	35	5	25	M8	26	10	44	49	10	35,0	20,5	49,5	35	28	82	340

