




Support Stands stepless adjustment

Screw Jacks

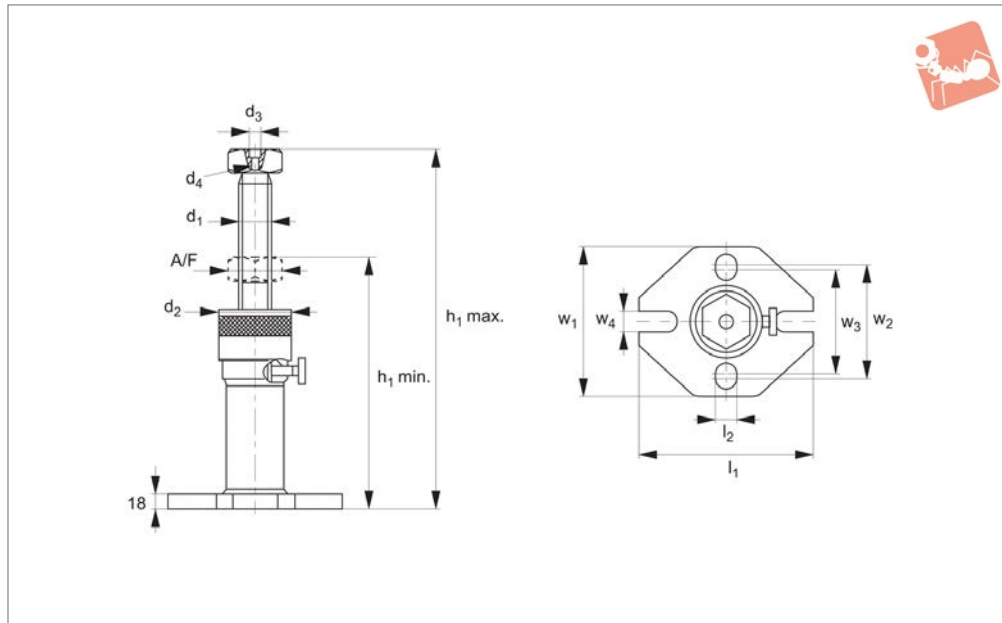

15360

SCREW JACKS

Material

Housing: steel, tempered, enamelled.
Spindle: steel, tempered, trapezoidal thread.

Technical Notes

This screw jack is designed for quick, stepless adjustment throughout its height

range.

Centering hole $\varnothing 12\text{mm}$.

See technical pages for the table of locating pad and support locating element suitability.

Tips

To adjust height, grip spindle, loosen

locking screw, twist setting ring and set required height.

Important Notes

Do not adjust screw jacks under load.

Order No.	$h_1 \text{ min.}$	$h_1 \text{ max.}$	d_1	d_2	d_3	d_4	w_1	w_2	l_1	A/F	Static load kN max.	Weight kg
15360.W0045	320	450	40x7	90	12	M10	26	190	220	65	50	11.5
15360.W0071	450	710	40x7	90	12	M10	26	190	220	65	40	13.7
15360.W0125	710	1250	40x7	90	12	M10	26	190	220	65	30	18.3