


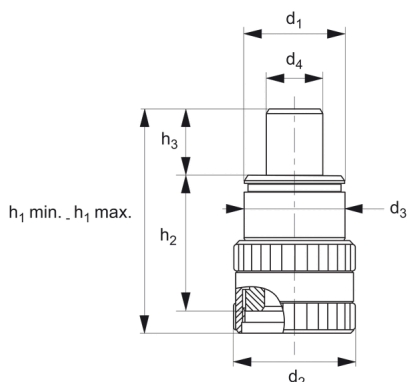

15370.2

SCREW JACKS

Material

Steel, tempered, burnished.

Technical Notes

These spacer elements are used with modular screw jacks 15370. Using the item

can allow stopless height range of up to 1620mm.

Tips

Can be used with other elements to achieve heights of up to 1.6 metres, with a max.

load of 60 kN. Observe possible buckling loads.

Do not adjust screw jacks under load.

Order No.	h_1 min.	h_1 max.	h_2	h_3	d_1	d_2	d_3	d_4	Weight g
15370.W0116	150	166.5	100	50	M76x3	89	75	42.5	3132
15370.W0126	250	266.5	200	50	M76x3	89	75	42.5	6228
15370.W0135	350	366.5	300	50	M76x3	89	75	42.5	7493



With the modular screw jack your production becomes even more flexible and economical. When combined you can achieve a maximum height of 1620mm.

Benefits

- Maximum height of 1620mm.
- Quick set-up time.

The Elements

- 1 Bearing pads, 15374.W0075, 15374.W0175, 15374.W0275
- 2 Screw jack, 15370.W0040, 15372.W0023
- 3 Spacer, 15370.W0116, 15370.W0126, 15370.W0135
- 4 Base, 15370.W0236, 15370.W0356, 15370.W0456
- 5 Thread adapter 15374.W0016, 15374.W0020, 15374.W0024

