


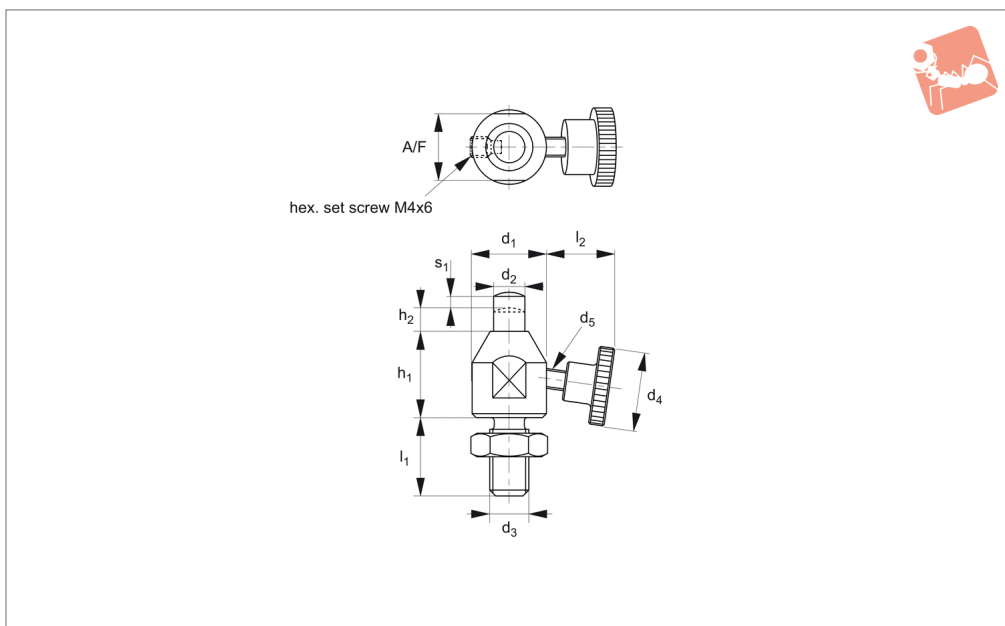

17005.1

SUPPORTS & STOPS

Material

oxide finish.

Body: steel (C45), black oxide finish.

Piston: steel (42CrMo), heat treated, black

Order No.	h_1	h_2	d_1	d_2	d_3	d_4	d_5	l_1	l_2	Piston spring force N	Stroke s_1	Support capacity kN	A/F	Weight g
17005.W0018	18	5	15	6	M 8x1,25	16	M 4x16	16	13,2	1,5~3,0	3	0,2	13	36
17005.W0022	22	6	19	8	M10x1,50	20	M 5x20	20	16,3	1,8~3,0	4	0,3	17	72
17005.W0025	25	6	22	10	M12x1,75	24	M 6x25	24	22,3	1,8~3,0	4	0,4	19	150

