




Set of Parallel Pairs in wooden case

Supports & Stops

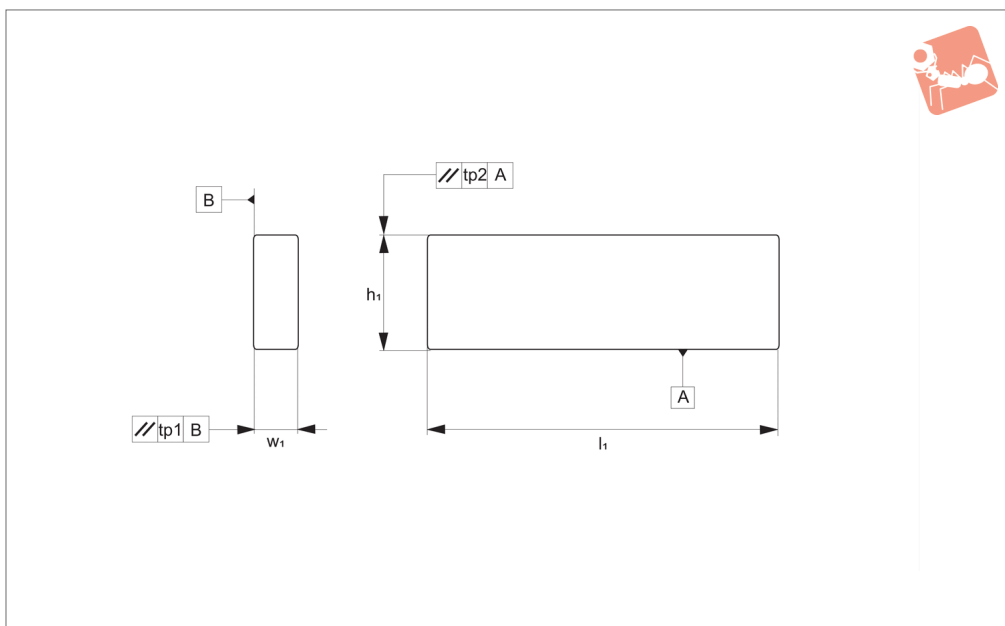

17120

SUPPORTS & STOPS

Material

Steel, case hardened and precision ground.
In wooden box with removable lid.

Tolerances:

h_1 (height) pair tolerance tp2 = to IT5.
 w_1 (width) pair tolerance tp1 = to IT5.
Other dimensions to ISO 2768m.

Technical Notes

Produced to DIN 6346S.

Order No.	Support height in 1 mm increments	1 pair $L = 250\text{mm}$ $h_1 \times w_1$	1 pair $l_2 = 100\text{mm}$ $h_1 \times w_1$	1 pair $l_2 = 160\text{mm}$ $h_1 \times w_1$	1 pair $l_2 = 63\text{mm}$ $h_1 \times w_1$	Wooden box $l_1 \times w_1$	Weight g
17120.W0025	2,5-25		12x4,0 16x5,0 20x6,3 25x8,0		8x2,5 10x3,2 12x4,0 16x5,0 20x6,3	200x100x36	1300
17120.W0040	4,0-40		12x4,0 16x5,0 20x6,3 25x8,0	25x8,0 32x10,0 40x12,0		305x115x50	3800
17120.W0063	8,0-63		25x8,0 32x10,0 40x12,0	50x16,0 63x20,0		305x115x70	7400
17120.W0100	20,0-100	63x20 80x25 100x32				280x215x125	27100
17120.W0532	4,0-32		12x4,0 16x5,0 20x6,3 25x8,0 32x10,0			132x145x50	1500
17120.W0550	8,0-50			25x8,0 32x10,0 40x12,0 50x16,0		192x158x75	4900