




Parallel Support Pairs - Set

high precision - in wooden stand



Supports & Stops

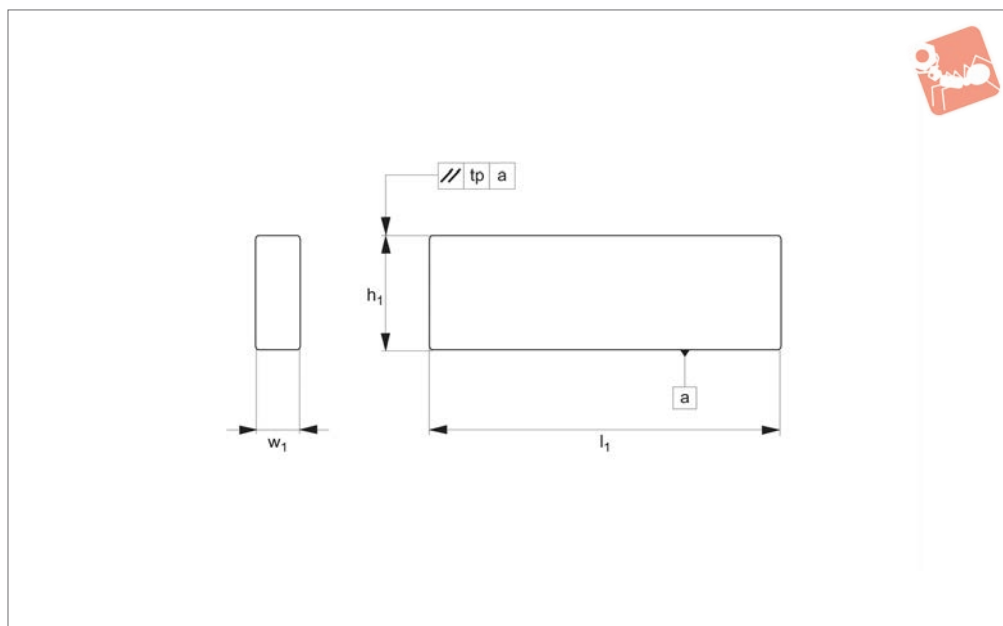

17211

SUPPORTS & STOPS

Material

Steel, case-hardened and finely ground in pairs.

Technical Notes

Machined in parallel and square. Set incre-

ments are 1mm.

Super high precision version. For standard precision model, (see part no 17200 for full tolerances).

Tolerances:

h_1 (height) pair tolerance $tp =$ to IT5.

h_1 (height) and w_1 (width) standard (single) tolerance $\pm 0,01$ mm.

All other dimensions to DIN ISO 2768m.

Order No.	Contents (1 pair each) $w_1 \times h_1 \times l_1$	Support height in 1 mm increments	Tolerance h_1 and w_1 mm	Weight g
17211.W0001	2x5x100 2x10x100	2-24	$\pm 0,01$	2200
	2x15x100 2x20x100			
	3x6x100 3x11x100			
	3x16x100 3x21x100			
	4x7x100 4x12x100			
17211.W0002	8x11x125 8x16x125	8-42	$\pm 0,01$	14000
	8x21x125 8x26x125			
	8x31x125 8x36x125			
	10x13x125 10x18x125			
	10x23x125 10x28x125			
17211.W0003	8x11x150 8x16x150	8-42	$\pm 0,01$	17000
	8x21x150 8x26x150			
	8x31x150 8x36x150			
	10x13x150 10x18x150			
	10x23x150 10x28x150			