


Parallel Support Pairs - Set standard precision - in wooden stand

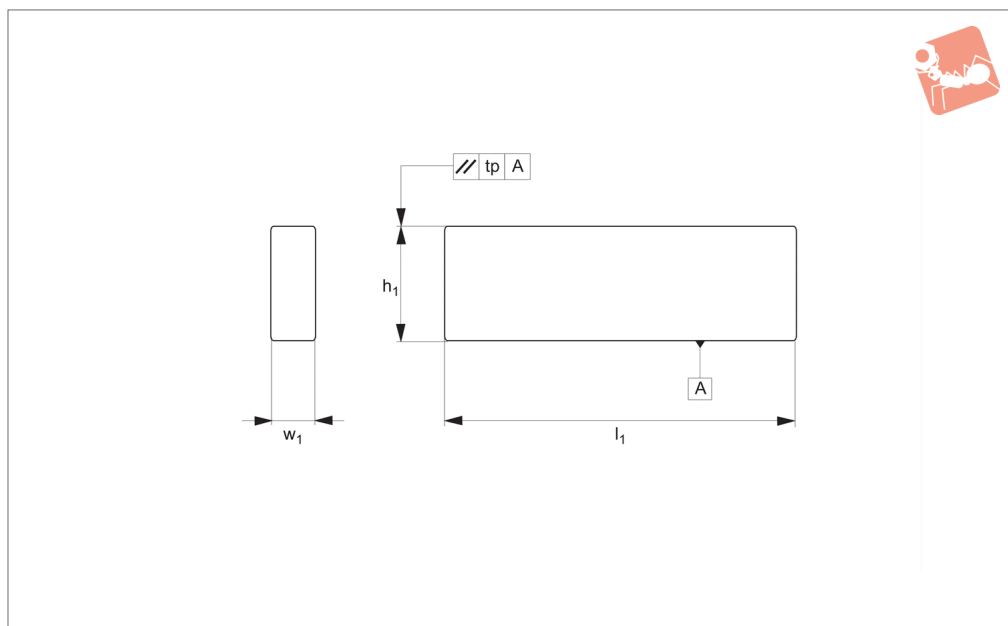

Supports & Stops



17212

SUPPORTS & STOPS

Material

Steel, case hardened and finely ground in pairs.

Technical Notes

Machined in parallel and square. Set incre-

ments are 1mm.

Standard precision version (see part no. 17200 for full tolerances). For high precision model, see parts 17211.

Tolerances:

h_1 (height) pair tolerance $tp =$ to ITS.

h_1 (height) and w_1 (width) standard (single) tolerance to DIN ISO 2768m.

All other dimensions to DIN ISO 2768m.

Order No.	Contents (1 pair each) $w_1 \times h_1 \times l_1$	Support height in 1 mm increments	Weight g
17212.W0201	2x5x100 2x10x100 2x15x100 2x20x100 3x6x100 3x11x100 3x16x100 3x21x100 4x7x100 4x12x100	2-24	2200
17212.W0202	8x11x125 8x16x125 8x21x125 8x26x125 8x31x125 8x36x125 10x13x125 10x18x125 10x23x125 10x28x125	8-42	14000
17212.W0203	8x11x150 8x16x150 8x21x150 8x26x150 8x31x150 8x36x150 10x13x150 10x18x150 10x23x150 10x28x150	8-42	17000