




Parallel Support Pairs - Set in wooden case

Supports & Stops

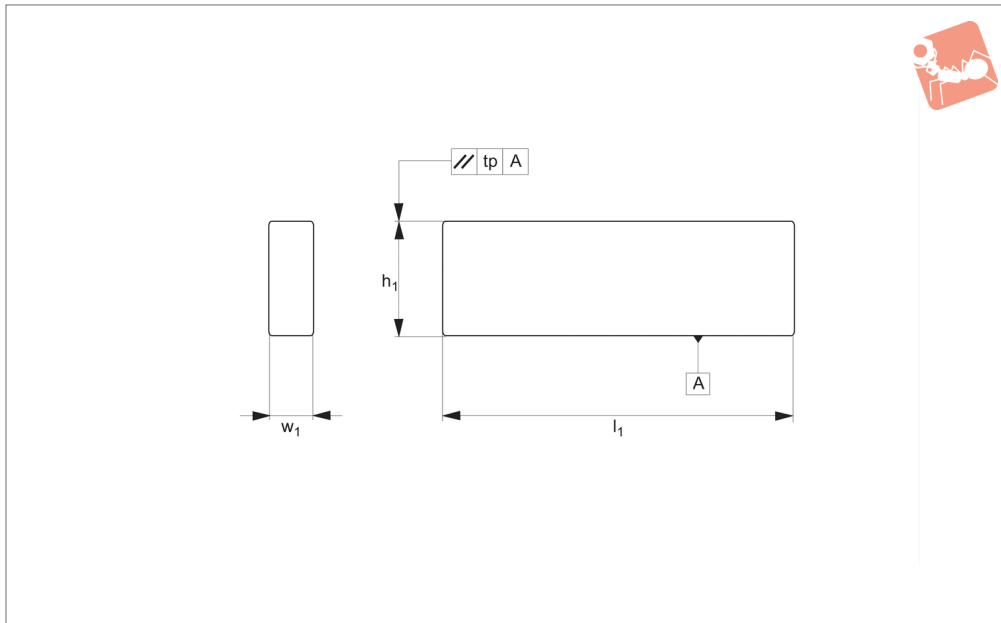

17220

SUPPORTS & STOPS

Material

Steel, ground and case-hardened.
In wooden box with removable lid.

Technical Notes

Dimensions w_1 and l_1 to ISO 2768 medium.
Tolerances - 17220.W0001 (super high precision).
 h_1 (height) pair tolerance $tp = 0,004\text{mm}$.
 h_1 (height) standard tolerance $tp = \pm 0,004\text{mm}$.

Other dimensions to DIN ISO 2768m.

Tolerances - 17220.W0000 (standard precision).
 h_1 (height) pair tolerance $tp = 0,010\text{mm}$.
 h_1 (height) standard tolerance $tp = \pm 0,004\text{mm}$.

Tips

Indispensable for parallel support of components in vices and plates. Their high

degree of accuracy allows the combination of sizes.

Part no. 17220.W0000 is exactly the same as 17220.W0001, but is a lower cost, and lower toleranced set.

Matched sets can be supplied on request for an extra charge.

Order No.	Contents (pairs) $h_1 \times w_1 \times l_1$	h_1 Standard tolerance	h_1 - Pair tolerance tp	Weight g
17220.W0001	14x10x150	$\pm 0,004$	$\pm 0,004$	10900
	16x10x150			
	18x10x150			
	20x10x150			
	22x10x150			
17220.W0000	as per 17220.W0001 but with lower tolerances	$\pm 0,2$ (to 30mm) $\pm 0,3$ (>30mm)	$\pm 0,010$	10600