

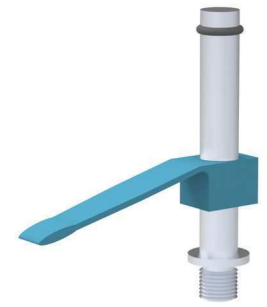


Soft Touch Clamps

for CMM fixturing

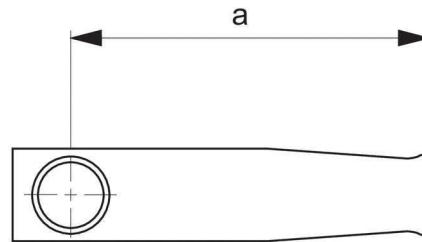

19320

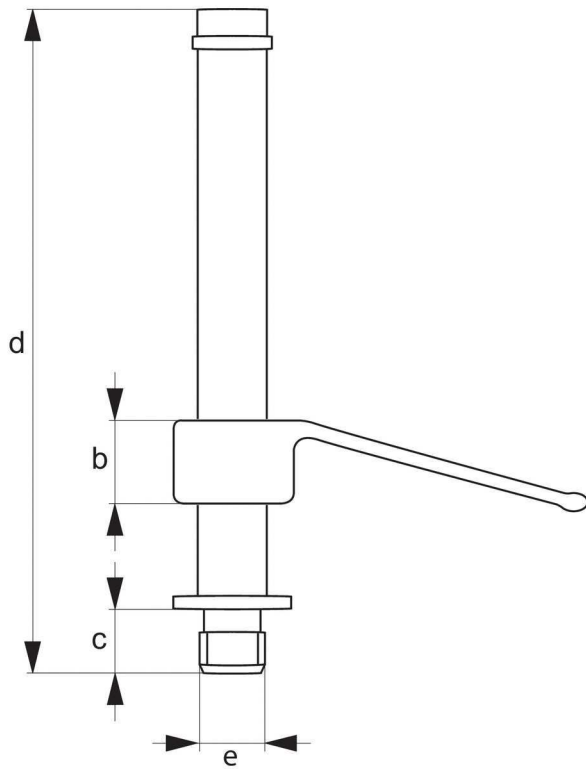

Material
Aluminium.

Technical Notes
For fixturing on CMMs only. Not recommended for machining.

Tips
Optional rubber coated tip helps prevent marring of parts during inspection.

Important Notes
Ideal for light pressure clamping.



Order No.	Type	a	b	c	d	e
19320.W0008	Standard	39,0	8	6,37	75	M 8
19320.W0012	Standard	58,7	12	6,37	75	M 8
19320.W0108	Rubber Coated Tip	39,0	8	6,37	75	M 8
19320.W0112	Rubber Coated Tip	58,7	12	6,37	75	M 8



Wixroyd's CMM fixturing system is designed for easy assembly and high repeatability, eliminating the need to build dedicated fixtures. The system offers a highly accurate and flexible solution of holding parts while probing.

Flexible

A variety of component parts as well as kits are available, to enable setup of fixtures in minutes.

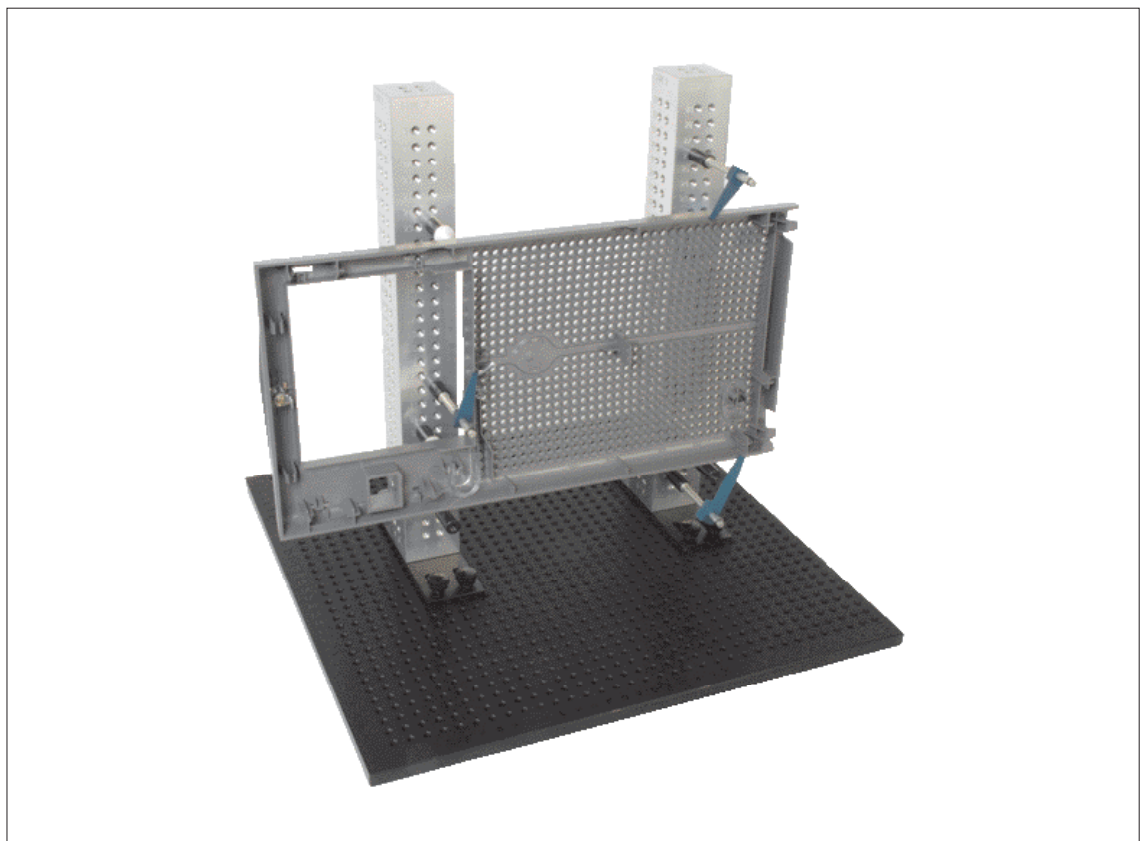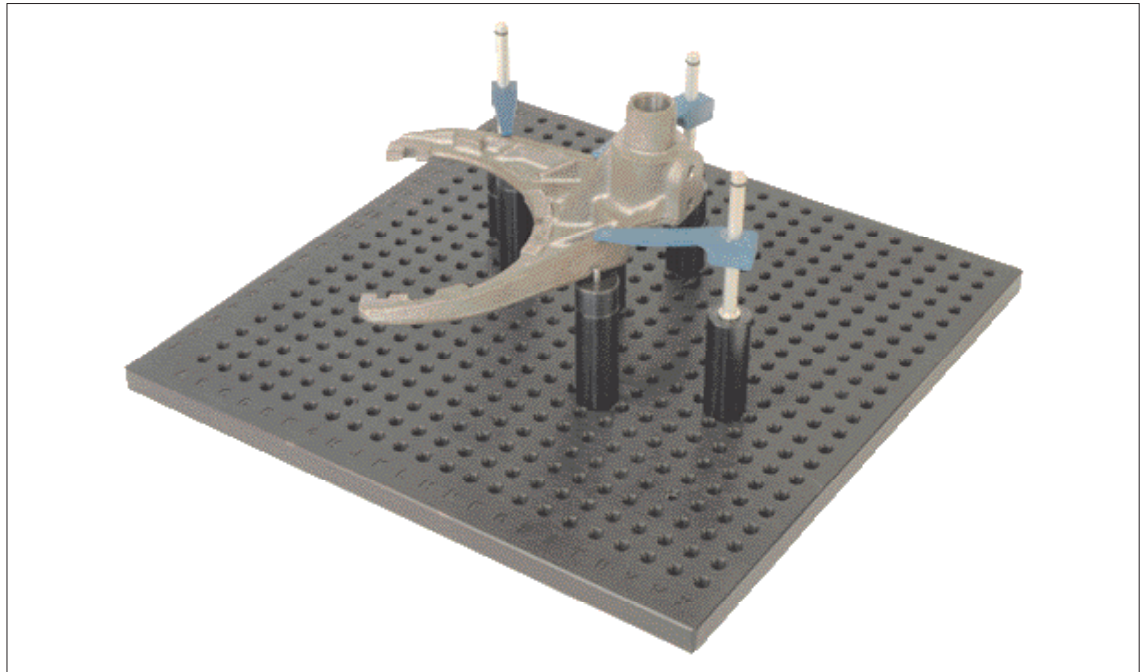

- Aluminium base plates – hole based system with alpha numeric labelling for easy set-up and recording of fixtures.
- Fixture towers – ideal for fixturing of large vertical components.
- Soft-touch clamps – non marking clamps providing the ideal force for holding parts during SMM probing.
- Locating components – rest pads, vee pads for cylindrical parts, pin rests etc.