




# T- Slot Base Plate rectangular

## Base Plates & Clamping

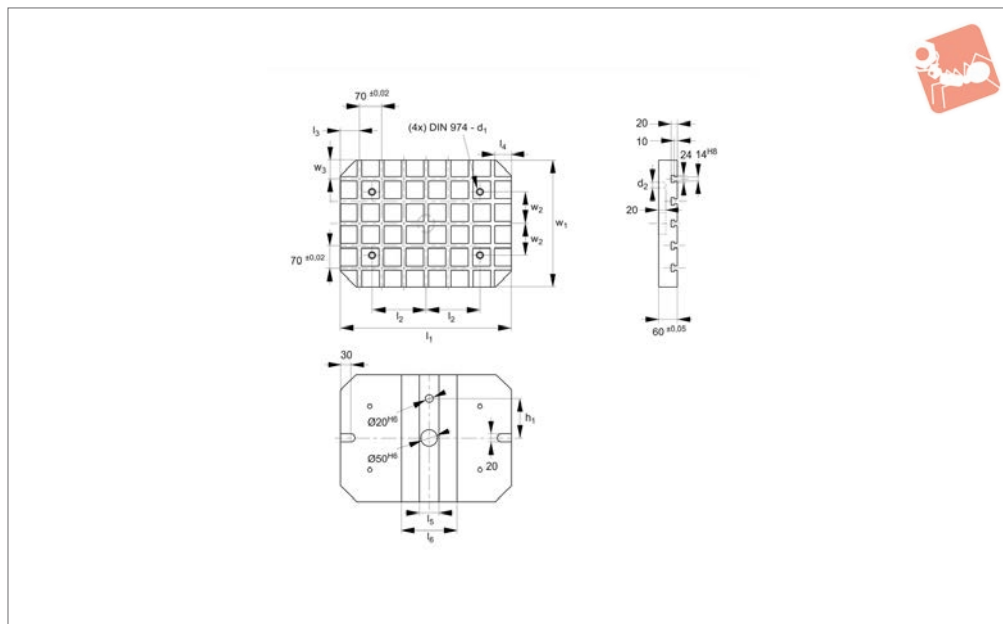

# 19584

BASE PLATES & CLAMPING ANGLES

### Material

High tensile tool steel.

Order No.	$w_1 \times l_1$	$w_2$ $\pm 0.2$	$w_3$ $\pm 0.02$	$l_2$ $\pm 0.2$	$l_3$ $\pm 0.02$	$l_4$	$l_5$	$l_6$	$h_1$ $\pm 0.013$	$d_1$	$d_2$	Number of T-slots	Weight kg
<b>19584.W0300</b>	400x500	100	60	200	40	50	70	310	150	12	20	5x7	77
<b>19584.W0500</b>	500x630	200	40	200	35	60	70	340	200	12	20	7x9	120