




8 Station Vice - ReLock 8 converts a double to single station vice

Vice Clamping

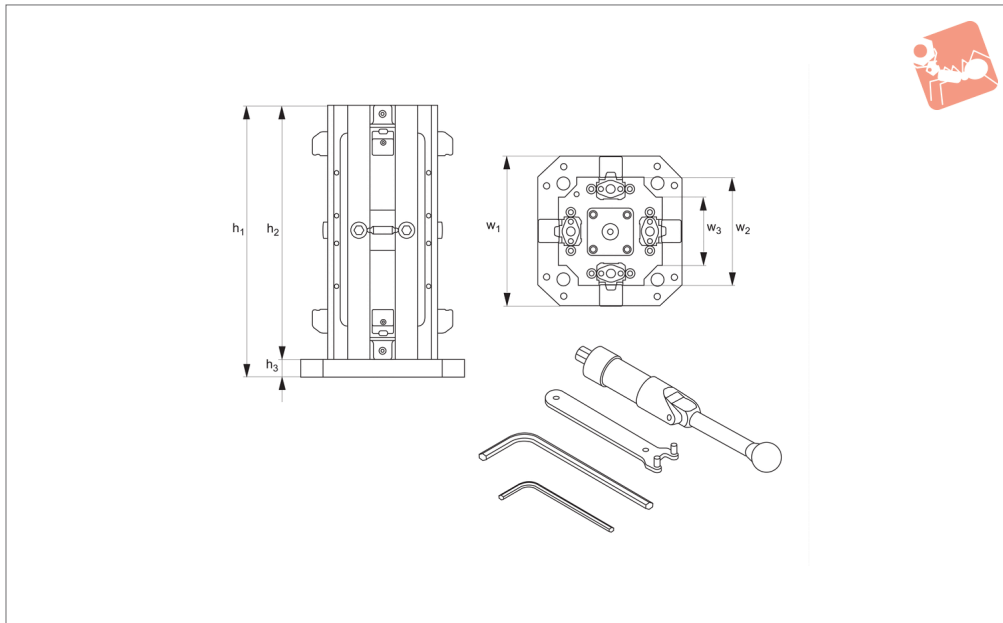

19762

VICE CLAMPING

Material

Body: 80000 PSI ductile cast iron.
Sideways flame hardened to 40 HRC max.

Technical Notes

Vice jaws not included, order separately.
See part no. 19790.
Jaw capacity dependent upon selection of
either machinable or hard jaws. See tech-

nical pages.
Replacement parts available.

Tips

Supplied with actuation handle, hex key
and wrench.
Base plate designed to adapt to wide range
of machine tables.
8-station vice columns can be located on a

pallet using edge location with shims or
spacers (not supplied).

Important Notes

Not compatible with 19768 compact 8-vice
column.

**All dimensions are in inches unless
stated *.**

Order No.	Vice size	Clamp pressure lb max.	Base type	h_1	h_2	h_3	w_1	w_2 ± 0.001	w_3	Weight lb
19762.W0040	4"	6000	Inch	17.90	16.75	1.15	10.75	7	4	150
19762.W0041	4"	6000	Metric	17.90	16.75	1.15	400*	7	4	150
19762.W0060	6"	12000	Inch	22.65	21.25	1.40	14.00	9	6	280
19762.W0061	6"	12000	Metric	22.65	21.25	1.40	400*	9	6	280
19762.W0080	8"	16000	Inch	31.10	29.50	1.60	18.00	12	8	750