


Lifting Pins-Self-Locking with t-handle - stainless steel

Quick Lift Pins

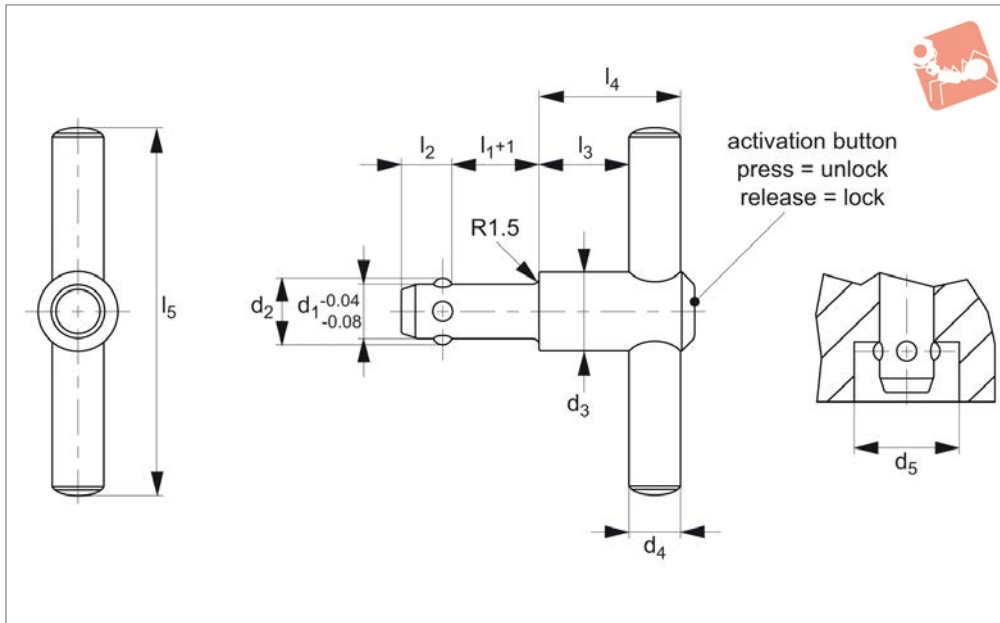

33424

QUICK LIFT PINS

Material

Pin: Stainless steel 1.4542, (AISI 630)
precipitation hardened.

Handle: Aluminium, blue anodised

Spring: Stainless Steel

Releasing= Locking.

Easy installation with plain drilled hole to
H11 tolerance

Temperature resistance up to 250° C

finished components, work holding
systems, speakers and other containers.
Corrosion and weathering resistant, thus
also suitable for outdoor application.

Technical Notes

Pressing= Unlocking.

Tips

The t-handled grip can be used to move or
transport workpieces via hand, e.g. part

Order No.	d_1 -0.04 -0.08	l_1 +1	d_2	d_3	d_4	d_5 min.	l_2	l_3	l_4	l_5	Carrying force N	Location hole tol. H11	Weight g
33424.W0005	8.0	35	9.35	21.5	14	9.85	8.75	18.7	36.0	100	500	8.0	141
33424.W0010	8.3	35	9.65	21.5	14	10.05	8.75	18.7	36.0	100	500	8.3	142
33424.W0015	10.0	50	11.70	21.5	14	12.20	10.20	18.7	36.5	100	500	10.0	159
33424.W0020	12.0	50	14.20	21.5	14	14.70	11.00	18.7	36.5	100	500	12.0	177

