


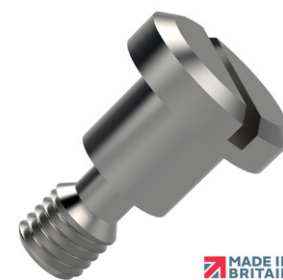

Pan Head Shoulder Screws

steel, zinc-plated


Shoulder Screws



MADE IN
BRITAIN

33656.ZP

SHOULDER SCREWS

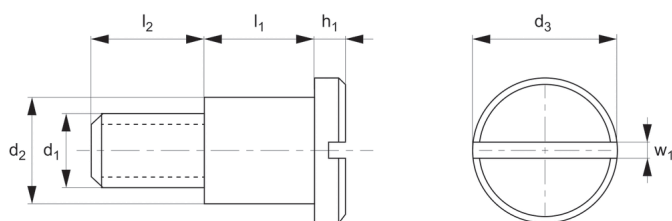

Material

Steel, zinc-plated.

Technical Notes

To DIN 923.

Order No.	d ₁	l ₁	d ₂ tol. h9	d ₃	h ₁	l ₂	w ₁
33656.W2002-ZP	M 2	2	2.8	4.5	1.2	3.0	0.5
33656.W2003-ZP	M 2	3	2.8	4.5	1.2	3.0	0.5
33656.W2004-ZP	M 2	4	2.8	4.5	1.2	3.0	0.5
33656.W2005-ZP	M 2	5	2.8	4.5	1.2	3.0	0.5
33656.W2006-ZP	M 2	6	2.8	4.5	1.2	3.0	0.5
33656.W2008-ZP	M 2	8	2.8	4.5	1.2	3.0	0.5
33656.W2012-ZP	M 2	12	2.8	4.5	1.2	3.0	0.5
33656.W2503-ZP	M 2.5	3	2.8	4.5	1.2	3.0	0.5
33656.W2504-ZP	M 2.5	4	2.8	4.5	1.2	3.0	0.5
33656.W2505-ZP	M 2.5	5	2.8	4.5	1.2	3.0	0.5
33656.W2506-ZP	M 2.5	6	2.8	4.5	1.2	3.0	0.5
33656.W2508-ZP	M 2.5	8	2.8	4.5	1.2	3.0	0.5
33656.W3001-ZP	M 3	1	4.0	7.0	1.8	4.5	0.8
33656.W3002-ZP	M 3	2	4.0	7.0	1.8	4.5	0.8
33656.W3003-ZP	M 3	3	4.0	7.0	1.8	4.5	0.8
33656.W3004-ZP	M 3	4	4.0	7.0	1.8	4.5	0.8
33656.W3005-ZP	M 3	5	4.0	7.0	1.8	4.5	0.8
33656.W3006-ZP	M 3	6	4.0	7.0	1.8	4.5	0.8
33656.W3008-ZP	M 3	8	4.0	7.0	1.8	4.5	0.8
33656.W3010-ZP	M 3	10	4.0	7.0	1.8	4.5	0.8
33656.W3012-ZP	M 3	12	4.0	7.0	1.8	4.5	0.8
33656.W3016-ZP	M 3	16	4.0	7.0	1.8	4.5	0.8
33656.W3030-ZP	M 3	30	4.0	7.0	1.8	4.5	0.8
33656.W4002-ZP	M 4	2	5.5	8.5	2.4	6.0	1.0
33656.W4003-ZP	M 4	3	5.5	8.5	2.4	6.0	1.0
33656.W4004-ZP	M 4	4	5.5	8.5	2.4	6.0	1.0
33656.W4005-ZP	M 4	5	5.5	8.5	2.4	6.0	1.0
33656.W4006-ZP	M 4	6	5.5	8.5	2.4	6.0	1.0
33656.W4008-ZP	M 4	8	5.5	8.5	2.4	6.0	1.0
33656.W4010-ZP	M 4	10	5.5	8.5	2.4	6.0	1.0
33656.W4012-ZP	M 4	12	5.5	8.5	2.4	6.0	1.0
33656.W4016-ZP	M 4	16	5.5	8.5	2.4	6.0	1.0
33656.W4020-ZP	M 4	20	5.5	8.5	2.4	6.0	1.0
33656.W4030-ZP	M 4	30	5.5	8.5	2.4	6.0	1.0



Order No.	d ₁	l ₁	d ₂ tol. h9	d ₃	h ₁	l ₂	w ₁
33656.W5002-ZP	M 5	2	7.0	11.0	2.7	7.0	1.2
33656.W5003-ZP	M 5	3	7.0	11.0	2.7	7.0	1.2
33656.W5004-ZP	M 5	4	7.0	11.0	2.7	7.0	1.2
33656.W5005-ZP	M 5	5	7.0	11.0	2.7	7.0	1.2
33656.W5006-ZP	M 5	6	7.0	11.0	2.7	7.0	1.2
33656.W5008-ZP	M 5	8	7.0	11.0	2.7	7.0	1.2
33656.W5010-ZP	M 5	10	7.0	11.0	2.7	7.0	1.2
33656.W5012-ZP	M 5	12	7.0	11.0	2.7	7.0	1.2
33656.W5016-ZP	M 5	16	7.0	11.0	2.7	7.0	1.2
33656.W5020-ZP	M 5	20	7.0	11.0	2.7	7.0	1.2
33656.W5025-ZP	M 5	25	7.0	11.0	2.7	7.0	1.2
33656.W6002-ZP	M 6	2	8.0	13.0	3.1	9.0	1.6
33656.W6003-ZP	M 6	3	8.0	13.0	3.1	9.0	1.6
33656.W6004-ZP	M 6	4	8.0	13.0	3.1	9.0	1.6
33656.W6005-ZP	M 6	5	8.0	13.0	3.1	9.0	1.6
33656.W6006-ZP	M 6	6	8.0	13.0	3.1	9.0	1.6
33656.W6008-ZP	M 6	8	8.0	13.0	3.1	9.0	1.6
33656.W6010-ZP	M 6	10	8.0	13.0	3.1	9.0	1.6
33656.W6012-ZP	M 6	12	8.0	13.0	3.1	9.0	1.6
33656.W6016-ZP	M 6	16	8.0	13.0	3.1	9.0	1.6
33656.W6020-ZP	M 6	16	8.0	13.0	3.1	9.0	1.6
33656.W6025-ZP	M 6	25	8.0	13.0	3.1	9.0	1.6
33656.W8004-ZP	M 8	4	10.0	16.0	3.8	11.0	2.0
33656.W8005-ZP	M 8	5	10.0	16.0	3.8	11.0	2.0
33656.W8006-ZP	M 8	6	10.0	16.0	3.8	11.0	2.0
33656.W8008-ZP	M 8	8	10.0	16.0	3.8	11.0	2.0
33656.W8010-ZP	M 8	10	10.0	16.0	3.8	11.0	2.0
33656.W8012-ZP	M 8	12	10.0	16.0	3.8	11.0	2.0
33656.W8016-ZP	M 8	16	10.0	16.0	3.8	11.0	2.0
33656.W8020-ZP	M 8	20	10.0	16.0	3.8	11.0	2.0
33656.W8025-ZP	M 8	25	10.0	16.0	3.8	11.0	2.0
33656.W0005-ZP	M 10	5	13.0	20.0	4.6	13.5	2.5
33656.W0006-ZP	M 10	6	13.0	20.0	4.6	13.5	2.5
33656.W0008-ZP	M 10	8	13.0	20.0	4.6	13.5	2.5
33656.W0010-ZP	M 10	10	13.0	20.0	4.6	13.5	2.5
33656.W0012-ZP	M 10	12	13.0	20.0	4.6	13.5	2.5
33656.W0016-ZP	M 10	16	13.0	20.0	4.6	13.5	2.5
33656.W0020-ZP	M 10	20	13.0	20.0	4.6	13.5	2.5
33656.W0025-ZP	M 10	25	13.0	20.0	4.6	13.5	2.5