


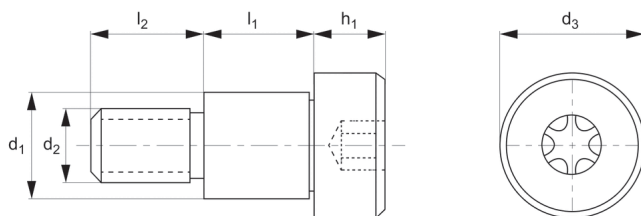

Shoulder Screws - Cap Head

TX drive - 303 stainless

Shoulder Screws



MADE IN
BRITAIN

33658.A2

SHOULDER SCREWS

Material

Stainless steel (AISI 303, 1.4305).
Tensile strength 550 N/mm².
Proof stress min. 190 N/mm², austenitic

stainless steel.

Technical Notes

303 series stainless steel provides good

resistance to corrosion. It is mildly magnetic.

Order No.	d ₁ +0.0 -0.025	l ₁ +0.05 -0.0	d ₂	d ₃	l ₂	h ₁	TX size
33658.W0402-A2	4	2	M 3	6	4	3	TX-10
33658.W0403-A2	4	3	M 3	6	4	3	TX-10
33658.W0404-A2	4	4	M 3	6	4	3	TX-10
33658.W0405-A2	4	5	M 3	6	4	3	TX-10
33658.W0406-A2	4	6	M 3	6	4	3	TX-10
33658.W0407-A2	4	7	M 3	6	4	3	TX-10
33658.W0408-A2	4	8	M 3	6	4	3	TX-10
33658.W0410-A2	4	10	M 3	6	4	3	TX-10
33658.W0412-A2	4	12	M 3	6	4	3	TX-10
33658.W0414-A2	4	14	M 3	6	4	3	TX-10
33658.W0416-A2	4	16	M 3	6	4	3	TX-10
33658.W0418-A2	4	18	M 3	6	4	3	TX-10
33658.W0420-A2	4	20	M 3	6	4	3	TX-10
33658.W0425-A2	4	25	M 3	6	4	3	TX-10
33658.W0430-A2	4	30	M 3	6	4	3	TX-10
33658.W0435-A2	4	35	M 3	6	4	3	TX-10
33658.W0440-A2	4	40	M 3	6	4	3	TX-10
33658.W0445-A2	4	45	M 3	6	4	3	TX-10
33658.W0450-A2	4	50	M 3	6	4	3	TX-10
33658.W0502-A2	5	2	M 4	8	5	4	TX-20
33658.W0503-A2	5	3	M 4	8	5	4	TX-20
33658.W0504-A2	5	4	M 4	8	5	4	TX-20
33658.W0505-A2	5	5	M 4	8	5	4	TX-20
33658.W0506-A2	5	6	M 4	8	5	4	TX-20
33658.W0507-A2	5	7	M 4	8	5	4	TX-20
33658.W0508-A2	5	8	M 4	8	5	4	TX-20
33658.W0510-A2	5	10	M 4	8	5	4	TX-20
33658.W0512-A2	5	12	M 4	8	5	4	TX-20
33658.W0514-A2	5	14	M 4	8	5	4	TX-20
33658.W0516-A2	5	16	M 4	8	5	4	TX-20
33658.W0518-A2	5	18	M 4	8	5	4	TX-20
33658.W0520-A2	5	20	M 4	8	5	4	TX-20
33658.W0525-A2	5	25	M 4	8	5	4	TX-20
33658.W0530-A2	5	30	M 4	8	5	4	TX-20



Order No.	d ₁ +0.0 -0.025	l ₁ +0.05 -0.0	d ₂	d ₃	l ₂	h ₁	TX size
33658.W0535-A2	5	35	M 4	8	5	4	TX-20
33658.W0540-A2	5	40	M 4	8	5	4	TX-20
33658.W0545-A2	5	45	M 4	8	5	4	TX-20
33658.W0550-A2	5	50	M 4	8	5	4	TX-20
33658.W0602-A2	6	2	M 5	10	6	5	TX-25
33658.W0603-A2	6	3	M 5	10	6	5	TX-25
33658.W0604-A2	6	4	M 5	10	6	5	TX-25
33658.W0605-A2	6	5	M 5	10	6	5	TX-25
33658.W0606-A2	6	6	M 5	10	6	5	TX-25
33658.W0607-A2	6	7	M 5	10	6	5	TX-25
33658.W0608-A2	6	8	M 5	10	6	5	TX-25
33658.W0610-A2	6	10	M 5	10	6	5	TX-25
33658.W0612-A2	6	12	M 5	10	6	5	TX-25
33658.W0614-A2	6	14	M 5	10	6	5	TX-25
33658.W0616-A2	6	16	M 5	10	6	5	TX-25
33658.W0618-A2	6	18	M 5	10	6	5	TX-25
33658.W0620-A2	6	20	M 5	10	6	5	TX-25
33658.W0625-A2	6	25	M 5	10	6	5	TX-25
33658.W0630-A2	6	30	M 5	10	6	5	TX-25
33658.W0635-A2	6	35	M 5	10	6	5	TX-25
33658.W0640-A2	6	40	M 5	10	6	5	TX-25
33658.W0645-A2	6	45	M 5	10	6	5	TX-25
33658.W0650-A2	6	50	M 5	10	6	5	TX-25
33658.W0655-A2	6	55	M 5	10	6	5	TX-25
33658.W0660-A2	6	60	M 5	10	6	5	TX-25
33658.W0670-A2	6	70	M 5	10	6	5	TX-25
33658.W0680-A2	6	80	M 5	10	6	5	TX-25
33658.W0690-A2	6	90	M 5	10	6	5	TX-25
33658.W0600-A2	6	100	M 5	10	6	5	TX-25
33658.W0804-A2	8	4	M 6	12	11	6	TX-30
33658.W0805-A2	8	5	M 6	12	11	6	TX-30
33658.W0806-A2	8	6	M 6	12	11	6	TX-30
33658.W0807-A2	8	7	M 6	12	11	6	TX-30
33658.W0808-A2	8	8	M 6	12	11	6	TX-30
33658.W0810-A2	8	10	M 6	12	11	6	TX-30
33658.W0812-A2	8	12	M 6	12	11	6	TX-30
33658.W0814-A2	8	14	M 6	12	11	6	TX-30
33658.W0816-A2	8	16	M 6	12	11	6	TX-30
33658.W0818-A2	8	18	M 6	12	11	6	TX-30
33658.W0820-A2	8	20	M 6	12	11	6	TX-30
33658.W0825-A2	8	25	M 6	12	11	6	TX-30
33658.W0830-A2	8	30	M 6	12	11	6	TX-30
33658.W0835-A2	8	35	M 6	12	11	6	TX-30
33658.W0840-A2	8	40	M 6	12	11	6	TX-30
33658.W0845-A2	8	45	M 6	12	11	6	TX-30
33658.W0850-A2	8	50	M 6	12	11	6	TX-30
33658.W0855-A2	8	55	M 6	12	11	6	TX-30
33658.W0860-A2	8	60	M 6	12	11	6	TX-30
33658.W0865-A2	8	65	M 6	12	11	6	TX-30
33658.W0870-A2	8	70	M 6	12	11	6	TX-30
33658.W0875-A2	8	75	M 6	12	11	6	TX-30
33658.W0880-A2	8	80	M 6	12	11	6	TX-30
33658.W0890-A2	8	90	M 6	12	11	6	TX-30
33658.W0800-A2	8	100	M 6	12	11	6	TX-30
33658.W1008-A2	10	8	M 8	14	12	7	TX-45
33658.W1010-A2	10	10	M 8	14	12	7	TX-45
33658.W1012-A2	10	12	M 8	14	12	7	TX-45
33658.W1014-A2	10	14	M 8	14	12	7	TX-45
33658.W1016-A2	10	16	M 8	14	12	7	TX-45
33658.W1018-A2	10	18	M 8	14	12	7	TX-45
33658.W1020-A2	10	20	M 8	14	12	7	TX-45
33658.W1025-A2	10	25	M 8	14	12	7	TX-45
33658.W1030-A2	10	30	M 8	14	12	7	TX-45
33658.W1035-A2	10	35	M 8	14	12	7	TX-45
33658.W1040-A2	10	40	M 8	14	12	7	TX-45
33658.W1045-A2	10	45	M 8	14	12	7	TX-45
33658.W1050-A2	10	50	M 8	14	12	7	TX-45
33658.W1055-A2	10	55	M 8	14	12	7	TX-45



Shoulder Screws - Cap Head

TX drive - 303 stainless

Shoulder Screws



Order No.	d_1 +0.0 -0.025	l_1 +0.05 -0.0	d_2	d_3	l_2	h_1	TX size
33658.W1060-A2	10	60	M 8	14	12	7	TX-45
33658.W1065-A2	10	65	M 8	14	12	7	TX-45
33658.W1070-A2	10	70	M 8	14	12	7	TX-45
33658.W1080-A2	10	80	M 8	14	12	7	TX-45
33658.W1090-A2	10	90	M 8	14	12	7	TX-45
33658.W1000-A2	10	100	M 8	14	12	7	TX-45
33658.W1208-A2	12	8	M 10	20	16	8	TX-50
33658.W1210-A2	12	10	M 10	20	16	8	TX-50
33658.W1212-A2	12	12	M 10	20	16	8	TX-50
33658.W1214-A2	12	14	M 10	20	16	8	TX-50
33658.W1216-A2	12	16	M 10	20	16	8	TX-50
33658.W1218-A2	12	18	M 10	20	16	8	TX-50
33658.W1220-A2	12	20	M 10	20	16	8	TX-50
33658.W1225-A2	12	25	M 10	20	16	8	TX-50
33658.W1230-A2	12	30	M 10	20	16	8	TX-50
33658.W1235-A2	12	35	M 10	20	16	8	TX-50
33658.W1240-A2	12	40	M 10	20	16	8	TX-50
33658.W1245-A2	12	45	M 10	20	16	8	TX-50
33658.W1250-A2	12	50	M 10	20	16	8	TX-50
33658.W1255-A2	12	55	M 10	20	16	8	TX-50
33658.W1260-A2	12	60	M 10	20	16	8	TX-50
33658.W1265-A2	12	65	M 10	20	16	8	TX-50
33658.W1270-A2	12	70	M 10	20	16	8	TX-50
33658.W1275-A2	12	75	M 10	20	16	8	TX-50
33658.W1280-A2	12	80	M 10	20	16	8	TX-50
33658.W1290-A2	12	90	M 10	20	16	8	TX-50
33658.W1200-A2	12	100	M 10	20	16	8	TX-50
33658.W1625-A2	16	25	M 12	24	18	11	TX-60
33658.W1630-A2	16	30	M 12	24	18	11	TX-60
33658.W1635-A2	16	35	M 12	24	18	11	TX-60
33658.W1640-A2	16	40	M 12	24	18	11	TX-60
33658.W1645-A2	16	45	M 12	24	18	11	TX-60
33658.W1650-A2	16	50	M 12	24	18	11	TX-60
33658.W1655-A2	16	55	M 12	24	18	11	TX-60
33658.W1660-A2	16	60	M 12	24	18	11	TX-60
33658.W1665-A2	16	65	M 12	24	18	11	TX-60
33658.W1670-A2	16	70	M 12	24	18	11	TX-60
33658.W1675-A2	16	75	M 12	24	18	11	TX-60
33658.W1680-A2	16	80	M 12	24	18	11	TX-60
33658.W1690-A2	16	90	M 12	24	18	11	TX-60
33658.W1600-A2	16	100	M 12	24	18	11	TX-60
33658.W2030-A2	20	30	M 16	30	22	14	TX-70
33658.W2035-A2	20	35	M 16	30	22	14	TX-70
33658.W2040-A2	20	40	M 16	30	22	14	TX-70
33658.W2045-A2	20	45	M 16	30	22	14	TX-70
33658.W2050-A2	20	50	M 16	30	22	14	TX-70
33658.W2055-A2	20	55	M 16	30	22	14	TX-70
33658.W2060-A2	20	60	M 16	30	22	14	TX-70
33658.W2065-A2	20	65	M 16	30	22	14	TX-70
33658.W2070-A2	20	70	M 16	30	22	14	TX-70
33658.W2075-A2	20	75	M 16	30	22	14	TX-70
33658.W2080-A2	20	80	M 16	30	22	14	TX-70
33658.W2090-A2	20	90	M 16	30	22	14	TX-70
33658.W2000-A2	20	100	M 16	30	22	14	TX-70