




One-Touch Fastener - Ball Clamping pin

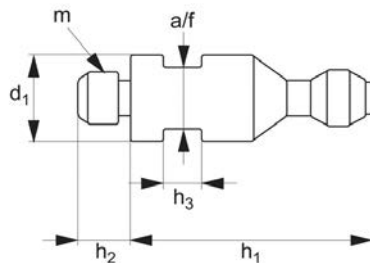

One Touch
Fasteners



33930

ONE TOUCH FASTENERS

Material

Body: steel, nickel plated.

Technical Notes

One-touch fasteners are the ideal solution for applications requiring rapid and recurring change over of tooling or set ups. Use in applications as diverse as bottling processes, machine covers, changing of

cogs and drive belts. One-touch fasteners provide a quick, simple and secure change over solution - no time waste in unfastening screws or other permanent fixings, and no opportunity for lost fixings in your machinery.


Important Notes

Pin 33930 is for use in conjunction with


one-touch fasteners, ball clamping; 33934 and 33936. Suitable for panels/enclosures of 6 to 20 mm thickness. Requires an M 6 thread, 6mm deep for installation into blind hole. See technical pages for further information.

Order No.	d_1 -0.2 -0.4	h_1	h_2	h_3	m	A/F	Weight g
33930.W0008	Ø8	23	5	4	M 5x0,8	6	7

Installation dimensions

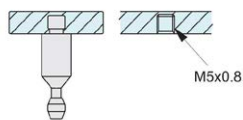





for installation in 6mm-thick plates

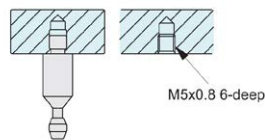

for installation in plates of thickness over 6mm,
use screw-in method




One-Touch Fasteners - Alternatives to Screws

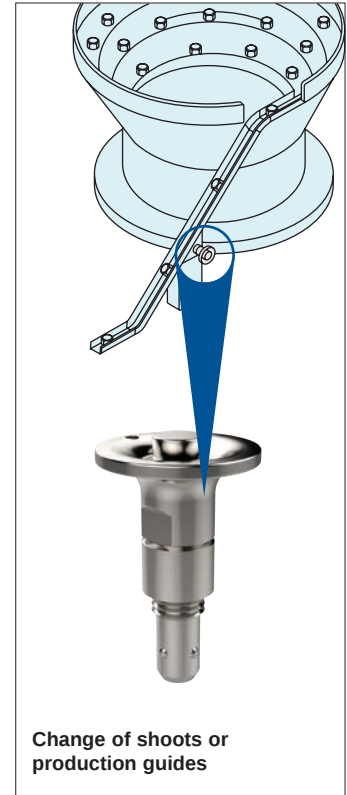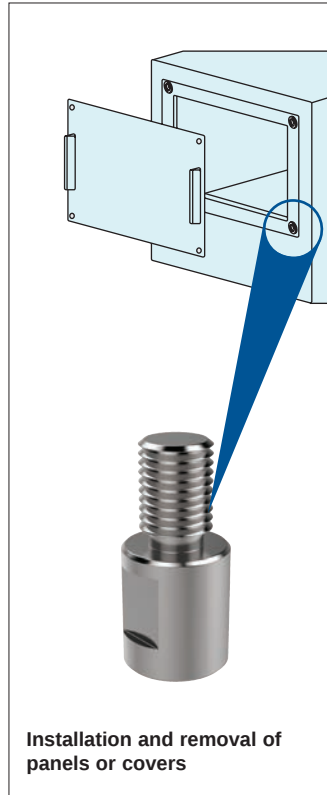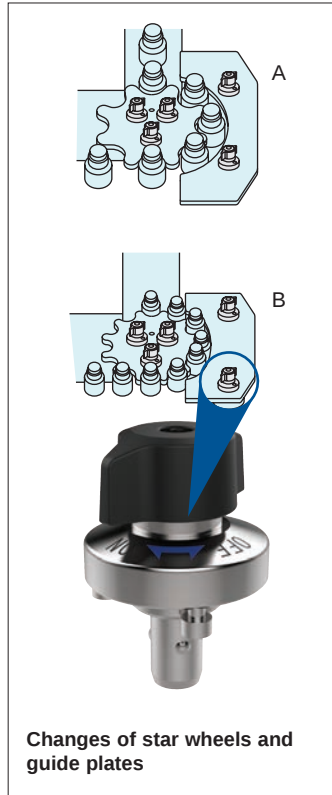
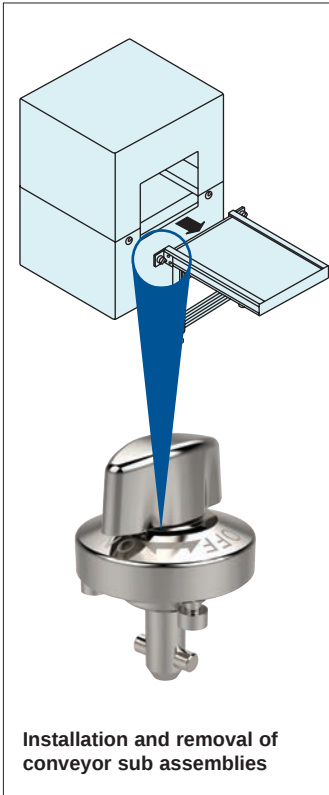


Easy & Secure! For Quick Changeover with No Tools!




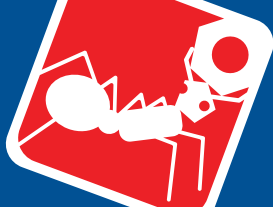



One-Touch Change Over

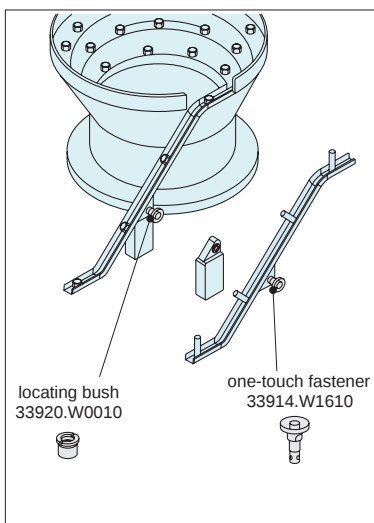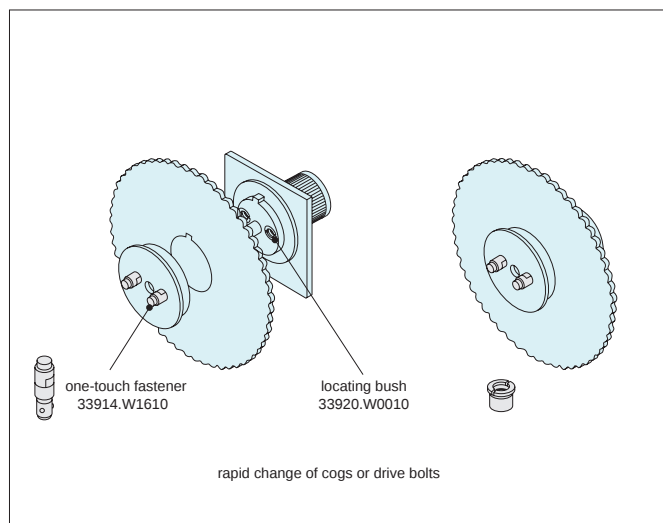

Installation and Removal of Rotary Blades and Changes of Shooters

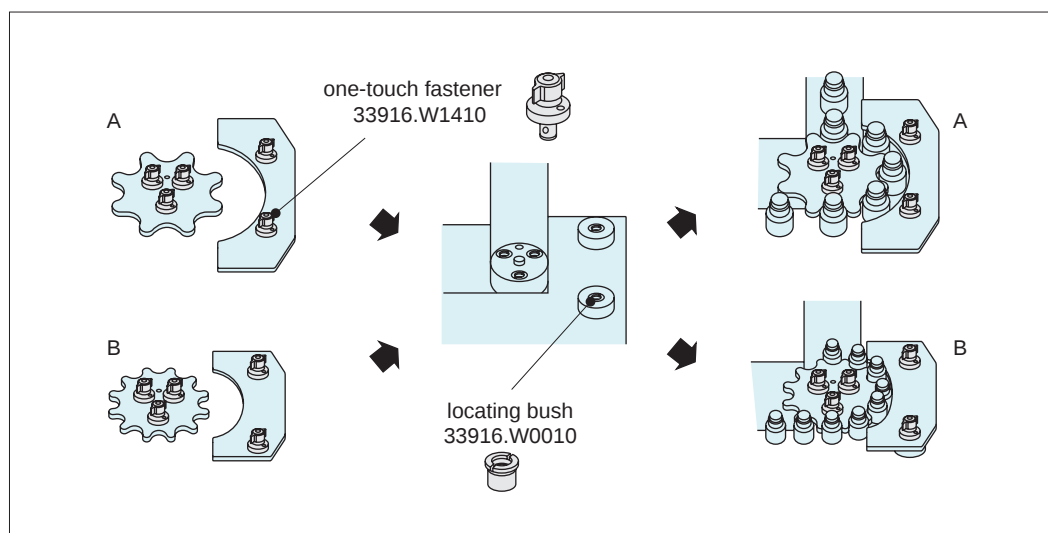

Changes of Star Wheels and Guide Plates

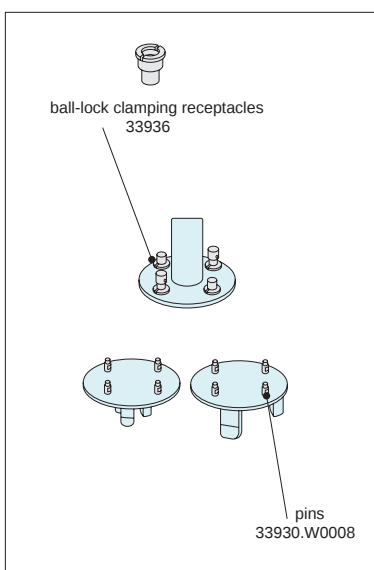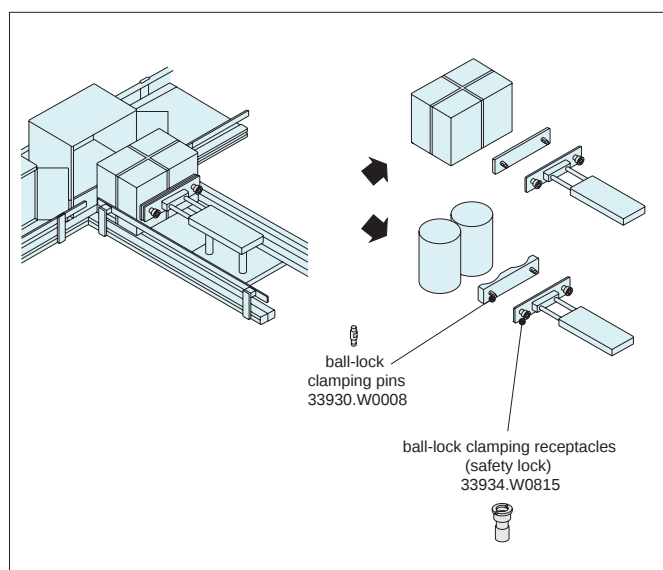

Changes of Pusher and Changes of Chuck Handling Machines