




One-Touch Fastener - Magnetic Hold pin



One Touch
Fasteners

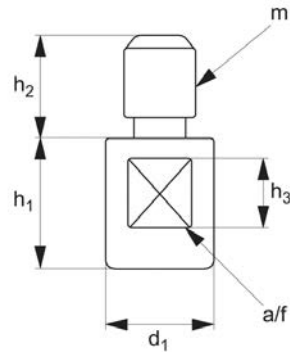

33950

ONE TOUCH FASTENERS

Material

Body: steel, nickel plated.

Technical Notes

Used in conjunction with magnetic one-touch fasteners 33956, provides secure fastening of panels and covers. One-touch fasteners are the ideal solution for applica-

tions requiring rapid and recurring change over of tooling or set ups. Use in applications as diverse as bottling processes, machine covers, changing of cogs and drive belts.

Note: pin itself is not magnetic, it is for use with locating bush part no. 33956,

which contains magnet.



Important Notes

Suitable for panels/enclosures of 2 to 6 20 mm thickness.

For installation instructions see technical page.





Order No.	For single panel thickness	d_1 -0.02 -0.04	h_1	h_2	h_3	m	A/F	Shear strength N	Weight g
33950.W0006	2 to 6	Ø6	7	5.8	4	M 4x0,7	5	900	2

Installation dimensions for magnetic hold clamping pin

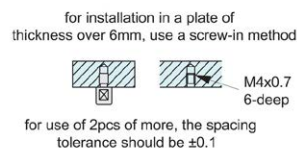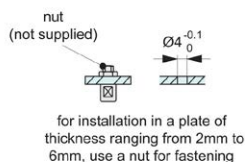



One-Touch Fasteners - Alternatives to Screws

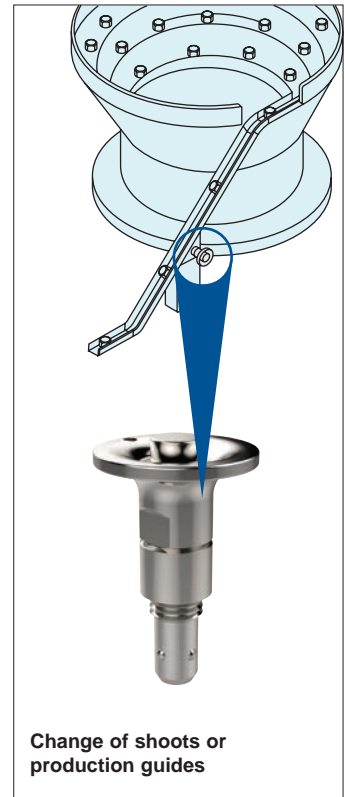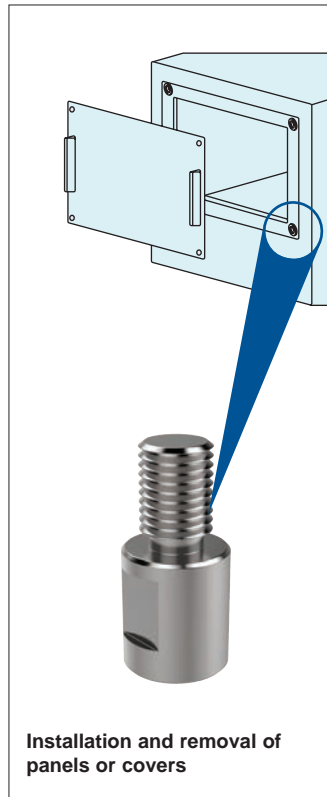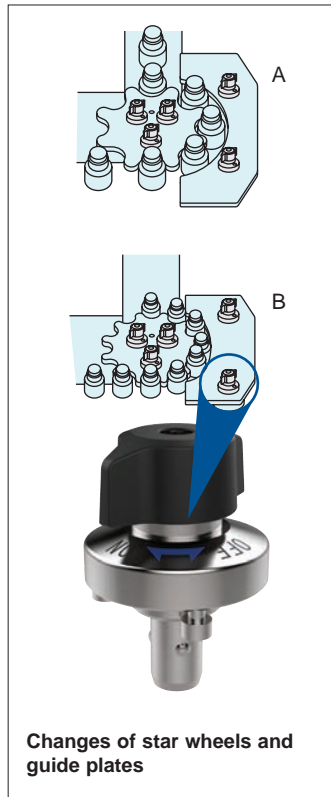
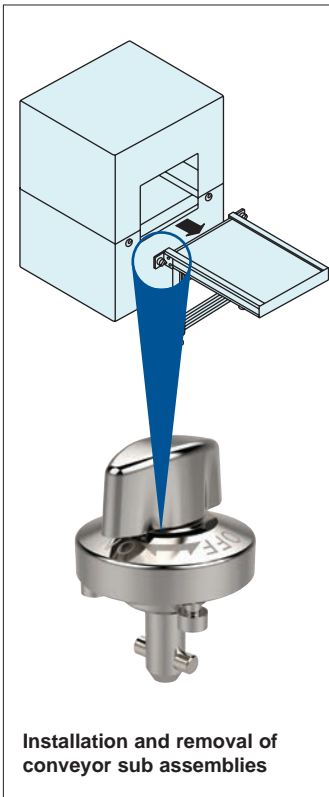


Easy & Secure! For Quick Changeover with No Tools!








One-Touch Change Over

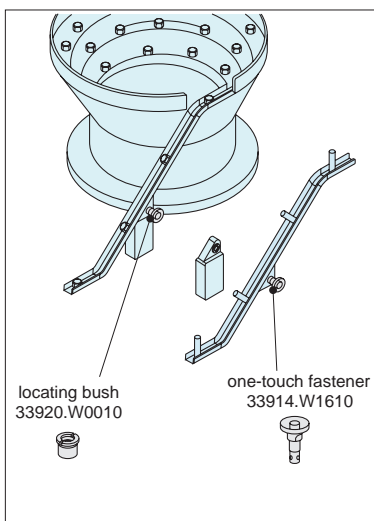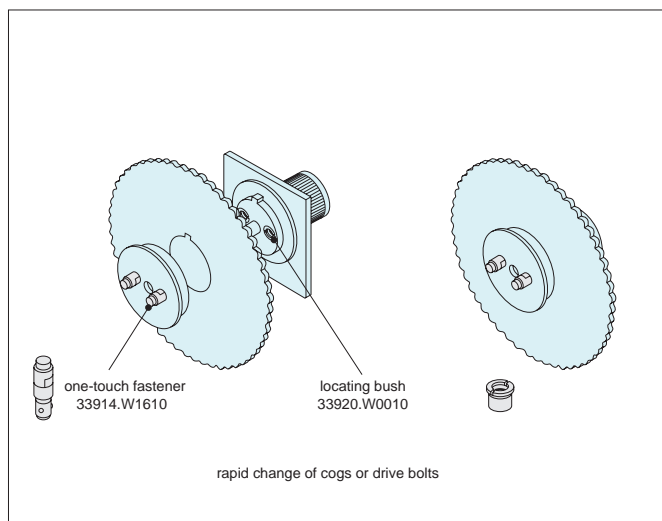

Installation and Removal of Rotary Blades and Changes of Shooters

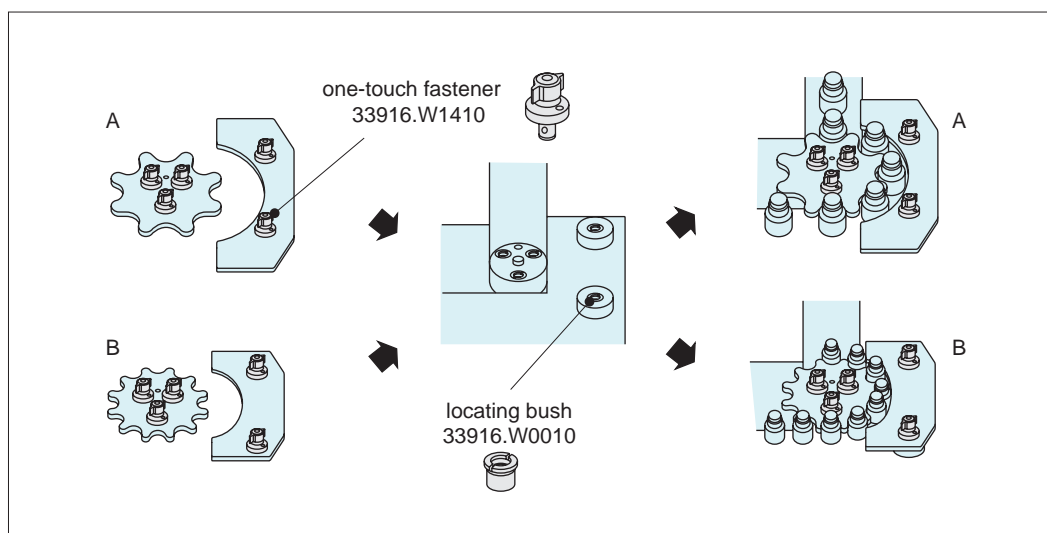

Changes of Star Wheels and Guide Plates

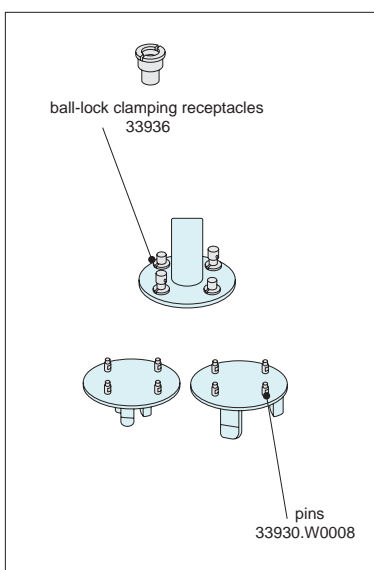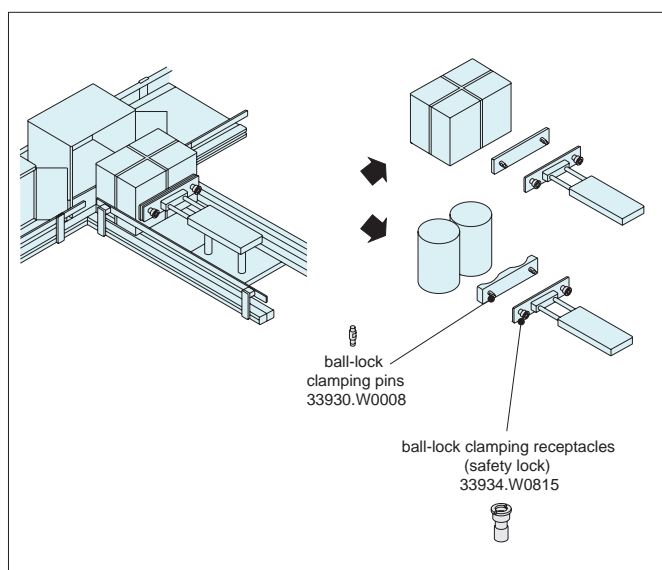

Changes of Pusher and Changes of Chuck Handling Machines