


Scale Plates - Single Scale

for sliding clamps 33970, 33972, 33973

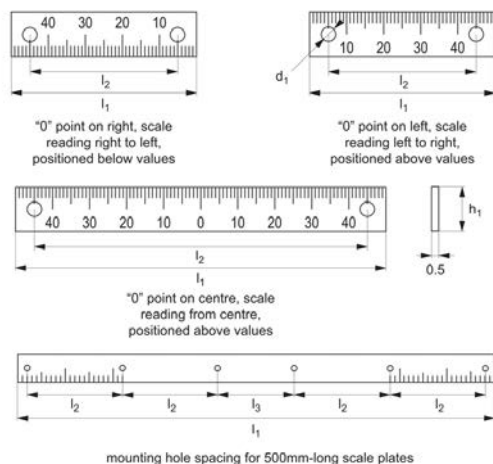

One Touch Fasteners



33975

ONE TOUCH FASTENERS

Material

Aluminium, with etched graduation/ markings.

Technical Notes

For use with sliding clamps 33970, 33972 and 33973. Markings are for indicative purposes, and are not intended for precise

measurement.

Adhesive mounting type: ensure receiving surface is clean and dirt free (features outline of screw hole location, not drilled).

Screw mounting type: holes drilled to

3,5mm dia.

When selecting scale plate consider;
- direction scale reads (left to right, right to left or from centre).
- position of scale relative to number valves (above, below or both).

Order No.	Mounting type	Number of mounting holes	Direction of measurement	Scale position	d ₁ (marked drilled)	h ₁	l ₁	l ₂	l ₃	Weight g
33975.W1005	Adhesive	2	Left	Top	(3,5)	12	50	40		0,8
33975.W1010	Adhesive	2	Left	Top	(3,5)	12	100	90		1,6
33975.W1015	Adhesive	3	Left	Top	(3,5)	12	150	70		2,4
33975.W1020	Adhesive	3	Left	Top	(3,5)	12	200	95		3,2
33975.W1030	Adhesive	2	Right	Top	(3,5)	12	50	40		0,8
33975.W1035	Adhesive	2	Right	Top	(3,5)	12	100	90		1,6
33975.W1040	Adhesive	3	Right	Top	(3,5)	12	150	70		2,4
33975.W1045	Adhesive	3	Right	Top	(3,5)	12	200	95		3,2
33975.W1055	Adhesive	2	Centre	Top	(3,5)	12	100	90		1,6
33975.W1060	Adhesive	3	Centre	Top	(3,5)	12	200	95		3,2
33975.W2005	Adhesive	2	Left	Bottom	(3,5)	12	50	40		0,8
33975.W2010	Adhesive	2	Left	Bottom	(3,5)	12	100	90		1,6
33975.W2015	Adhesive	3	Left	Bottom	(3,5)	12	150	70		2,4
33975.W2020	Adhesive	3	Left	Bottom	(3,5)	12	200	95		3,2
33975.W2030	Adhesive	2	Right	Bottom	(3,5)	12	50	40		0,8
33975.W2035	Adhesive	2	Right	Bottom	(3,5)	12	100	90		1,6
33975.W2040	Adhesive	3	Right	Bottom	(3,5)	12	150	70		2,4
33975.W2045	Adhesive	3	Right	Bottom	(3,5)	12	200	95		3,2
33975.W2055	Adhesive	2	Centre	Bottom	(3,5)	12	100	90		1,6
33975.W2060	Adhesive	3	Centre	Bottom	(3,5)	12	200	95		3,2
33975.W5005	Screw Mount	2	Left	Top	3,5	12	50	40		0,8
33975.W5010	Screw Mount	2	Left	Top	3,5	12	100	90		1,6
33975.W5015	Screw Mount	3	Left	Top	3,5	12	150	70		2,4
33975.W5020	Screw Mount	3	Left	Top	3,5	12	200	95		3,2
33975.W5025	Screw Mount	6	Left	Top	3,5	12	500	100	90	8,0
33975.W5030	Screw Mount	2	Right	Top	3,5	12	50	40		0,8
33975.W5035	Screw Mount	2	Right	Top	3,5	12	100	90		1,6
33975.W5040	Screw Mount	3	Right	Top	3,5	12	150	70		2,4
33975.W5045	Screw Mount	3	Right	Top	3,5	12	200	95		3,2
33975.W5050	Screw Mount	6	Right	Top	3,5	12	500	100	90	8,0



Order No.	Mounting type	Number of mounting holes	Direction of measurement	Scale position	d ₁ (marked) drilled	h ₁	l ₁	l ₂	l ₃	Weight g
33975.W5055	Screw Mount	2	Centre	Top	3,5	12	100	90		1,6
33975.W5060	Screw Mount	3	Centre	Top	3,5	12	200	95		3,2
33975.W5065	Screw Mount	6	Centre	Top	3,5	12	500	100	90	8,0
33975.W6005	Screw Mount	2	Left	Bottom	3,5	12	50	40		0,8
33975.W6010	Screw Mount	2	Left	Bottom	3,5	12	100	90		1,6
33975.W6015	Screw Mount	3	Left	Bottom	3,5	12	150	70		2,4
33975.W6020	Screw Mount	3	Left	Bottom	3,5	12	200	95		3,2
33975.W6025	Screw Mount	6	Left	Bottom	3,5	12	500	100	90	8,0
33975.W6030	Screw Mount	2	Right	Bottom	3,5	12	50	40		0,8
33975.W6035	Screw Mount	2	Right	Bottom	3,5	12	100	90		1,6
33975.W6040	Screw Mount	3	Right	Bottom	3,5	12	150	70		2,4
33975.W6045	Screw Mount	3	Right	Bottom	3,5	12	200	95		3,2
33975.W6050	Screw Mount	6	Right	Bottom	3,5	12	500	100	90	8,0
33975.W6055	Screw Mount	2	Centre	Bottom	3,5	12	100	90		1,6
33975.W6060	Screw Mount	3	Centre	Bottom	3,5	12	200	95		3,2
33975.W6065	Screw Mount	6	Centre	Bottom	3,5	12	500	100	90	8,0