





# Scale Plates - Double Scale

for sliding clamps 33970, 33972, 33973



One Touch Fasteners

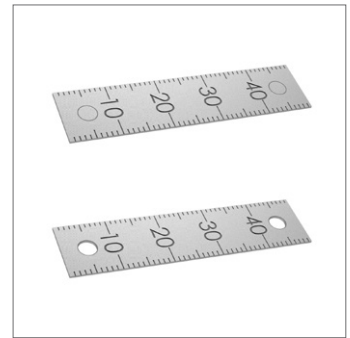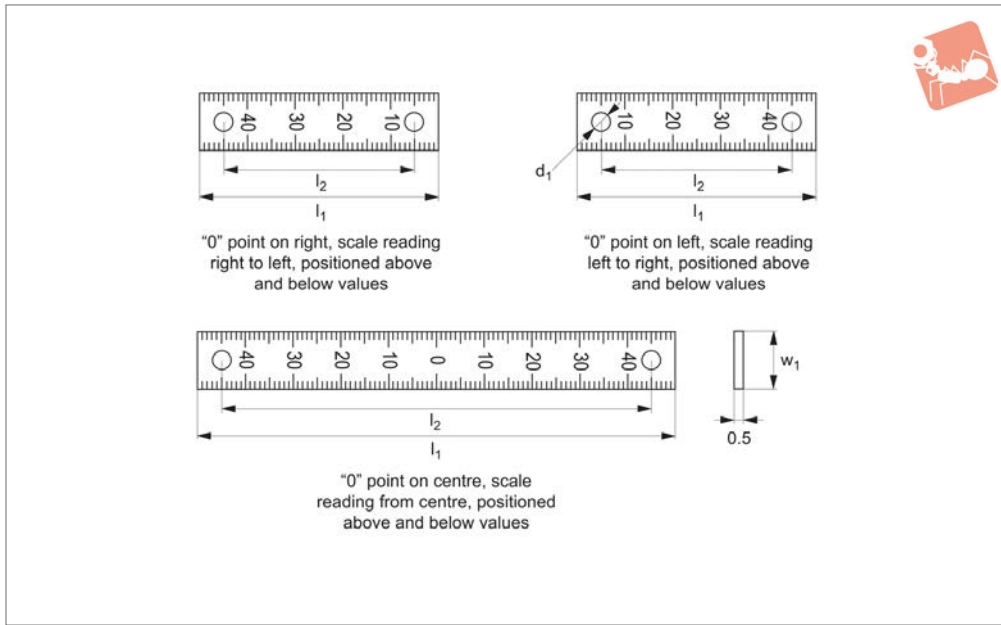

33976

ONE TOUCH FASTENERS

### Material

Aluminium, with etched graduation/ markings.

### Technical Notes

For use with sliding clamps 33970, 33972 and 33973. Markings are for indicative purposes, and are not intended for precise

measurement.

Adhesive mounting type: ensure receiving surface is clean and dirt free (features outline of screw hole location, not drilled).

Screw mounting type: holes drilled to

3,5mm dia.

When selecting scale plate consider;  
 - direction scale reads (left to right, right to left or from centre).  
 - position of scale relative to number valves (above, below or both).

Order No.	Mounting type	Number of mounting holes	Location of „0“ point	d <sub>1</sub>	l <sub>1</sub>	l <sub>2</sub>	w <sub>1</sub>	Weight g
33976.W1005	Adhesive	2	Left	-	50	40	15	1
33976.W1010	Adhesive	2	Left	-	100	90	15	2
33976.W1015	Adhesive	2	Right	-	50	40	15	1
33976.W1020	Adhesive	2	Right	-	100	90	15	2
33976.W1025	Adhesive	2	Centre	-	100	90	15	2
33976.W5005	Screw Mount	2	Left	3.5	50	40	15	1
33976.W5010	Screw Mount	2	Left	3.5	100	90	15	2
33976.W5015	Screw Mount	2	Right	3.5	50	40	15	1
33976.W5020	Screw Mount	2	Right	3.5	100	90	15	2
33976.W5025	Screw Mount	2	Centre	3.5	100	90	15	2