



# Threaded Plastic Inserts for Hollow Section

with brass bush

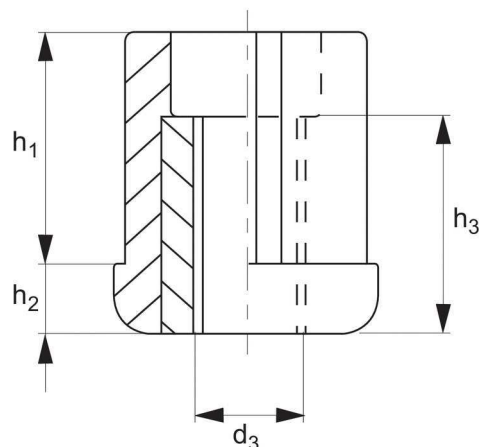

# 34691

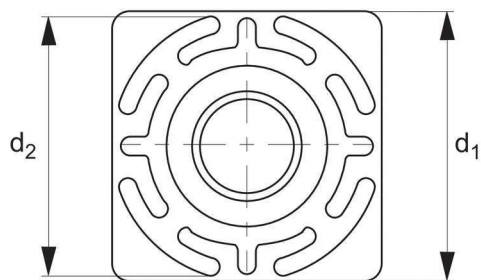

### Material

Body: polyamide reinforced nylon.  
Bush: brass, nickel plated.

### Technical Notes

For use with levelling feet parts.



Order No.	Outerbox $d_1$	Innerbox $d_2$	$d_3$	$h_1$	$h_2$	Max. static load kN
34691.W0108	30x30x1,5	27	M 8	27	6	5,5
34691.W0110	30x30x1,5	27	M10	27	6	5,5
34691.W0112	30x30x1,5	27	M12	27	6	5,5
34691.W0114	30x30x1,5	27	M14	27	6	5,5
34691.W0116	30x30x1,5	27	M16	27	6	5,5
34691.W0117	35x35x1,5	32	M 8	35	8	7,0
34691.W0118	35x35x1,5	32	M10	35	8	7,0
34961.W0119	35x35x1,5	32	M12	35	8	7,0
34961.W0120	35x35x1,5	32	M14	35	8	7,0
34961.W0121	35x35x1,5	32	M16	35	8	7,0
34691.W0208	40x40x1,5	37	M 8	35	8	8,0
34691.W0210	40x40x1,5	37	M10	35	8	8,0
34691.W0212	40x40x1,5	37	M12	35	8	8,0
34691.W0214	40x40x1,5	37	M14	35	8	8,0
34691.W0216	40x40x1,5	37	M16	35	8	8,0
34691.W0220	40x40x1,5	37	M20	35	8	8,0
34691.W0308	40x40x2,0	36	M8	35	8	8,0
34691.W0310	40x40x2,0	36	M10	35	8	8,0
34691.W0312	40x40x2,0	36	M12	35	8	8,0
34691.W0314	40x40x2,0	36	M14	35	8	8,0
34691.W0316	40x40x2,0	36	M16	35	8	8,0
34691.W0320	40x40x2,0	36	M20	35	8	8,0
34691.W0412	50x50x1,5	47	M12	35	8	8,0
34691.W0416	50x50x1,5	47	M14	45	10	9,5
34691.W0420	50x50x1,5	47	M16	45	10	9,5
34691.W0424	50x50x1,5	47	M20	45	10	9,5
34691.W0412	50x50x2,5	45	M12	45	10	9,5
34691.W0516	50x50x2,5	45	M14	45	10	9,5
34691.W0520	50x50x2,5	45	M16	45	10	9,5
34691.W0524	50x50x2,5	45	M20	45	10	9,5






## A Range of features to suit your application

To ensure you select the most suitable levelling feet for your application consider the following questions:

- Tilting or fixed?
- Material required - steel, stainless or plastic?
- Load carrying capacity - light, medium or heavy duty?  
(Review the quoted load capacities in the individual product tables).
- Bolt down feature required?
- Threaded or plastic insert required for mounting?
- Optional extras: hygiene seal, rubber pad, (subject to minimum quantity and selected model).


### Product selection

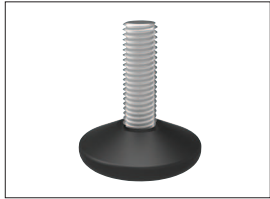

Fixed feet



Articulating levelling feet

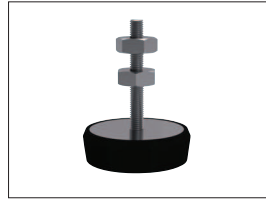


Machine mounts



Fulcrum screw

### Key Types

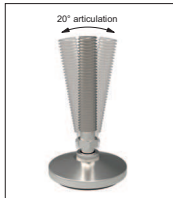

Articulation



Standard nylon base




Anti-slip base



Bolt down base



Hygienic seal

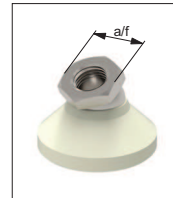

Hex for easy installation

### Available features



Steel thread - Nylon base



Stainless thread - Nylon base



Steel thread - Steel base




Stainless thread - Stainless base


### Materials



Weldable insert

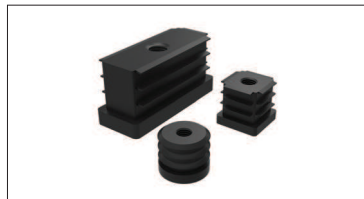

Hollow section insert

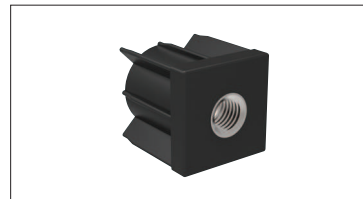

Hollow section bushed insert

### Mounting inserts



For applications under greater loads and requiring increased precision of adjustment see our range of Precision Height Adjusters.



For applications exposed to extreme vibrations see our range of Anti-Vibration Mounts.

### Additional technical information