




Threaded Plastic Insert - Square with nickel plated brass bush

Threaded Frame Inserts

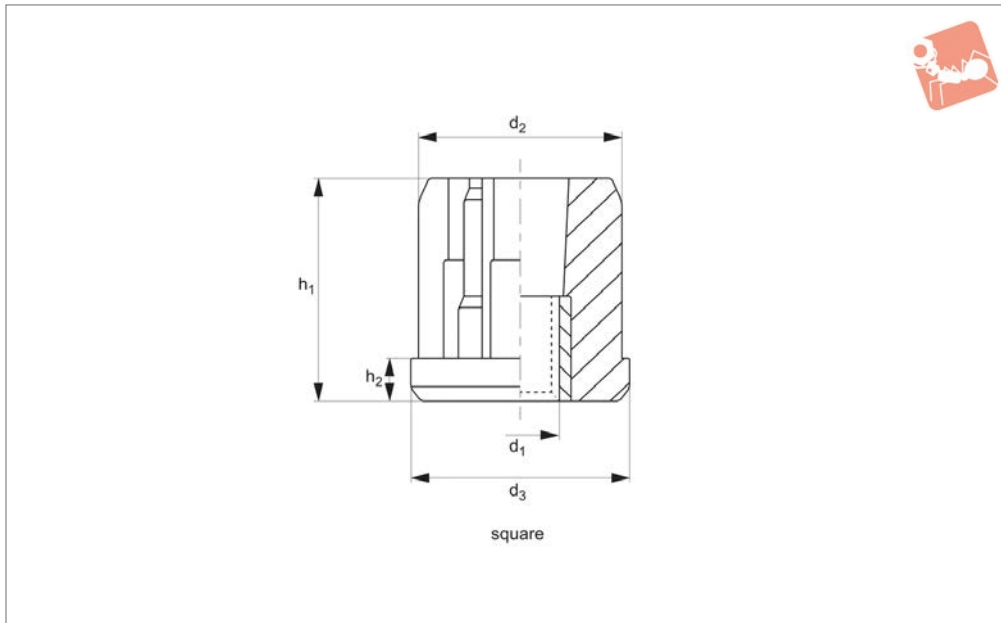

34694

THREADED FRAME INSERTS

Material

Moulding: polyamide, reinforced with fiber glass.

Insert: nickel-plated brass.

Stainless steel inserts available on request.

Notes -

Order No.	d ₁	d ₂	d ₃	h ₁	h ₂	Static load kN max.
34694.W0110	M10	27	30x30x1,5	33	6	5.5
34694.W0112	M12	27	30x30x1,5	33	6	5.5
34694.W0114	M14	27	30x30x1,5	33	6	5.5
34694.W0116	M16	27	30x30x1,5	33	6	5.5
34694.W0210	M10	32	35x35x1,5	43	8	7.0
34694.W0212	M12	32	35x35x1,5	43	8	7.0
34694.W0214	M14	32	35x35x1,5	43	8	7.0
34694.W0216	M16	32	35x35x1,5	43	8	7.0
34694.W0310	M10	37	40x40x1,5	43	8	8.0
34694.W0312	M12	37	40x40x1,5	43	8	8.0
34694.W0314	M14	37	40x40x1,5	43	8	8.0
34694.W0316	M16	37	40x40x1,5	43	8	8.0
34694.W0320	M20	37	40x40x1,5	43	8	8.0
34694.W0410	M10	36	40x40x2,0	43	8	8.0
34694.W0412	M12	36	40x40x2,0	43	8	8.0
34694.W0414	M14	36	40x40x2,0	43	8	8.0
34694.W0416	M16	36	40x40x2,0	43	8	8.0
34694.W0420	M20	36	40x40x2,0	43	8	8.0
34694.W0512	M12	47	50x50x1,5	55	10	9.5
34694.W0514	M14	47	50x50x1,5	55	10	9.5
34694.W0516	M16	47	50x50x1,5	55	10	9.5
34694.W0520	M20	47	50x50x1,5	55	10	9.5
34694.W0612	M12	45	50x50x2,0	55	10	9.5
34694.W0614	M14	45	50x50x2,0	55	10	9.5
34694.W0616	M16	45	50x50x2,0	55	10	9.5
34694.W0620	M20	45	50x50x2,0	55	10	9.5



A Range of features to suit your application

Product selection

To ensure you select the most suitable levelling feet for your application consider the following questions:

- Tilting or fixed?
- Material required - steel, stainless or plastic?
- Load carrying capacity - light, medium or heavy duty?
(Review the quoted load capacities in the individual product tables).
- Bolt down feature required?
- Threaded or plastic insert required for mounting?
- Optional extras: hygiene seal, rubber pad, (subject to minimum quantity and selected model).

Key types



Fixed feet



Articulating levelling feet



Machine mounts



Fulcrum screw

Available features



Articulation



Standard nylon base




Anti-slip base



Bolt down base



Hygienic seal

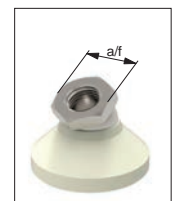

Hex for easy installation

Materials



Steel thread - Nylon base



Stainless thread - Nylon base



Steel thread - Steel base



Stainless thread - Stainless base

Mounting inserts



Weldable insert



Hollow section insert



Hollow section bushed insert

Additional technical information



▶ For applications under greater loads and requiring increased precision of adjustment see our range of Precision Height Adjusters.

▶ For applications exposed to extreme vibrations see our range of Anti-Vibration Mounts.

