


# Levelling Feet - Non Slip

pad thermoplastic, bolt **stainless steel**

## Levelling Feet

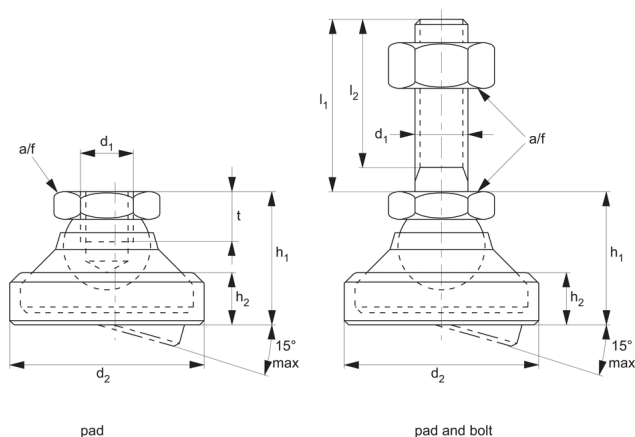

**34761**

LEVELLING FEET

### Material

Pad: white thermoplastic (POM).  
Bolt: stainless steel 1.4305 (AISI 303).  
Lock nut: Stainless steel A2, DIN 934/ISO 4032. (M10, M12 only).

Cap: Black Rubber

### Tips

To be used as feet and thrust pads. Used for levelling up to 15° on surface.

Also used:

34701 - Levelling Feet  
34700 - Levelling Feet - steel/stainless, non slip.

| Order No.          | Type         | d <sub>1</sub> | l <sub>1</sub> | d <sub>2</sub> | l <sub>2</sub> | h <sub>1</sub><br>≈ | h <sub>2</sub> | Static load<br>kN<br>max. | t    | A/F | Weight<br>g |
|--------------------|--------------|----------------|----------------|----------------|----------------|---------------------|----------------|---------------------------|------|-----|-------------|
| <b>34761.W1106</b> | Pad          | M 6            | -              | 22.5           | -              | 16.5                | 6.4            | 4                         | 5.0  | 10  | 7           |
| <b>34761.W1108</b> | Pad          | M 8            | -              | 28.0           | -              | 20.6                | 8.3            | 7                         | 7.0  | 13  | 16          |
| <b>34761.W1110</b> | Pad          | M10            | -              | 36.0           | -              | 26.0                | 11.0           | 10                        | 9.0  | 17  | 32          |
| <b>34761.W1112</b> | Pad          | M12            | -              | 45.0           | -              | 30.5                | 13.2           | 18                        | 11.0 | 19  | 51          |
| <b>34761.W1116</b> | Pad          | M16            | -              | 56.0           | -              | 37.5                | 15.5           | 20                        | 13.5 | 24  | 96          |
| <b>34761.W1120</b> | Pad          | M20            | -              | 67.0           | -              | 49.5                | 19.5           | 22                        | 17.0 | 30  | 190         |
| <b>34761.W1124</b> | Pad          | M24            | -              | 69.0           | -              | 55.0                | 24.0           | 25                        | 19.0 | 36  | 240         |
| <b>34761.W1510</b> | Pad and Bolt | M 6            | 60             | 22.5           | 57.0           | 16.5                | 6.4            | 4                         | -    | 10  | 21          |
| <b>34761.W1522</b> | Pad and Bolt | M 8            | 80             | 28.0           | 76.0           | 20.6                | 8.3            | 7                         | -    | 13  | 49          |
| <b>34761.W1538</b> | Pad and Bolt | M10            | 100            | 36.0           | 95.5           | 26.0                | 11.0           | 10                        | -    | 17  | 98          |
| <b>34761.W1542</b> | Pad and Bolt | M10            | 150            | 36.0           | 145.5          | 26.0                | 11.0           | 10                        | -    | 17  | 124         |
| <b>34761.W1552</b> | Pad and Bolt | M12            | 100            | 45.0           | 94.5           | 30.5                | 13.2           | 18                        | -    | 19  | 150         |
| <b>34761.W1556</b> | Pad and Bolt | M12            | 150            | 45.0           | 144.5          | 30.5                | 13.2           | 18                        | -    | 19  | 184         |
| <b>34761.W1568</b> | Pad and Bolt | M16            | 100            | 56.0           | 94.0           | 37.5                | 15.5           | 20                        | -    | 24  | 285         |
| <b>34761.W1572</b> | Pad and Bolt | M16            | 200            | 56.0           | 194.0          | 37.5                | 15.5           | 20                        | -    | 24  | 414         |
| <b>34761.W1582</b> | Pad and Bolt | M20            | 100            | 67.0           | 92.5           | 49.5                | 19.5           | 22                        | -    | 30  | 503         |
| <b>34761.W1588</b> | Pad and Bolt | M20            | 200            | 67.0           | 192.5          | 49.5                | 19.5           | 22                        | -    | 30  | 704         |
| <b>34761.W1595</b> | Pad and Bolt | M24            | 100            | 69.0           | 91.0           | 55.0                | 24.0           | 25                        | -    | 36  | 718         |
| <b>34761.W1598</b> | Pad and Bolt | M24            | 200            | 69.0           | 191.0          | 55.0                | 24.0           | 25                        | -    | 36  | 1016        |

