

Ultra Low Head - Shoulder Screw


hex drive - 316 stainless

Shoulder Screws



36650.A4

SHOULDER SCREWS

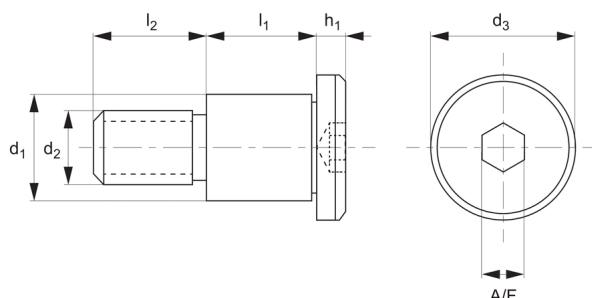

Material

Stainless steel (AISI 316, 1.440). Tensile strength 480 N/mm². Proof stress min. 200 N/mm², austenitic stainless steel.

Technical Notes

These very low profile socket shoulder

screws have a head height approximately 1/3 that of normal shoulder screws (36642).

316 Series stainless have excellent corrosion resistance. Stainless steel suitable for marine and other applications.

Order No.	d ₁ +0 -0.025	l ₁ +0.05 -0.0	d ₂	d ₃	l ₂	h ₁	A/F
36650.W0404-A4	4	4	M 3	6	4	1.3	2.0
36650.W0405-A4	4	5	M 3	6	4	1.3	2.0
36650.W0406-A4	4	6	M 3	6	4	1.3	2.0
36650.W0408-A4	4	8	M 3	6	4	1.3	2.0
36650.W0410-A4	4	10	M 3	6	4	1.3	2.0
36650.W0412-A4	4	12	M 3	6	4	1.3	2.0
36650.W0416-A4	4	16	M 3	6	4	1.3	2.0
36650.W0420-A4	4	20	M 3	6	4	1.3	2.0
36650.W0504-A4	5	4	M 4	9	5	1.3	2.5
36650.W0505-A4	5	5	M 4	9	5	1.3	2.5
36650.W0506-A4	5	6	M 4	9	5	1.3	2.5
36650.W0508-A4	5	8	M 4	9	5	1.3	2.5
36650.W0510-A4	5	10	M 4	9	5	1.3	2.5
36650.W0512-A4	5	12	M 4	9	5	1.3	2.5
36650.W0516-A4	5	16	M 4	9	5	1.3	2.5
36650.W0520-A4	5	20	M 4	9	5	1.3	2.5
36650.W0525-A4	5	25	M 4	9	5	1.3	2.5
36650.W0530-A4	5	30	M 4	9	5	1.3	2.5
36650.W0540-A4	5	40	M 4	9	5	1.3	2.5
36650.W0604-A4	6	4	M 5	10	6	1.7	3.0
36650.W0605-A4	6	5	M 5	10	6	1.7	3.0
36650.W0606-A4	6	6	M 5	10	6	1.7	3.0
36650.W0608-A4	6	8	M 5	10	6	1.7	3.0
36650.W0610-A4	6	10	M 5	10	6	1.7	3.0
36650.W0612-A4	6	12	M 5	10	6	1.7	3.0
36650.W0616-A4	6	16	M 5	10	6	1.7	3.0
36650.W0620-A4	6	20	M 5	10	6	1.7	3.0
36650.W0625-A4	6	25	M 5	10	6	1.7	3.0
36650.W0630-A4	6	30	M 5	10	6	1.7	3.0
36650.W0640-A4	6	40	M 5	10	6	1.7	3.0
36650.W0806-A4	8	6	M 6	13	11	2.0	3.0



Order No.	d_1 +0 -0.025	l_1 +0.05 -0.0	d_2	d_3	l_2	h_1	A/F
36650.W0808-A4	8	8	M 6	13	11	2.0	4.0
36650.W0810-A4	8	10	M 6	13	11	2.0	4.0
36650.W0812-A4	8	12	M 6	13	11	2.0	4.0
36650.W0816-A4	8	16	M 6	13	11	2.0	4.0
36650.W0820-A4	8	20	M 6	13	11	2.0	4.0
36650.W0825-A4	8	25	M 6	13	11	2.0	4.0
36650.W0830-A4	8	30	M 6	13	11	2.0	4.0
36650.W0840-A4	8	40	M 6	13	11	2.0	4.0
36650.W1008-A4	10	8	M 8	14	12	2.7	5.0
36650.W1010-A4	10	10	M 8	14	12	2.7	5.0
36650.W1012-A4	10	12	M 8	14	12	2.7	5.0
36650.W1016-A4	10	16	M 8	14	12	2.7	5.0
36650.W1020-A4	10	20	M 8	14	12	2.7	5.0
36650.W1025-A4	10	25	M 8	14	12	2.7	5.0
36650.W1030-A4	10	30	M 8	14	12	2.7	5.0
36650.W1040-A4	10	40	M 8	14	12	2.7	5.0
36650.W1050-A4	10	50	M 8	14	12	2.7	5.0
36650.W1210-A4	12	10	M 10	20	16	3.5	6.0
36650.W1212-A4	12	12	M 10	20	16	3.5	6.0
36650.W1216-A4	12	16	M 10	20	16	3.5	6.0
36650.W1220-A4	12	20	M 10	20	16	3.5	6.0
36650.W1225-A4	12	25	M 10	20	16	3.5	6.0
36650.W1230-A4	12	30	M 10	20	16	3.5	6.0
36650.W1240-A4	12	40	M 10	20	16	3.5	6.0
36650.W1250-A4	12	50	M 10	20	16	3.5	6.0