


Ultra Low Head - Shoulder Screw

hex drive - 303 stainless, blackened

Shoulder Screws

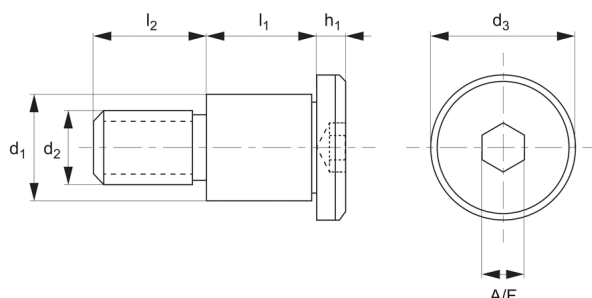

36650.B2

SHOULDER SCREWS

Material

Stainless steel (AISI 303, 1.4305), black oxide coating. Tensile strength 550 N/mm². Proof stress min. 190 N/mm², austenitic stainless steel.

Technical Notes

These very low profile socket shoulder screws have a head height approximately 1/3 that of normal shoulder screws (36642).

303 Series stainless is suitable for pharmaceutical and other applications. Stainless steel suitable for marine and other applications.

Order No.	d ₁ +0 -0.025	l ₁ +0.05 -0.0	d ₂	d ₃	l ₂	h ₁	A/F
36650.W0404-B2	4	4	M 3	6	4	1.3	2
36650.W0405-B2	4	5	M 3	6	4	1.3	2
36650.W0406-B2	4	6	M 3	6	4	1.3	2
36650.W0408-B2	4	8	M 3	6	4	1.3	2
36650.W0410-B2	4	10	M 3	6	4	1.3	2
36650.W0412-B2	4	12	M 3	6	4	1.3	2
36650.W0416-B2	4	16	M 3	6	4	1.3	2
36650.W0420-B2	4	20	M 3	6	4	1.3	2
36650.W0504-B2	5	4	M 4	9	5	1.3	2.5
36650.W0505-B2	5	5	M 4	9	5	1.3	2.5
36650.W0506-B2	5	6	M 4	9	5	1.3	2.5
36650.W0508-B2	5	8	M 4	9	5	1.3	2.5
36650.W0510-B2	5	10	M 4	9	5	1.3	2.5
36650.W0512-B2	5	12	M 4	9	5	1.3	2.5
36650.W0516-B2	5	16	M 4	9	5	1.3	2.5
36650.W0520-B2	5	20	M 4	9	5	1.3	2.5
36650.W0525-B2	5	25	M 4	9	5	1.3	2.5
36650.W0530-B2	5	30	M 4	9	5	1.3	2.5
36650.W0540-B2	5	40	M 4	9	5	1.3	2.5
36650.W0604-B2	6	4	M 5	10	6	1.7	3
36650.W0605-B2	6	5	M 5	10	6	1.7	3
36650.W0606-B2	6	6	M 5	10	6	1.7	3
36650.W0608-B2	6	8	M 5	10	6	1.7	3
36650.W0610-B2	6	10	M 5	10	6	1.7	3
36650.W0612-B2	6	12	M 5	10	6	1.7	3
36650.W0616-B2	6	16	M 5	10	6	1.7	3
36650.W0620-B2	6	20	M 5	10	6	1.7	3
36650.W0625-B2	6	25	M 5	10	6	1.7	3
36650.W0630-B2	6	30	M 5	10	6	1.7	3
36650.W0640-B2	6	40	M 5	10	6	1.7	3
36650.W0806-B2	8	6	M 6	13	11	2.0	4
36650.W0808-B2	8	8	M 6	13	11	2.0	4
36650.W0810-B2	8	10	M 6	13	11	2.0	4



Order No.	d_1 +0 -0.025	l_1 +0.05 -0.0	d_2	d_3	l_2	h_1	A/F
36650.W0812-B2	8	12	M 6	13	11	2.0	4
36650.W0816-B2	8	16	M 6	13	11	2.0	4
36650.W0820-B2	8	20	M 6	13	11	2.0	4
36650.W0825-B2	8	25	M 6	13	11	2.0	4
36650.W0830-B2	8	30	M 6	13	11	2.0	4
36650.W0840-B2	8	40	M 6	13	11	2.0	4
36650.W1008-B2	10	8	M 8	14	12	2.7	5
36650.W1010-B2	10	10	M 8	14	12	2.7	5
36650.W1012-B2	10	12	M 8	14	12	2.7	5
36650.W1016-B2	10	16	M 8	14	12	2.7	5
36650.W1020-B2	10	20	M 8	14	12	2.7	5
36650.W1025-B2	10	25	M 8	14	12	2.7	5
36650.W1030-B2	10	30	M 8	14	12	2.7	5
36650.W1040-B2	10	40	M 8	14	12	2.7	5
36650.W1050-B2	10	50	M 8	14	12	2.7	5
36650.W1210-B2	12	10	M 10	20	16	3.5	6
36650.W1212-B2	12	12	M 10	20	16	3.5	6
36650.W1216-B2	12	16	M 10	20	16	3.5	6
36650.W1220-B2	12	20	M 10	20	16	3.5	6
36650.W1225-B2	12	25	M 10	20	16	3.5	6
36650.W1230-B2	12	30	M 10	20	16	3.5	6
36650.W1240-B2	12	40	M 10	20	16	3.5	6
36650.W1250-B2	12	50	M 10	20	16	3.5	6