




# Knurled Thumb Screws

DIN 464

## Thumb Screws

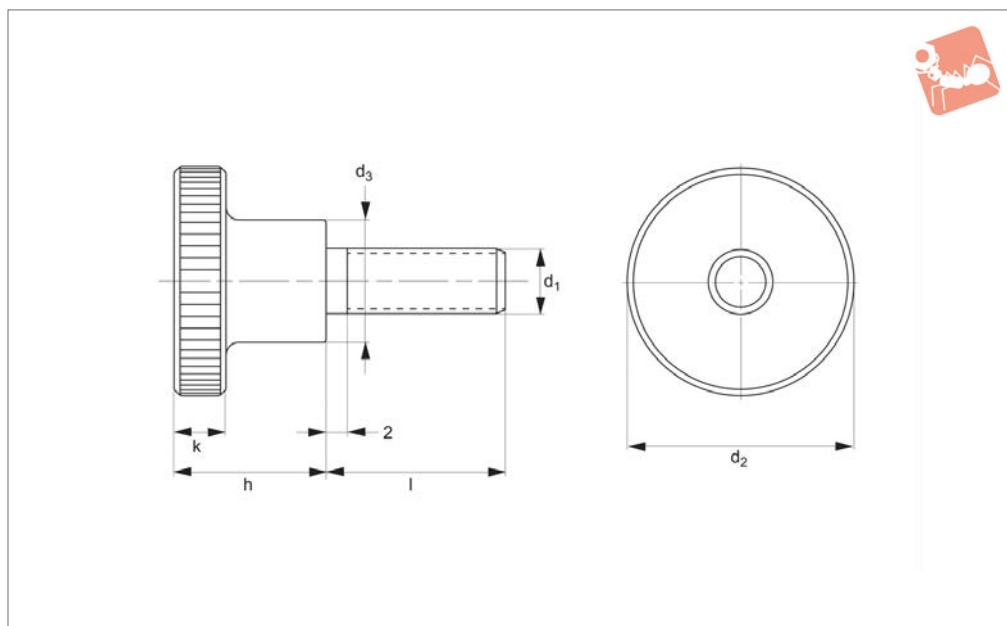

**37140**

THUMB SCREWS

### Material

Steel, quality 5.8, blackened. Turned, visible face, good finish.

tured. Contrary to the Official Standard Sheet, they all have a thread up to the head, as shown, but no recess at the thread end.

### Technical Notes

All knurled screws are one-piece manufac-

| Order No.   | d <sub>1</sub> | d <sub>2</sub> | d <sub>3</sub> | h    | k   | l  | Weight<br>g |
|-------------|----------------|----------------|----------------|------|-----|----|-------------|
| 37140.W0031 | M 3            | 12             | 6              | 7.5  | 2.5 | 6  | 3.7         |
| 37140.W0032 | M 3            | 12             | 6              | 7.5  | 2.5 | 10 | 3.8         |
| 37140.W0033 | M 3            | 12             | 6              | 7.5  | 2.5 | 12 | 4.0         |
| 37140.W0034 | M 3            | 12             | 6              | 7.5  | 2.5 | 16 | 4.0         |
| 37140.W0040 | M 4            | 16             | 8              | 9.5  | 3.5 | 5  | 7.7         |
| 37140.W0041 | M 4            | 16             | 8              | 9.5  | 3.5 | 8  | 7.9         |
| 37140.W0042 | M 4            | 16             | 8              | 9.5  | 3.5 | 10 | 8.1         |
| 37140.W0043 | M 4            | 16             | 8              | 9.5  | 3.5 | 12 | 8.3         |
| 37140.W0044 | M 4            | 16             | 8              | 9.5  | 3.5 | 16 | 8.4         |
| 37140.W0045 | M 4            | 16             | 8              | 9.5  | 3.5 | 20 | 9.1         |
| 37140.W0046 | M 4            | 16             | 8              | 9.5  | 3.5 | 25 | 9.0         |
| 37140.W0051 | M 5            | 20             | 10             | 11.5 | 4.0 | 6  | 14.0        |
| 37140.W0052 | M 5            | 20             | 10             | 11.5 | 4.0 | 8  | 15.0        |
| 37140.W0053 | M 5            | 20             | 10             | 11.5 | 4.0 | 10 | 15.0        |
| 37140.W0054 | M 5            | 20             | 10             | 11.5 | 4.0 | 12 | 15.0        |
| 37140.W0055 | M 5            | 20             | 10             | 11.5 | 4.0 | 16 | 16.0        |
| 37140.W0056 | M 5            | 20             | 10             | 11.5 | 4.0 | 20 | 16.0        |
| 37140.W0057 | M 5            | 20             | 10             | 11.5 | 4.0 | 25 | 17.0        |
| 37140.W0058 | M 5            | 20             | 10             | 11.5 | 4.0 | 30 | 17.0        |
| 37140.W0061 | M 6            | 24             | 12             | 15.0 | 5.0 | 8  | 28.0        |
| 37140.W0062 | M 6            | 24             | 12             | 15.0 | 5.0 | 10 | 27.0        |
| 37140.W0063 | M 6            | 24             | 12             | 15.0 | 5.0 | 12 | 28.0        |
| 37140.W0064 | M 6            | 24             | 12             | 15.0 | 5.0 | 16 | 28.0        |
| 37140.W0065 | M 6            | 24             | 12             | 15.0 | 5.0 | 20 | 29.0        |
| 37140.W0066 | M 6            | 24             | 12             | 15.0 | 5.0 | 25 | 30.0        |
| 37140.W0067 | M 6            | 24             | 12             | 15.0 | 5.0 | 30 | 31.0        |
| 37140.W0068 | M 6            | 24             | 12             | 15.0 | 5.0 | 35 | 31.0        |
| 37140.W0081 | M 8            | 30             | 16             | 18.0 | 6.0 | 12 | 53.0        |
| 37140.W0082 | M 8            | 30             | 16             | 18.0 | 6.0 | 16 | 55.0        |
| 37140.W0083 | M 8            | 30             | 16             | 18.0 | 6.0 | 20 | 56.0        |
| 37140.W0084 | M 8            | 30             | 16             | 18.0 | 6.0 | 25 | 58.0        |
| 37140.W0085 | M 8            | 30             | 16             | 18.0 | 6.0 | 30 | 60.0        |



| Order No.   | d <sub>1</sub> | d <sub>2</sub> | d <sub>3</sub> | h    | k   | l  | Weight<br>g |
|-------------|----------------|----------------|----------------|------|-----|----|-------------|
| 37140.W0086 | M 8            | 30             | 16             | 18.0 | 6.0 | 35 | 50.0        |
| 37140.W0087 | M 8            | 30             | 16             | 18.0 | 6.0 | 40 | 61.0        |
| 37140.W0101 | M10            | 36             | 20             | 23.0 | 8.0 | 20 | 106.0       |
| 37140.W0102 | M10            | 36             | 20             | 23.0 | 8.0 | 25 | 109.0       |
| 37140.W0103 | M10            | 36             | 20             | 23.0 | 8.0 | 30 | 112.0       |
| 37140.W0104 | M10            | 36             | 20             | 23.0 | 8.0 | 35 | 116.0       |
| 37140.W0105 | M10            | 36             | 20             | 23.0 | 8.0 | 40 | 116.0       |