




Set Collar quick setting

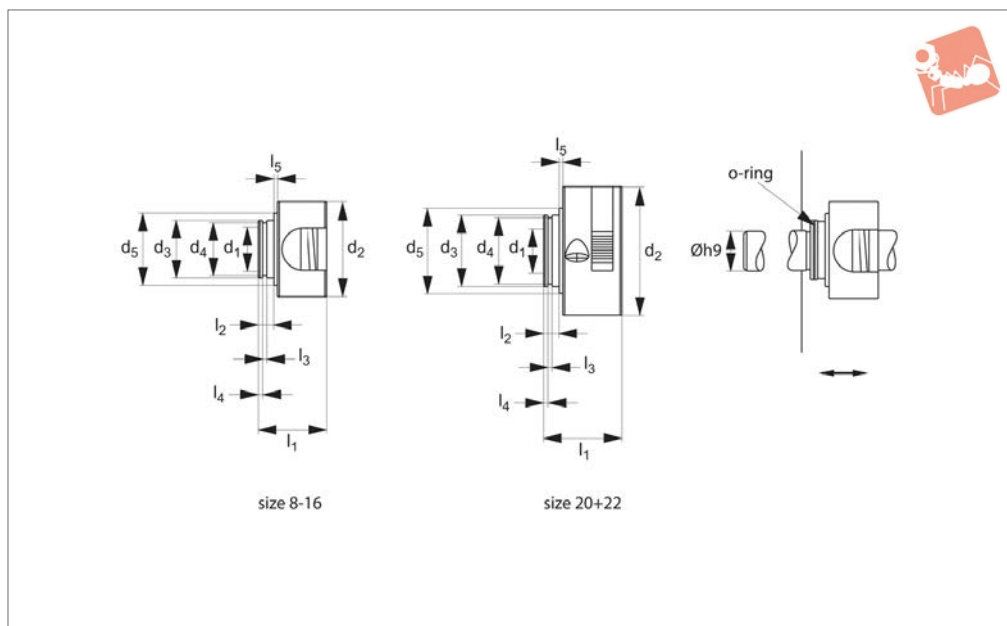

Set Collars



38660

SET COLLARS

Material

Body: Thermoplastic PA 6, black : Inner parts Stainless steel

Technical Notes

To be used for positioning, gripping, clam-

ping and as a quick adjustment element on shafts. Quick, self-clamping and vibration-free mounting by one-hand operation in pull-direction. Maximum temperature 80°C.

Order No.	d ₁ +0.1	d ₂	d ₃	d ₄	d ₅	l ₁	l ₂	l ₃	l ₄	l ₅	Holding force N axial, one-sided	Weight g
38660.W0008	8	40	25	22.4	31	27.5	7	1.7	3.15	0.50	250	31
38660.W0010	10	40	25	22.4	31	27.5	7	1.7	3.15	0.50	250	34
38660.W0012	12	40	25	22.4	31	27.5	7	1.7	3.15	0.50	350	30
38660.W0015	15	40	25	22.4	31	27.5	7	1.7	3.15	0.50	350	28
38660.W0016	16	40	25	22.4	31	27.5	7	1.7	3.15	0.50	380	27
38660.W0020	20	55	30	27.4	37	32.5	7	1.7	2.65	0.50	320	51
38660.W0022	22	55	30	27.4	37	32.5	7	1.7	2.65	0.50	320	49