




Horizontal Toggle Clamp Plus

stainless - increased clamping force

Stainless Steel Toggle Clamps

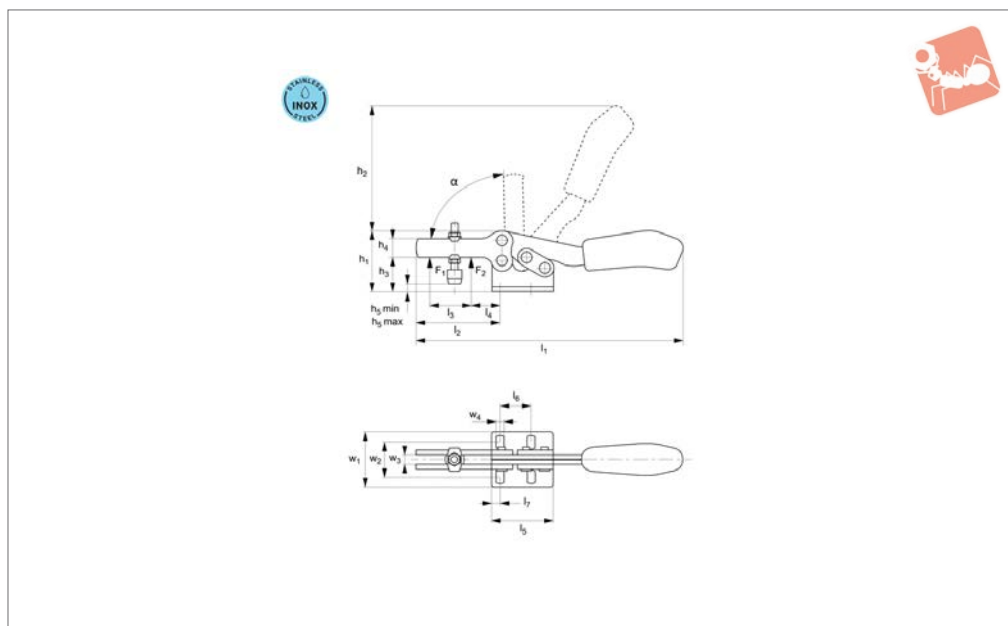

41001.4

STAINLESS STEEL TOGGLE CLAMPS

Material

Body: stainless steel, polished.
Rivets: stainless steel running in hardened bushes. Pre-lubricated bearings (grease suitable for food industry use).

Ergonomic soft feel oil-resistant handle with large grip area.
Supplied complete with stainless clamping screw (with rubber pad).

Technical Notes

Suitable for use in the food industry.
Temperature range -10°C to +80°C.
With increased retaining forces.

Order No.	Size	F ₁ kN	F ₂ kN	Clamping screw	h ₁	h ₂	h ₃	h ₄	h ₅ min.	h ₅ max.	l ₁	Weight g
41001.W0301	1	1.1	1.7	M 5x35	37	52	19.6	12	1	10.2	125	150
41001.W0302	2	1.6	3.0	M 6x50	51	110	28.0	16	-1	12.0	224	450
41001.W0303	3	2.5	4.0	M 8x58	61	112	35.0	18	1	13.0	243	600
41001.W0304	4	3.5	8.0	M10x76	77	135	41.0	24	-2	17.5	329	1250

Order No.	l ₂	l ₃	l ₄	l ₅	l ₆	l ₇	w ₁	w ₂	w ₃	w ₄	α
41001.W0301	44	20.5	15.0	40	13.5	6.0	27.2	14,7 - 19,5	5	4.3	80°
41001.W0302	71	39.0	14.0	52	26.0	7.0	46.0	23,5 - 34,0	8	6.5	90°
41001.W0303	74	41.5	20.6	56	26.2	6.5	49.2	27,5 - 38,0	8	6.5	90°
41001.W0304	120	69.0	23.0	76	41.5	10.5	60.0	34,5 - 45,0	10	8.6	90°