


Hook Type Toggle Clamp

stainless steel - narrow base

**Stainless Steel
Toggle Clamps**

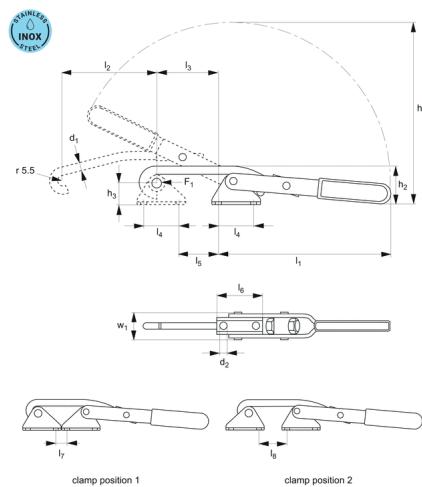

41781.4



STAINLESS STEEL TOGGLE CLAMPS

Material

Body: stainless steel (AISI 304, 1.4301).
Rivets: stainless steel running in hardened bushes. Pre-lubricated bearings.
Handle: oil-resistant plastic with large grip area.

Technical Notes

Suitable for use as a toggle type fastener

for the lids or covers of fixed or rotating drums and containers. The length of the hook is adjustable.

Their narrow base makes them ideal for applications where space is limited but holding forces must not be compromised.

The length of the hook is adjustable, up to 22mm. Adjustment made by rotating

the threaded hook to extend or contract its reach.

Temperature range -10°C to +80°C.

Tips

See part no. 41791.W0313 for fixed catch.

Order No.	Size	F_1 kN	h_1	h_2	h_3	l_1	l_2	l_3	l_4	l_5	l_6	l_7	l_8	w_1	d_1	d_2	Adj. distance	Weight g
41781.W0303	3	1.5	179	37	23	169	98	44- 55	38	15- 41	52	15- 20	29- 41	26.5	8	6.5	22	270