




Push-Pull Toggle Clamps

stainless steel - angle bracket

Stainless Steel Toggle Clamps

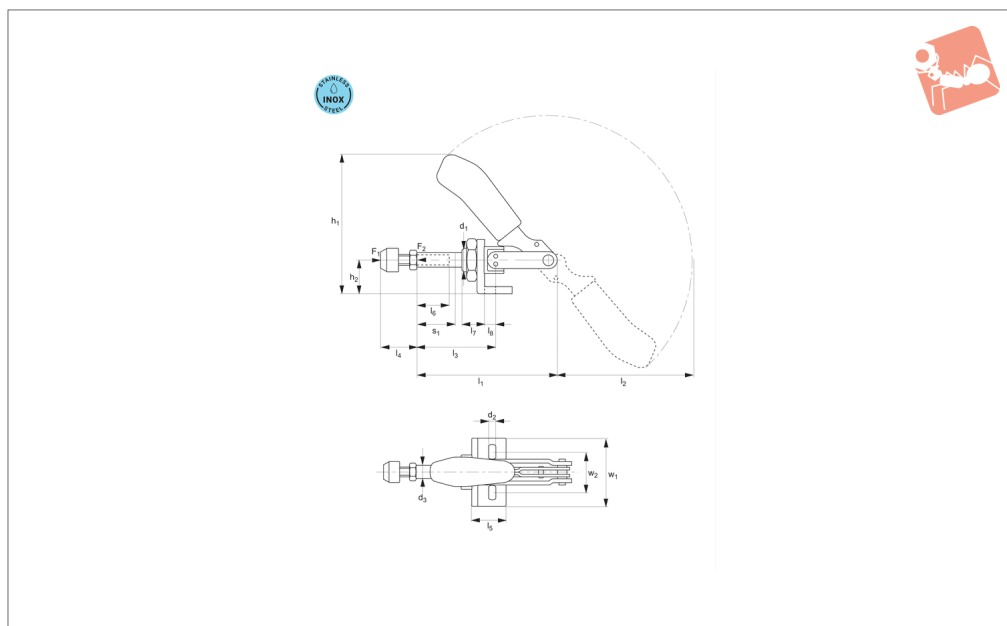

41890

STAINLESS STEEL TOGGLE CLAMPS

Material

Body: stainless steel (AISI 304, 1.4301), polished.
Rivets: stainless steel running in hardened bushes. Pre-lubricated bearings.
Ergonomic soft feel, oil-resistant handle

with large grip area.

Supplied complete with stainless clamping screw (with rubber pad).

Technical Notes

Long clamping stroke. Lever can be set to

any angle relative to base.

Suitable for use in the food industry.
Temperature range -10°C to +80°C.

Order No.	Size	F ₁ kN	F ₂ kN	Clamping screw	Stroke s ₁	h ₁	h ₂	l ₁	l ₂	Weight g
41890.W0000	0	0.8	0.8	M 4x20	16	49.3	12	66.5	54	65
41890.W0003	3	2.5	2.5	M 8x35	32	110.0	25	140.0	132	445

Order No.	l ₃ min.	l ₃ max.	l ₄ min.	l ₄ max.	l ₅	l ₆	l ₇	l ₈	w ₁	w ₂	d ₁	d ₂	d ₃
41890.W0000	17	33	12	20	16	13	10	6.5	25	16.0	M10x1,0	4.5	6.5
41890.W0003	37	69	22	35	30	30	22	13.0	60	29,5-42,5	M20x1,5	6.5	12.0