




Heavy Duty Push-Pull Toggle Clamps

reversible lever



Heavy Duty Toggle Clamps

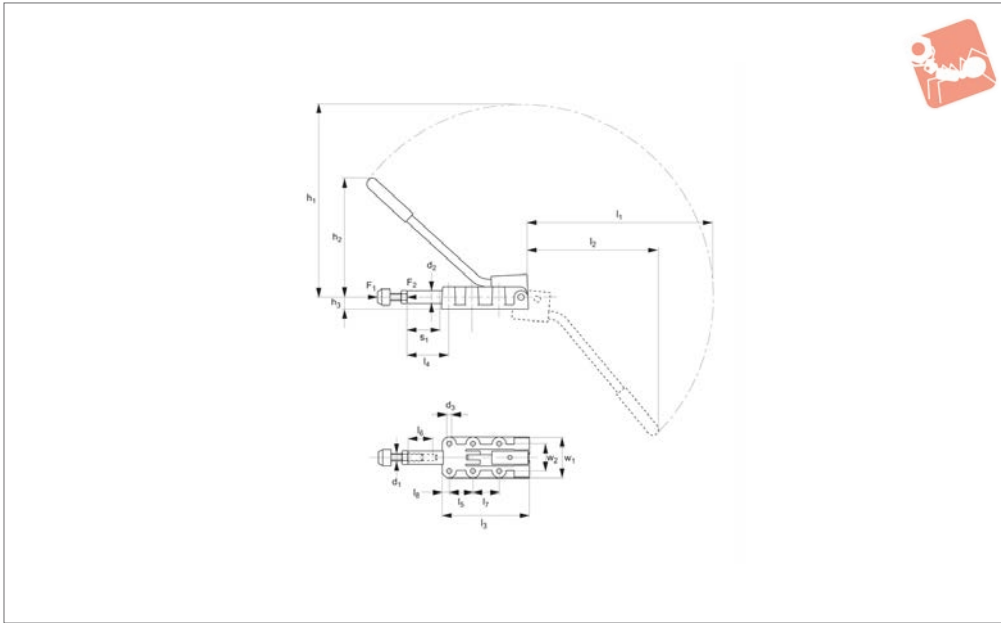

42100

HEAVY DUTY TOGGLE CLAMPS

Material

Body: cast iron, malleable, burnished.
 Lever and rod: tempered steel, burnished.
 Lever: steel, zinc plated.
 Handle: ergonomic soft feel, oil-resistant,

with large grip area.

Supplied complete with zinc plated clamping screw.

Technical Notes

For push-pull clamping.
 Very strong construction with long push-rod guidance.
 Temperature range -10°C to +80°C.

Order No.	Size	F ₁ kN	F ₂ kN	Clamping screw d ₁	Stroke s ₁	d ₂	d ₃	h ₁	h ₂	h ₃	Weight g
42100.W0004	4	7	7	M 8x35	32	14	5.5	190.0	115.0	12	650
42100.W0005	5	12	12	M10x50	50	20	8.5	290.5	178.5	18	1600
42100.W0007	7	25	25	M12x50	75	25	10.5	392.0	246.0	22	4280
42100.W0008	8	45	45	M16x80	106	30	10.5	523.0	323.0	28	7720

Order No.	l ₁	l ₂	l ₃	l ₄	l ₅	l ₆	l ₇	l ₈	w ₁	w ₂
42100.W0004	182	128	90	63	36.5	30	-	25.0	47	33.3
42100.W0005	279	197	137	63	35.0	50	41	8.0	58	41.0
42100.W0007	374	267	198	114	45.0	50	45	12.0	84	54.0
42100.W0008	501	365	254	149	70.0	60	70	14.5	86	57.0