




# Heavy Duty Push-Pull Toggle Clamp

solid hand lever



## Heavy Duty Toggle Clamps

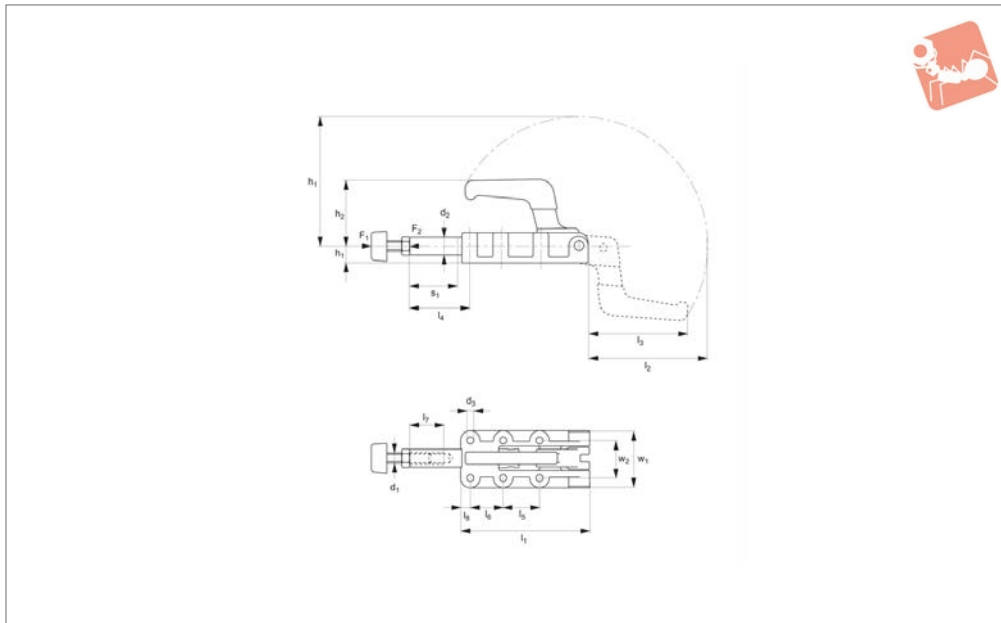

**42150**

HEAVY DUTY TOGGLE CLAMPS

### Material

Body: cast iron, malleable, burnished.  
 Lever and rod: tempered steel, burnished.  
 Handle: ergonomic soft feel, oil-resistant, with large grip area.

Supplied complete with zinc plated and tempered clamping screw.

### Technical Notes

Heavy duty version with long guide rod.  
 Temperature range -10°C to +80°C.

Order No.	Size	F <sub>1</sub> kN	F <sub>2</sub> kN	Clamping screw d <sub>1</sub>	Stroke s <sub>1</sub>	d <sub>2</sub>	d <sub>3</sub>	h <sub>1</sub>	h <sub>2</sub>	h <sub>3</sub>	Weight g
<b>42150.W0004</b>	4	7	7	M 8x35	32	14	5.5	96	42.5	12	590
<b>42150.W0005</b>	5	12	12	M10x50	50	20	8.5	136	70.0	18	1650
<b>42150.W0007</b>	7	25	25	M12x50	75	25	10.5	196	93.5	22	4150
<b>42150.W0008</b>	8	45	45	M16x80	106	30	10.5	247	111.5	28	7420

Order No.	l <sub>1</sub>	l <sub>2</sub>	l <sub>3</sub>	l <sub>4</sub>	l <sub>5</sub>	l <sub>6</sub>	l <sub>7</sub>	l <sub>8</sub>	w <sub>1</sub>	w <sub>2</sub>
<b>42150.W0004</b>	90	88.0	69.0	63	-	36.5	30	25.0	47	33.3
<b>42150.W0005</b>	137	126.0	105.0	63	41	35.0	50	8.0	58	41.0
<b>42150.W0007</b>	198	183.5	151.5	114	45	45.0	50	12.0	84	54.0
<b>42150.W0008</b>	254	232.0	196.0	149	70	70.0	60	14.5	86	57.0