



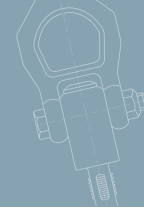

Durasoft Roller shaft drive

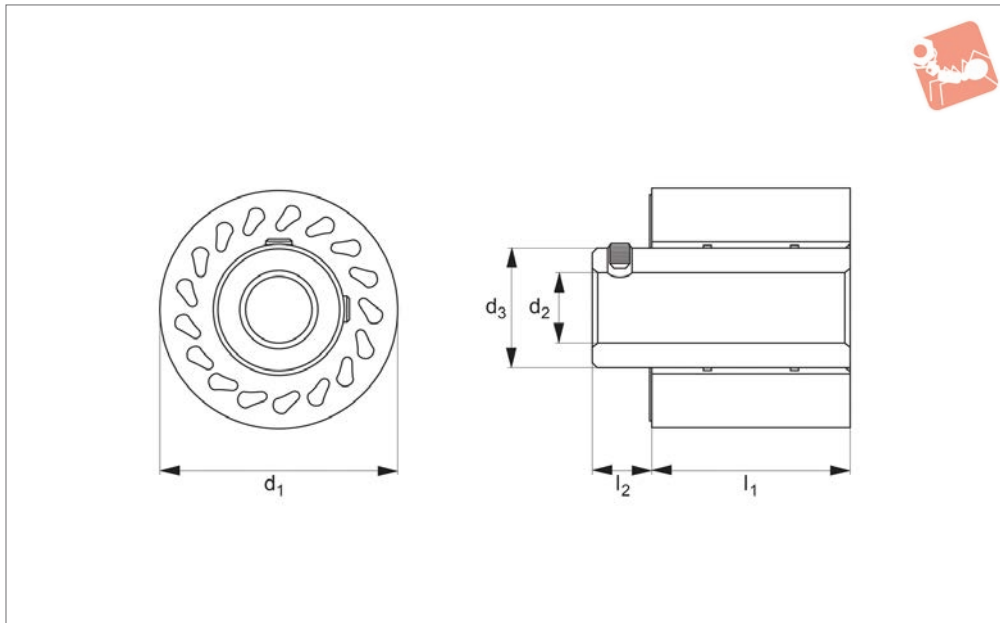

Rollers & Bumpers



60646

ROLLERS & BUMPERS

Material

Urethane bonded to a steel insert. Hardness from 35-80 durometer (Shore A).

Technical Notes

Designed to be mounted onto a shaft. A

hub extends past the roller and is supplied with two set screws at 90°.

damaging contact.

Tips

Durasoft rollers have „teardrop“ holes to allow the roller to flex for firm but non-

Order No.	Durometer	d ₁	l ₁	d ₂ min. max.	l ₂	d ₃
60646.W1003	35	63,5 (2,5“)	23.37	12,73/12,83	12.7	31.75
60646.W1006	60	63,5 (2,5“)	23.37	12,73/12,83	12.7	31.75
60646.W1008	80	63,5 (2,5“)	23.37	12,73/12,83	12.7	31.75
60646.W1009	95	63,5 (2,5“)	23.37	12,73/12,83	12.7	31.75
60646.W1013	35	63,5 (2,5“)	23.37	15,90/16,03	12.7	31.75
60646.W1016	60	63,5 (2,5“)	23.37	15,90/16,03	12.7	31.75
60646.W1018	80	63,5 (2,5“)	23.37	15,90/16,03	12.7	31.75
60646.W1019	95	63,5 (2,5“)	23.37	15,90/16,03	12.7	31.75
60646.W1023	35	63,5 (2,5“)	23.27	19,08/19,20	12.7	31.75
60646.W1026	60	63,5 (2,5“)	23.27	19,08/19,20	12.7	31.75
60646.W1028	80	63,5 (2,5“)	23.27	19,08/19,20	12.7	31.75
60646.W1029	95	63,5 (2,5“)	23.27	19,08/19,20	12.7	31.75