



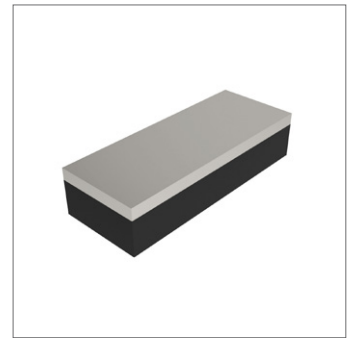

Anti-vibration Impact Plates

metal-rubber

Anti-Vibration

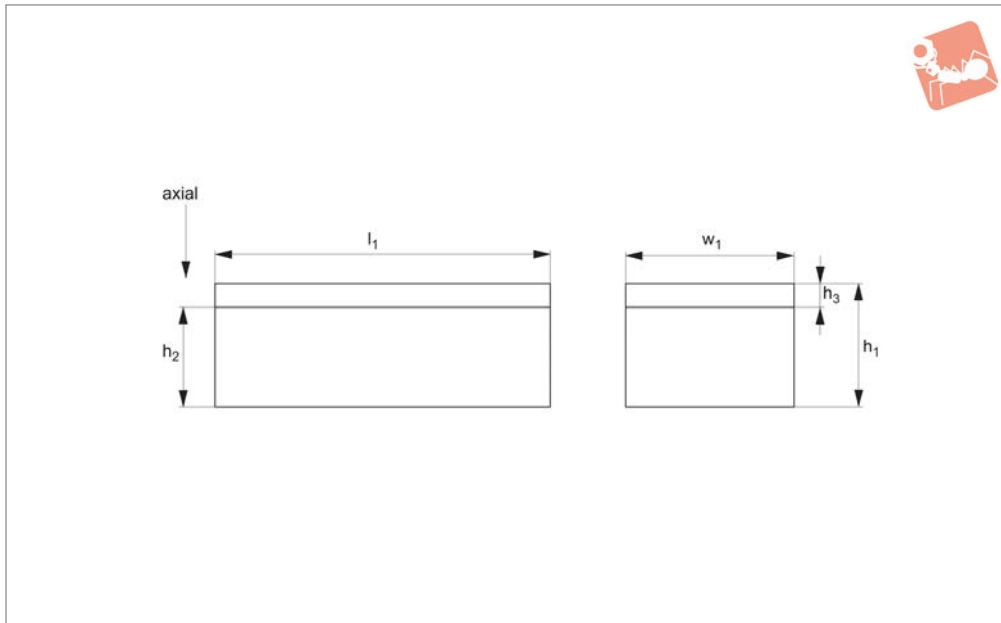

61600

ANTI-VIBRATION

Material

Rubber on silver zinc plated steel (rubber hardness - 60 Shore A).

be drilled to suit the number of threads, thread sizes and the pitch you require.

request.

Technical Notes

The metal plate is provided blank so it can

Part no. 61600.0500-125 has a ribbed base. Other sizes can be supplied on

Order No.	l_1	w_1	h_1	h_2	h_3	Axial load kgf max.	Compression max.
61600.W0035	1250	35	40	30	10	2500	2.0
61600.W0070	180	70	40	30	10	1000	2.8
61600.W0071	245	70	40	30	10	1300	3.7
61600.W0072	285	70	40	30	10	2000	3.6
61600.W0073	320	70	40	30	10	2700	3.5
61600.W0120	250	120	40	28	12	5000	3.3
61600.W0125	500	125	30	15	15	10000	4.0