
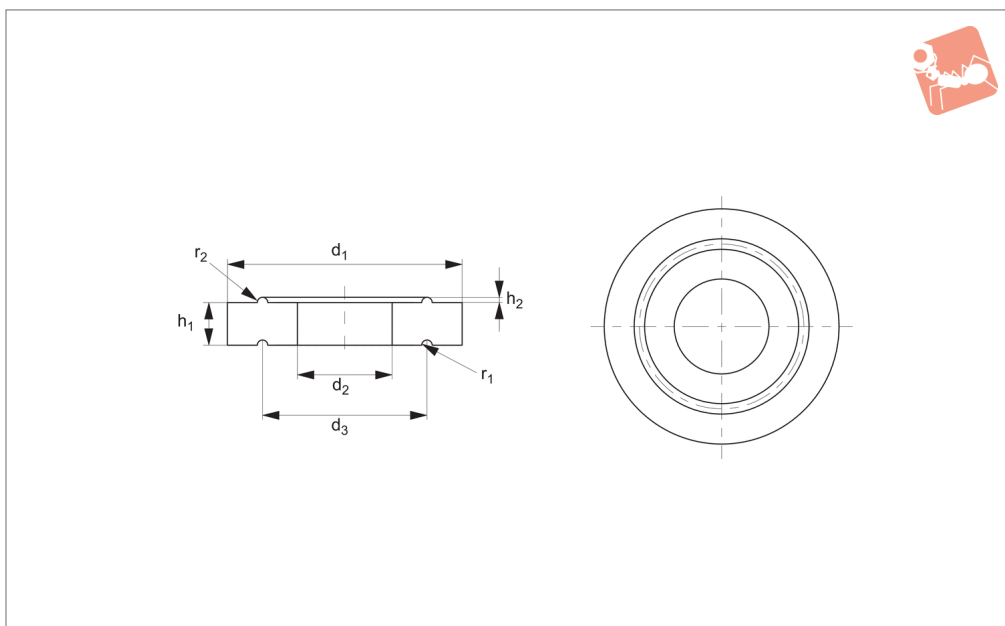


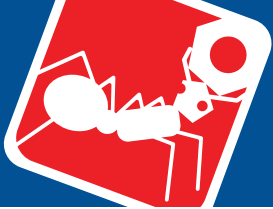

61760

ANTI-VIBRATION

Material

Rubber (hardness 70 Shore A).

Order No.	d ₁	d ₂	d ₃	h ₁	h ₂	r ₁	r ₂	Compression max.	Axial load kgf max.
61760.W0010	70	30	50	14	2	7	4	2	200
61760.W0020	72	32	52	23	2	2	2	7	400
61760.W0021	72	32	52	23	2	2	2	8.5	900
61760.W0022	76	37	58	12.5	3.5	2.5	2.5	2	550
61760.W0023	114	66	90	15	3	3	3	3.2	500
61760.W0024	114	66	90	15	3	3	3	5	1500
61760.W0030	116	52	84	23.5	2.5	3.5	2.5	3.5	800
61760.W0031	116	52	84	23.5	2.5	3.5	2.5	3.5	1000
61760.W0040	120	50	85	27.5	2.5	2.5	2.5	3.5	1000
61760.W0050	174	126	150	15	3	3	3	2	2000
61760.W0065	192	55	122	31	3	4	3	3.1	4340
61760.W0070	207	108	160	28	2	4	4	2.5	3000