


# Star Grips

plastic - DIN 6336



## Grips

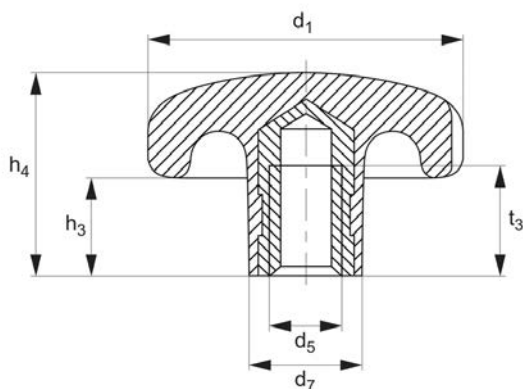

70140

GRIPS

### Material

Grip: duroplast PF 31 DIN 7708, black.

Threaded bush: steel, galvanised, stainless

steel A2 or brass.

### Technical Notes

Temperature range: max 110°C.

| Order No.   | Finish    | d <sub>1</sub> | d <sub>5</sub> | d <sub>7</sub> | h <sub>3</sub> | h <sub>4</sub> | t <sub>3</sub> | Weight<br>g |
|-------------|-----------|----------------|----------------|----------------|----------------|----------------|----------------|-------------|
| 70140.W0220 | Brass     | 20             | M 4            | 10             | 7              | 13             | 6.5            | 3.4         |
| 70140.W0225 | Steel     | 25             | M 5            | 12             | 8              | 16             | 9.5            | 7.4         |
| 70140.W0232 | Steel     | 32             | M 6            | 14             | 10             | 20             | 12.0           | 11.0        |
| 70140.W0240 | Steel     | 40             | M 8            | 18             | 13             | 25             | 14.0           | 22.0        |
| 70140.W0250 | Steel     | 50             | M10            | 22             | 17             | 32             | 18.0           | 40.0        |
| 70140.W0263 | Steel     | 63             | M12            | 26             | 21             | 40             | 22.0           | 83.0        |
| 70140.W0280 | Steel     | 80             | M16            | 35             | 25             | 50             | 30.0           | 163.0       |
| 70140.W1225 | Stainless | 25             | M 5            | 12             | 8              | 16             | 9.5            | 7.4         |
| 70140.W1232 | Stainless | 32             | M 6            | 14             | 10             | 20             | 12.0           | 11.0        |
| 70140.W1240 | Stainless | 40             | M 8            | 18             | 13             | 25             | 14.0           | 22.0        |
| 70140.W1250 | Stainless | 50             | M10            | 22             | 17             | 32             | 18.0           | 40.0        |
| 70140.W1263 | Stainless | 63             | M12            | 26             | 21             | 40             | 22.0           | 83.0        |
| 70140.W1280 | Stainless | 80             | M16            | 35             | 25             | 50             | 30.0           | 163.0       |