


# Star Grips


female, stainless steel




# 70160

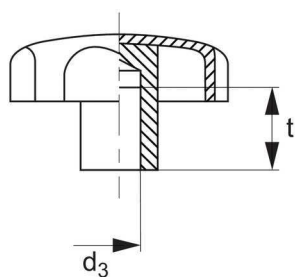

smooth blind hole

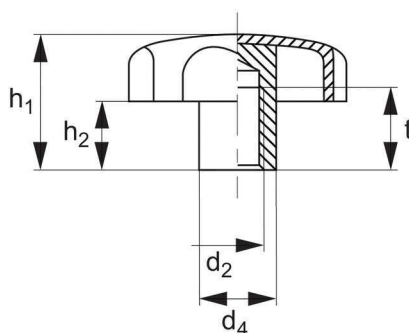

threaded blind hole

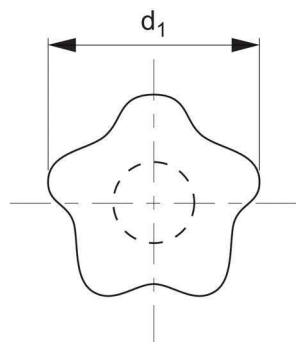


### Material

Grip: sheet drawn stainless (AISI 304) dull blasted.

Hub: stainless steel (AISI 304), butt-welded.



Order No.	Finish	d <sub>1</sub>	d <sub>2</sub>	d <sub>3</sub> H7	d <sub>4</sub>	h <sub>1</sub>	h <sub>2</sub>	t min	 g
70160.W0240	Smooth, Blind	40	-	8	14	25	12,5	15	29
70160.W0250	Smooth, Blind	50	-	10	18	32	17,5	18	67
70160.W0260	Smooth, Blind	60	-	12	20	40	21,0	22	110
70160.W0440	Threaded, Blind	40	M 8	-	14	25	12,5	15	37
70160.W0450	Threaded, Blind	50	M10	-	18	32	17,5	18	69
70160.W0460	Threaded, Blind	60	M12	-	20	40	21,0	22	112