



# Star Grips

solid stainless steel

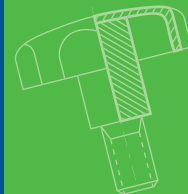

## Grips

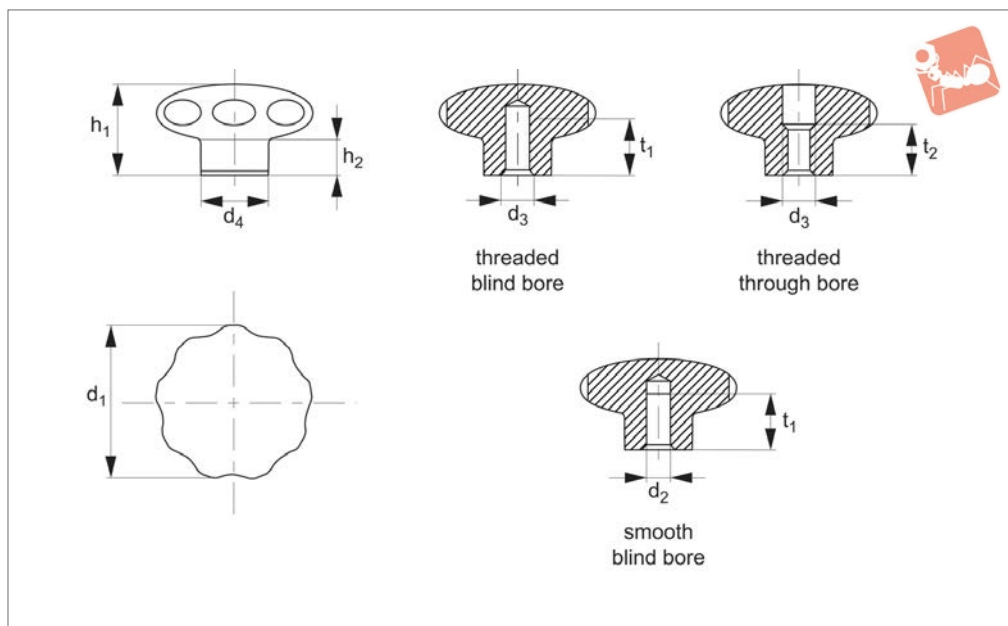

70180

GRIPS

### Material

Stainless steel 1.4305 (AISI 303), matt, dull blasted.

### Technical Notes

Stainless steel star grips are a special

development intended for the food processing machinery industry. Large radii and smooth surfaces have been introduced to meet the highest hygienic demands.

| Order No.   | Finish           | d <sub>1</sub> | d <sub>2</sub><br>tol. H7 | d <sub>3</sub> | d <sub>4</sub> | h <sub>1</sub> | h <sub>2</sub> | t <sub>1</sub><br>min. | t <sub>2</sub> | Weight<br>g |
|-------------|------------------|----------------|---------------------------|----------------|----------------|----------------|----------------|------------------------|----------------|-------------|
| 70180.W0040 | Threaded, Blind  | 40             | -                         | M 6            | 18             | 30.5           | 15             | 12                     | -              | 134         |
| 70180.W0041 | Threaded, Blind  | 40             | -                         | M 8            | 18             | 30.5           | 15             | 12                     | -              | 132         |
| 70180.W0050 | Threaded, Blind  | 50             | -                         | M 8            | 21             | 34.0           | 17             | 15                     | -              | 226         |
| 70180.W0051 | Threaded, Blind  | 50             | -                         | M10            | 21             | 34.0           | 17             | 15                     | -              | 222         |
| 70180.W0060 | Threaded, Blind  | 60             | -                         | M10            | 25             | 39.0           | 18             | 18                     | -              | 395         |
| 70180.W0061 | Threaded, Blind  | 60             | -                         | M12            | 25             | 39.0           | 18             | 18                     | -              | 384         |
| 70180.W0141 | Threaded Through | 40             | -                         | M 8            | 18             | 30.5           | 15             | -                      | 13             | 129         |
| 70180.W0151 | Threaded Through | 50             | -                         | M10            | 21             | 34.0           | 17             | -                      | 16             | 216         |
| 70180.W0161 | Threaded Through | 60             | -                         | M12            | 25             | 39.0           | 18             | -                      | 20             | 362         |
| 70180.W0240 | Smooth, Blind    | 40             | 8                         | -              | 18             | 30.5           | 15             | 12                     | -              | 131         |
| 70180.W0250 | Smooth, Blind    | 50             | 10                        | -              | 21             | 34.0           | 17             | 15                     | -              | 223         |
| 70180.W0260 | Smooth, Blind    | 60             | 12                        | -              | 25             | 39.0           | 18             | 18                     | -              | 386         |