




# Star Grips with grub screw - DIN 6336

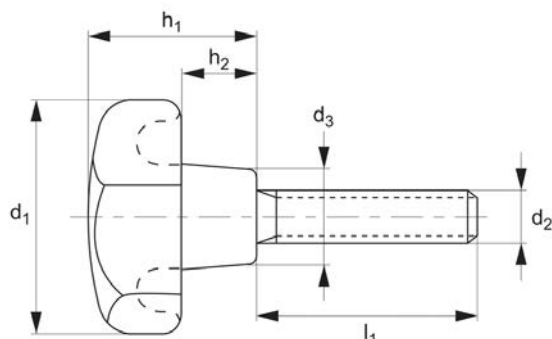

Grips



70500

GRIPS

## Material

duroplast PF 31, black.  
Grub screw: steel, galvanised.

Special designs e.g. different lengths or  
grub screws in brass or stainless steel, on  
request.

## Technical Notes

Produced to DIN 7708.

Temperature range max. 110°C.  
DIN 6336.

| Order No.   | Material        | d <sub>1</sub> | d <sub>2</sub> | d <sub>3</sub> | h <sub>1</sub> | h <sub>2</sub> | l <sub>1</sub> | Weight<br>g |
|-------------|-----------------|----------------|----------------|----------------|----------------|----------------|----------------|-------------|
| 70500.W0051 | Steel           | 25             | M 5            | 12             | 16             | 8              | 10             | 7.3         |
| 70500.W0054 | Steel           | 25             | M 5            | 12             | 16             | 8              | 15             | 7.2         |
| 70500.W0056 | Steel           | 25             | M 5            | 12             | 16             | 8              | 20             | 8.7         |
| 70500.W0058 | Steel           | 25             | M 5            | 12             | 16             | 8              | 25             | 8.7         |
| 70500.W0060 | Steel           | 25             | M 5            | 12             | 16             | 8              | 30             | 9.2         |
| 70500.W0102 | Steel           | 32             | M 6            | 14             | 20             | 10             | 15             | 14.0        |
| 70500.W0104 | Steel           | 32             | M 6            | 14             | 20             | 10             | 20             | 14.0        |
| 70500.W0106 | Steel           | 32             | M 6            | 14             | 20             | 10             | 25             | 14.0        |
| 70500.W0108 | Steel           | 32             | M 6            | 14             | 20             | 10             | 30             | 16.0        |
| 70500.W0110 | Steel           | 32             | M 6            | 14             | 20             | 10             | 40             | 17.0        |
| 70500.W0152 | Steel           | 40             | M 8            | 18             | 25             | 13             | 20             | 28.0        |
| 70500.W0154 | Steel           | 40             | M 8            | 18             | 25             | 13             | 25             | 30.0        |
| 70500.W0156 | Steel           | 40             | M 8            | 18             | 25             | 13             | 30             | 32.0        |
| 70500.W0158 | Steel           | 40             | M 8            | 18             | 25             | 13             | 40             | 35.0        |
| 70500.W0160 | Steel           | 40             | M 8            | 18             | 25             | 13             | 50             | 38.0        |
| 70500.W0202 | Steel           | 50             | M10            | 22             | 32             | 17             | 25             | 51.0        |
| 70500.W0204 | Steel           | 50             | M10            | 22             | 32             | 17             | 30             | 54.0        |
| 70500.W0206 | Steel           | 50             | M10            | 22             | 32             | 17             | 40             | 60.0        |
| 70500.W0208 | Steel           | 50             | M10            | 22             | 32             | 17             | 50             | 64.0        |
| 70500.W0210 | Steel           | 50             | M10            | 22             | 32             | 17             | 60             | 77.0        |
| 70500.W0252 | Steel           | 63             | M12            | 26             | 40             | 21             | 30             | 101.0       |
| 70500.W0254 | Steel           | 63             | M12            | 26             | 40             | 21             | 40             | 108.0       |
| 70500.W0256 | Steel           | 63             | M12            | 26             | 40             | 21             | 50             | 115.0       |
| 70500.W0258 | Steel           | 63             | M12            | 26             | 40             | 21             | 60             | 121.0       |
| 70500.W0260 | Steel           | 63             | M12            | 26             | 40             | 21             | 80             | 143.0       |
| 70500.W0302 | Steel           | 80             | M16            | 35             | 50             | 25             | 40             | 223.0       |
| 70500.W0304 | Steel           | 80             | M16            | 35             | 50             | 25             | 50             | 237.0       |
| 70500.W0306 | Steel           | 80             | M16            | 35             | 50             | 25             | 60             | 232.0       |
| 70500.W0308 | Steel           | 80             | M16            | 35             | 50             | 25             | 80             | 274.0       |
| 70500.W1051 | Stainless Steel | 25             | M 5            | 12             | 16             | 8              | 10             | 7.3         |
| 70500.W1054 | Stainless Steel | 25             | M 5            | 12             | 16             | 8              | 15             | 7.2         |
| 70500.W1056 | Stainless Steel | 25             | M 5            | 12             | 16             | 8              | 20             | 8.7         |



| Order No.   | Material        | d <sub>1</sub> | d <sub>2</sub> | d <sub>3</sub> | h <sub>1</sub> | h <sub>2</sub> | l <sub>1</sub> | Weight<br>g |
|-------------|-----------------|----------------|----------------|----------------|----------------|----------------|----------------|-------------|
| 70500.W1058 | Stainless Steel | 25             | M 5            | 12             | 16             | 8              | 25             | 8.7         |
| 70500.W1060 | Stainless Steel | 25             | M 5            | 12             | 16             | 8              | 30             | 9.2         |
| 70500.W1102 | Stainless Steel | 32             | M 6            | 14             | 20             | 10             | 15             | 14.0        |
| 70500.W1104 | Stainless Steel | 32             | M 6            | 14             | 20             | 10             | 20             | 14.0        |
| 70500.W1106 | Stainless Steel | 32             | M 6            | 14             | 20             | 10             | 25             | 14.0        |
| 70500.W1108 | Stainless Steel | 32             | M 6            | 14             | 20             | 10             | 30             | 16.0        |
| 70500.W1110 | Stainless Steel | 32             | M 6            | 14             | 20             | 10             | 40             | 17.0        |
| 70500.W1152 | Stainless Steel | 40             | M 8            | 18             | 25             | 13             | 20             | 28.0        |
| 70500.W1154 | Stainless Steel | 40             | M 8            | 18             | 25             | 13             | 25             | 30.0        |
| 70500.W1156 | Stainless Steel | 40             | M 8            | 18             | 25             | 13             | 30             | 32.0        |
| 70500.W1158 | Stainless Steel | 40             | M 8            | 18             | 25             | 13             | 40             | 35.0        |
| 70500.W1160 | Stainless Steel | 40             | M 8            | 18             | 25             | 13             | 50             | 38.0        |
| 70500.W1202 | Stainless Steel | 50             | M10            | 22             | 32             | 17             | 25             | 51.0        |
| 70500.W1204 | Stainless Steel | 50             | M10            | 22             | 32             | 17             | 30             | 54.0        |
| 70500.W1206 | Stainless Steel | 50             | M10            | 22             | 32             | 17             | 40             | 60.0        |
| 70500.W1208 | Stainless Steel | 50             | M10            | 22             | 32             | 17             | 50             | 64.0        |
| 70500.W1210 | Stainless Steel | 50             | M10            | 22             | 32             | 17             | 60             | 77.0        |
| 70500.W1252 | Stainless Steel | 63             | M12            | 26             | 40             | 21             | 30             | 101.0       |
| 70500.W1254 | Stainless Steel | 63             | M12            | 26             | 40             | 21             | 40             | 108.0       |
| 70500.W1256 | Stainless Steel | 63             | M12            | 26             | 40             | 21             | 50             | 115.0       |
| 70500.W1258 | Stainless Steel | 63             | M12            | 26             | 40             | 21             | 60             | 121.0       |
| 70500.W1260 | Stainless Steel | 63             | M12            | 26             | 40             | 21             | 80             | 143.0       |
| 70500.W1302 | Stainless Steel | 80             | M16            | 35             | 50             | 25             | 40             | 223.0       |
| 70500.W1304 | Stainless Steel | 80             | M16            | 35             | 50             | 25             | 50             | 237.0       |
| 70500.W1306 | Stainless Steel | 80             | M16            | 35             | 50             | 25             | 60             | 232.0       |
| 70500.W1308 | Stainless Steel | 80             | M16            | 35             | 50             | 25             | 80             | 274.0       |