


Adjustable Clamping Levers

cast zinc, inner parts stainless steel

Clamping Levers

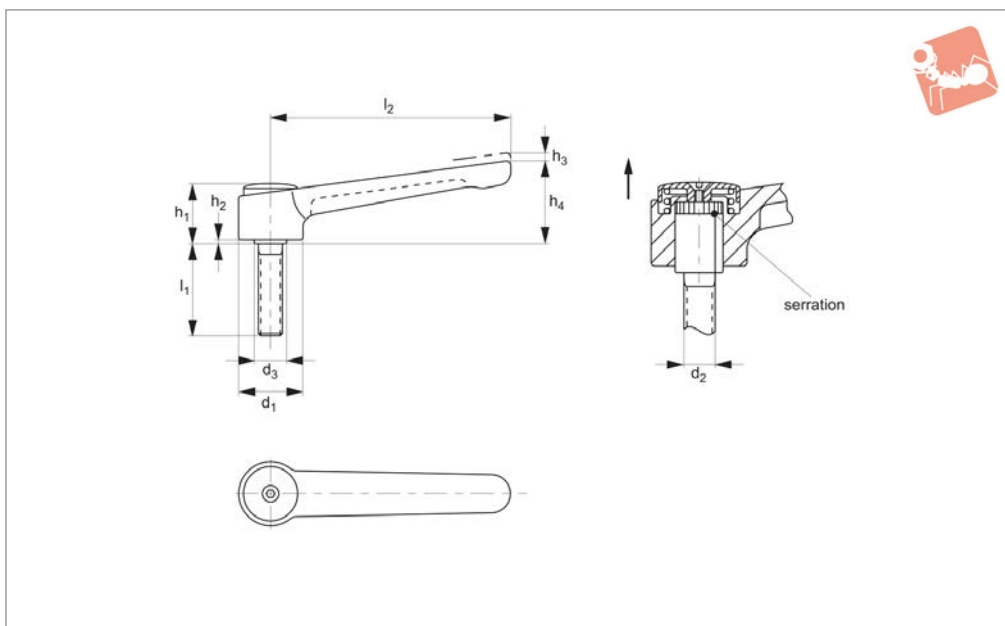

74496

CLAMPING LEVERS

Material

Lever: Zinc die-cast, plastic coated, matt
 Black - similar to RAL 9005
 Silver - similar to RAL 9006
 Inner: Stainless steel 1.4305
 Screw: Stainless steel 1.4305
 Cover: Plastic.

Technical Notes

By lifting up the lever, the serrations are disengaged and the handle can then be swung to any position. On releasing the serrations are automatically re-engaged.

Screw part can be changed.

Tips

Suitable for use in restricted areas due to low height and adjustable lever.

Order No.	Colour	l_1	d_1	d_2	d_3	h_1	h_2	h_3	h_4	l_2	Weight g
74496.W0650	Black	20	32	M10	16	29.5	2	2.5	41.5	120	202
74496.W0655	Black	25	32	M10	16	29.5	2	2.5	41.5	120	204
74496.W0660	Black	32	32	M10	16	29.5	2	2.5	41.5	120	207
74496.W0665	Black	40	32	M10	16	29.5	2	2.5	41.5	120	212
74496.W0670	Black	50	32	M10	16	29.5	2	2.5	41.5	120	217
74496.W0680	Black	80	32	M10	16	29.5	2	2.5	41.5	120	231
74496.W0685	Black	20	32	M12	16	29.5	2	2.5	41.5	120	206
74496.W0690	Black	25	32	M12	16	29.5	2	2.5	41.5	120	210
74496.W0695	Black	32	32	M12	16	29.5	2	2.5	41.5	120	215
74496.W0700	Black	40	32	M12	16	29.5	2	2.5	41.5	120	221
74496.W0705	Black	50	32	M12	16	29.5	2	2.5	41.5	120	228
74496.W0710	Black	63	32	M12	16	29.5	2	2.5	41.5	120	237
74496.W0715	Black	80	32	M12	16	29.5	2	2.5	41.5	120	249
74496.W0725	Black	32	40	M12	23	42.0	4	4.0	56.0	145	432
74496.W0730	Black	40	40	M12	23	42.0	4	4.0	56.0	145	440
74496.W0735	Black	50	40	M12	23	42.0	4	4.0	56.0	145	447
74496.W0740	Black	63	40	M12	23	42.0	4	4.0	56.0	145	455
74496.W0745	Black	80	40	M12	23	42.0	4	4.0	56.0	145	445
74496.W0750	Black	32	40	M16	23	42.0	4	4.0	56.0	145	449
74496.W0755	Black	40	40	M16	23	42.0	4	4.0	56.0	145	460
74496.W0760	Black	50	40	M16	23	42.0	4	4.0	56.0	145	472
74496.W0765	Black	63	40	M16	23	42.0	4	4.0	56.0	145	491
74496.W0770	Black	80	40	M16	23	42.0	4	4.0	56.0	145	513
74496.W1650	Silver	20	32	M10	16	29.5	2	2.5	41.5	120	202
74496.W1655	Silver	25	32	M10	16	29.5	2	2.5	41.5	120	204
74496.W1660	Silver	32	32	M10	16	29.5	2	2.5	41.5	120	207
74496.W1665	Silver	40	32	M10	16	29.5	2	2.5	41.5	120	212
74496.W1670	Silver	50	32	M10	16	29.5	2	2.5	41.5	120	217
74496.W1680	Silver	80	32	M10	16	29.5	2	2.5	41.5	120	231
74496.W1685	Silver	20	32	M12	16	29.5	2	2.5	41.5	120	206
74496.W1690	Silver	25	32	M12	16	29.5	2	2.5	41.5	120	210



Order No.	Colour	l_1	d_1	d_2	d_3	h_1	h_2	h_3	h_4	l_2	Weight g
74496.W1695	Silver	32	32	M12	16	29.5	2	2.5	41.5	120	215
74496.W1700	Silver	40	32	M12	16	29.5	2	2.5	41.5	120	221
74496.W1705	Silver	50	32	M12	16	29.5	2	2.5	41.5	120	228
74496.W1710	Silver	63	32	M12	16	29.5	2	2.5	41.5	120	237
74496.W1715	Silver	80	32	M12	16	29.5	2	2.5	41.5	120	249
74496.W1725	Silver	32	40	M12	23	42.0	4	4.0	56.0	145	432
74496.W1730	Silver	40	40	M12	23	42.0	4	4.0	56.0	145	440
74496.W1735	Silver	50	40	M12	23	42.0	4	4.0	56.0	145	447
74496.W1740	Silver	63	40	M12	23	42.0	4	4.0	56.0	145	455
74496.W1745	Silver	80	40	M12	23	42.0	4	4.0	56.0	145	445
74496.W1750	Silver	32	40	M16	23	42.0	4	4.0	56.0	145	449
74496.W1755	Silver	40	40	M16	23	42.0	4	4.0	56.0	145	460
74496.W1760	Silver	50	40	M16	23	42.0	4	4.0	56.0	145	472
74496.W1765	Silver	63	40	M16	23	42.0	4	4.0	56.0	145	491
74496.W1770	Silver	80	40	M16	23	42.0	4	4.0	56.0	145	513